




# Adjustable Clamping Levers

## Clamping Levers

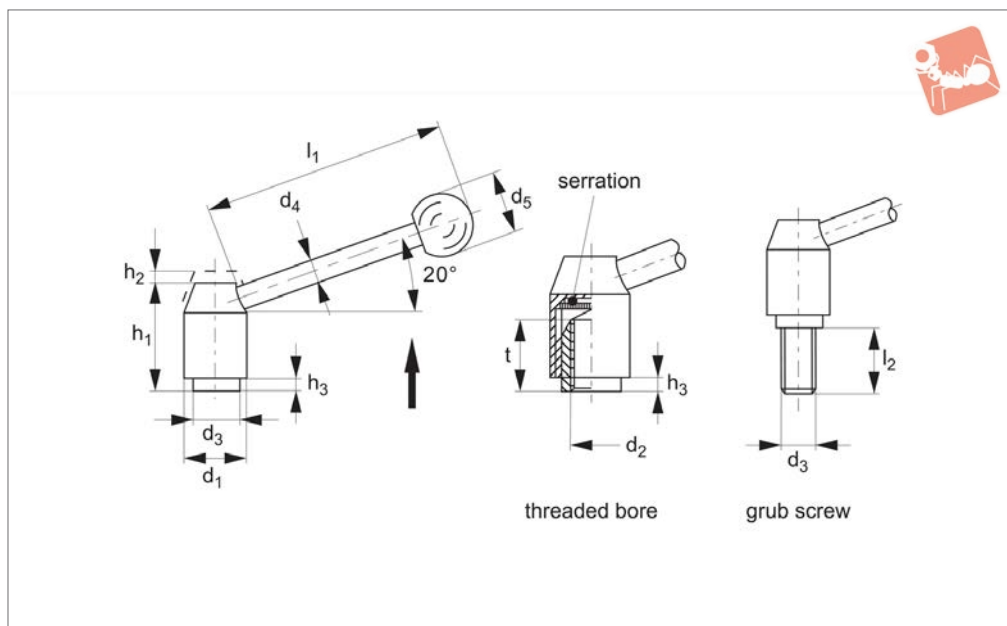

74500

CLAMPING LEVERS

### Material

Lever: free cutting steel, blackened.  
Screw & inner parts: steel, quality 5.8, blackened.

Ball knob: DIN 319 plastic. (PF 31), black.

### Technical Notes

By lifting up the lever, the serrations are

disengaged and the handle can then be swung to any position. On releasing the serrations are automatically re-engaged.

| Order No.   | Finish        | d <sub>1</sub> | d <sub>2</sub> | d <sub>3</sub> | d <sub>4</sub> | d <sub>5</sub> | h <sub>1</sub> | h <sub>2</sub> | h <sub>3</sub> | l <sub>1</sub><br>≈ | l <sub>2</sub> | t<br>min. | Weight<br>g |
|-------------|---------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|---------------------|----------------|-----------|-------------|
| 74500.W0101 | Threaded Bore | 21             | M 6            | 13.5           | 8              | 20             | 33.5           | 4.0            | 1.0            | 70                  | -              | 11        | 91          |
| 74500.W0102 | Threaded Bore | 21             | M 8            | 13.5           | 8              | 20             | 33.5           | 4.0            | 1.0            | 70                  | -              | 11        | 89          |
| 74500.W0201 | Threaded Bore | 24             | M 8            | 16.0           | 10             | 25             | 40.0           | 4.5            | 2.5            | 96                  | -              | 14        | 159         |
| 74500.W0202 | Threaded Bore | 24             | M10            | 16.0           | 10             | 25             | 40.0           | 4.5            | 2.5            | 96                  | -              | 14        | 153         |
| 74500.W0301 | Threaded Bore | 28             | M10            | 19.0           | 12             | 30             | 48.5           | 4.5            | 4.5            | 110                 | -              | 17        | 255         |
| 74500.W0302 | Threaded Bore | 28             | M12            | 19.0           | 12             | 30             | 48.5           | 4.5            | 4.5            | 110                 | -              | 17        | 248         |
| 74500.W0401 | Threaded Bore | 33             | M12            | 23.0           | 12             | 32             | 55.0           | 5.5            | 6.0            | 124                 | -              | 23        | 361         |
| 74500.W0402 | Threaded Bore | 33             | M16            | 23.0           | 12             | 32             | 55.0           | 5.5            | 6.0            | 124                 | -              | 23        | 347         |
| 74500.W0501 | Threaded Bore | 40             | M16            | 30.0           | 14             | 35             | 68.0           | 5.5            | 6.0            | 138                 | -              | 36        | 622         |
| 74500.W0502 | Threaded Bore | 40             | M20            | 30.0           | 14             | 35             | 68.0           | 5.5            | 6.0            | 138                 | -              | 36        | 599         |
| 74500.W0120 | Grub Screw    | 21             | M 8            | 13.5           | 8              | 20             | 33.5           | 4.0            | 1.0            | 70                  | 12             | -         | 98          |
| 74500.W0122 | Grub Screw    | 21             | M 8            | 13.5           | 8              | 20             | 33.5           | 4.0            | 1.0            | 70                  | 16             | -         | 99          |
| 74500.W0124 | Grub Screw    | 21             | M 8            | 13.5           | 8              | 20             | 33.5           | 4.0            | 1.0            | 70                  | 20             | -         | 103         |
| 74500.W0126 | Grub Screw    | 21             | M 8            | 13.5           | 8              | 20             | 33.5           | 4.0            | 1.0            | 70                  | 25             | -         | 102         |
| 74500.W0128 | Grub Screw    | 21             | M 8            | 13.5           | 8              | 20             | 33.5           | 4.0            | 1.0            | 70                  | 32             | -         | 105         |
| 74500.W0130 | Grub Screw    | 21             | M 8            | 13.5           | 8              | 20             | 33.5           | 4.0            | 1.0            | 70                  | 40             | -         | 112         |
| 74500.W0132 | Grub Screw    | 21             | M 8            | 13.5           | 8              | 20             | 33.5           | 4.0            | 1.0            | 70                  | 50             | -         | 109         |
| 74500.W0134 | Grub Screw    | 21             | M 8            | 13.5           | 8              | 20             | 33.5           | 4.0            | 1.0            | 70                  | 63             | -         | 114         |
| 74500.W0220 | Grub Screw    | 24             | M10            | 16.0           | 10             | 25             | 40.0           | 4.5            | 2.5            | 96                  | 16             | -         | 172         |
| 74500.W0222 | Grub Screw    | 24             | M10            | 16.0           | 10             | 25             | 40.0           | 4.5            | 2.5            | 96                  | 20             | -         | 173         |
| 74500.W0224 | Grub Screw    | 24             | M10            | 16.0           | 10             | 25             | 40.0           | 4.5            | 2.5            | 96                  | 25             | -         | 174         |
| 74500.W0226 | Grub Screw    | 24             | M10            | 16.0           | 10             | 25             | 40.0           | 4.5            | 2.5            | 96                  | 32             | -         | 177         |
| 74500.W0228 | Grub Screw    | 24             | M10            | 16.0           | 10             | 25             | 40.0           | 4.5            | 2.5            | 96                  | 40             | -         | 184         |
| 74500.W0230 | Grub Screw    | 24             | M10            | 16.0           | 10             | 25             | 40.0           | 4.5            | 2.5            | 96                  | 50             | -         | 185         |
| 74500.W0232 | Grub Screw    | 24             | M10            | 16.0           | 10             | 25             | 40.0           | 4.5            | 2.5            | 96                  | 63             | -         | 195         |
| 74500.W0234 | Grub Screw    | 24             | M10            | 16.0           | 10             | 25             | 40.0           | 4.5            | 2.5            | 96                  | 80             | -         | 205         |
| 74500.W0318 | Grub Screw    | 28             | M12            | 19.0           | 12             | 30             | 48.5           | 4.5            | 4.5            | 110                 | 16             | -         | 277         |
| 74500.W0320 | Grub Screw    | 28             | M12            | 19.0           | 12             | 30             | 48.5           | 4.5            | 4.5            | 110                 | 20             | -         | 282         |
| 74500.W0322 | Grub Screw    | 28             | M12            | 19.0           | 12             | 30             | 48.5           | 4.5            | 4.5            | 110                 | 25             | -         | 283         |
| 74500.W0324 | Grub Screw    | 28             | M12            | 19.0           | 12             | 30             | 48.5           | 4.5            | 4.5            | 110                 | 32             | -         | 287         |
| 74500.W0326 | Grub Screw    | 28             | M12            | 19.0           | 12             | 30             | 48.5           | 4.5            | 4.5            | 110                 | 40             | -         | 298         |
| 74500.W0328 | Grub Screw    | 28             | M12            | 19.0           | 12             | 30             | 48.5           | 4.5            | 4.5            | 110                 | 50             | -         | 302         |
| 74500.W0330 | Grub Screw    | 28             | M12            | 19.0           | 12             | 30             | 48.5           | 4.5            | 4.5            | 110                 | 63             | -         | 312         |
| 74500.W0332 | Grub Screw    | 28             | M12            | 19.0           | 12             | 30             | 48.5           | 4.5            | 4.5            | 110                 | 80             | -         | 320         |



| Order No.          | Finish     | d <sub>1</sub> | d <sub>2</sub> | d <sub>3</sub> | d <sub>4</sub> | d <sub>5</sub> | h <sub>1</sub> | h <sub>2</sub> | h <sub>3</sub> | l <sub>1</sub><br>≈ | l <sub>2</sub> | t<br>min. | Weight<br>g |
|--------------------|------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|---------------------|----------------|-----------|-------------|
| <b>74500.W0422</b> | Grub Screw | 33             | M16            | 23.0           | 12             | 32             | 55.0           | 5.5            | 6.0            | 124                 | 32             | -         | 422         |
| <b>74500.W0424</b> | Grub Screw | 33             | M16            | 23.0           | 12             | 32             | 55.0           | 5.5            | 6.0            | 124                 | 40             | -         | 439         |
| <b>74500.W0426</b> | Grub Screw | 33             | M16            | 23.0           | 12             | 32             | 55.0           | 5.5            | 6.0            | 124                 | 50             | -         | 446         |
| <b>74500.W0428</b> | Grub Screw | 33             | M16            | 23.0           | 12             | 32             | 55.0           | 5.5            | 6.0            | 124                 | 63             | -         | 461         |
| <b>74500.W0430</b> | Grub Screw | 33             | M16            | 23.0           | 12             | 32             | 55.0           | 5.5            | 6.0            | 124                 | 80             | -         | 486         |
| <b>74500.W0520</b> | Grub Screw | 40             | M20            | 30.0           | 14             | 35             | 68.0           | 5.5            | 6.0            | 138                 | 40             | -         | 772         |
| <b>74500.W0522</b> | Grub Screw | 40             | M20            | 30.0           | 14             | 35             | 68.0           | 5.5            | 6.0            | 138                 | 50             | -         | 792         |
| <b>74500.W0524</b> | Grub Screw | 40             | M20            | 30.0           | 14             | 35             | 68.0           | 5.5            | 6.0            | 138                 | 63             | -         | 826         |
| <b>74500.W0526</b> | Grub Screw | 40             | M20            | 30.0           | 14             | 35             | 68.0           | 5.5            | 6.0            | 138                 | 80             | -         | 859         |