


Adjustable Clamping Levers threaded insert

Clamping Levers

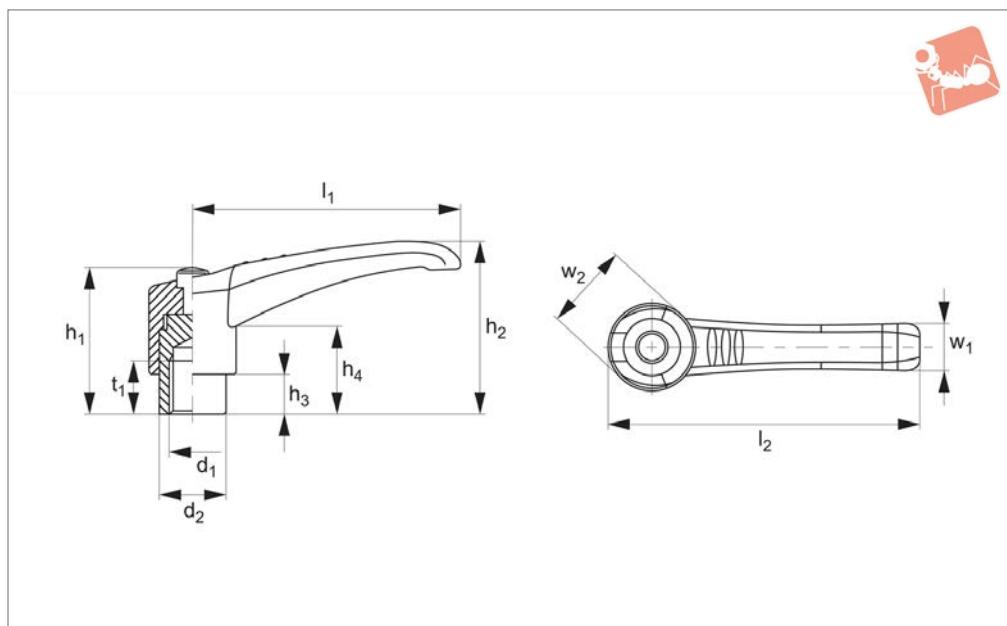

74760

CLAMPING LEVERS

Material

Black, matt thermoplast, reinforced.
Insert: zinc plated steel.

Button: black.

subject to minimum quantities.

Important Notes

Other button colours available on request

Order No.	l_1	d_1	l_2	d_2	h_1	h_2	h_3	h_4	t_1	w_1	w_2	Weight g
74760.W0452	45	M 5	53	12	30	33.5	7.5	18	8	10.5	16	22
74760.W0453	45	M 6	53	12	30	33.5	7.5	18	8	10.5	16	24
74760.W0652	65	M 6	75	15	35	41.0	7.5	19	11	13.5	20	26
74760.W0653	65	M 8	75	15	35	41.0	7.5	19	11	13.5	20	24
74760.W0801	80	M 8	92	20	45	53.0	12.0	26	16	16.5	24	55
74760.W0802	80	M10	92	20	45	53.0	12.0	26	16	16.5	24	56
74760.W0803	80	M12	92	20	45	53.0	12.0	26	16	16.5	24	57
74760.W0951	95	M12	108	21	50	61.0	13.0	30	22	19.0	27	83
74760.W0952	95	M14	108	21	50	61.0	13.0	30	22	19.0	27	94
74760.W0953	95	M16	108	21	50	61.0	13.0	30	22	19.0	27	89