


# Pull Handles - Aluminium

for 19" drawers and instrument panels



# 78120

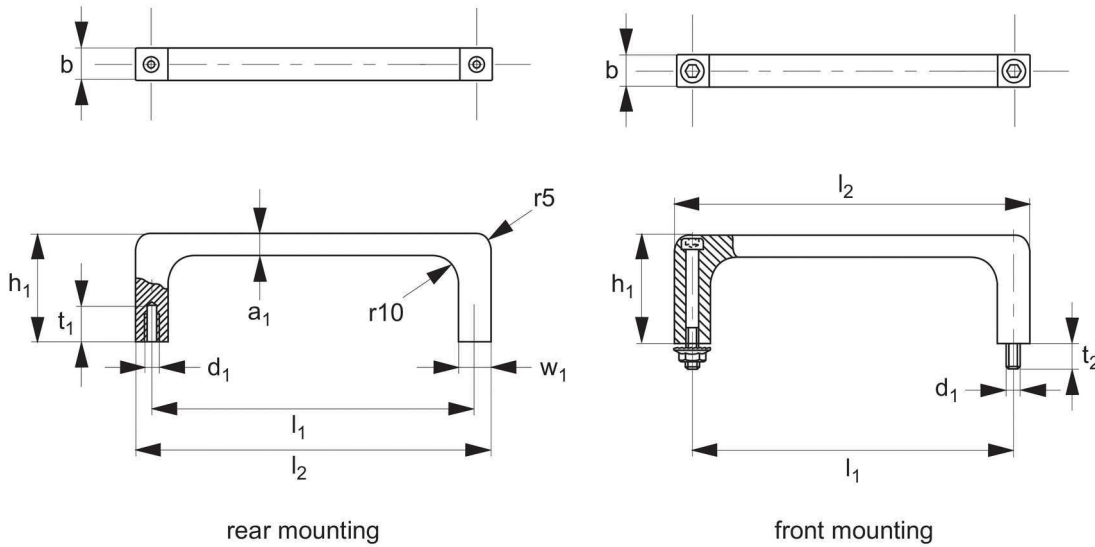

### Material

Profile aluminium Al Mg Si 0,5.  
Finish: vibration ground and anodized to a matt finish in natural or black colour. Stainless steel hexagon screws to DIN 912, with self locking nuts, are supplied for front mounting type.

### Technical Notes

Minimum stress resistance 500N.



Order No.	Type	Finish	h Height of front panel	Mou ntin g type	$l_1$	$l_2$	$d_1$	$h_1$	$a_1$	$b_1$	$t_1$	$t_2$	$w_1$
78120.W0005-1	Rear Mounting	Natural	88,1	1	55,0	67,0	M 5	40	8	12	10	9	12
78120.W0008-1	Rear Mounting	Natural	132,5	1	88,0	100,	M 5	40	8	12	10	9	12
78120.W0012-1	Rear Mounting	Natural	177,0	1	120,0	132,0	M 5	40	8	12	10	9	12
78120.W0018-1	Rear Mounting	Natural	221,5	1	180,0	192,0	M 5	40	8	12	10	9	12
78120.W0023-1	Rear Mounting	Natural	266,0	1	235,0	247,0	M 5	40	8	12	10	9	12
78120.W0505-1	Rear Mounting	Natural	44,0	2	32,0	43,5	M 5	40	8	12	10	9	12
78120.W0508-1	Rear Mounting	Natural	88,1	2	75,5	87,5	M 5	40	8	12	10	9	12
78120.W0512-1	Rear Mounting	Natural	132,5	2	120,0	132,0	M 5	40	8	12	10	9	12
78120.W0523-1	Rear Mounting	Natural	266,0	2	253,5	265,5	M 5	40	8	12	10	9	12
78120.W0005-4	Rear Mounting	Black	88,1	1	55,0	67,0	M 5	40	8	12	10	9	12
78120.W0008-4	Rear Mounting	Black	132,5	1	88,0	100,0	M 5	40	8	12	10	9	12
78120.W0012-4	Rear Mounting	Black	177,0	1	120,0	132,0	M 5	40	8	12	10	9	12
78120.W0018-4	Rear Mounting	Black	221,5	1	180,0	192,0	M 5	40	8	12	10	9	12
78120.W0023-4	Rear Mounting	Black	266,0	1	235,0	247,0	M 5	40	8	12	10	9	12
78120.W0505-4	Rear Mounting	Black	44,0	2	32,0	43,5	M 5	40	8	12	10	9	12
78120.W0508-4	Rear Mounting	Black	88,1	2	75,5	87,5	M 5	40	8	12	10	9	12
78120.W0512-4	Rear Mounting	Black	132,5	2	120,0	132,0	M 5	40	8	12	10	9	12
78120.W0523-4	Rear Mounting	Black	266,0	2	253,5	265,5	M 5	40	8	12	10	9	12
78120.W0105-1	Front Mounting	Natural	88,1	1	55,0	67,0	M 5	40	8	12	10	9	12
78120.W0108-1	Front Mounting	Natural	132,5	1	88,0	100,	M 5	40	8	12	10	9	12
78120.W0112-1	Front Mounting	Natural	177,0	1	120,0	132,0	M 5	40	8	12	10	9	12
78120.W0118-1	Front Mounting	Natural	221,5	1	180,0	192,0	M 5	40	8	12	10	9	12
78120.W0123-1	Front Mounting	Natural	266,0	1	235,0	247,0	M 5	40	8	12	10	9	12

# Pull Handles - Aluminium

for 19" drawers and instrument panels



# 78120

Order No.	Type	Finish	h Height of front panel	Mou ntin g type	l <sub>1</sub>	l <sub>2</sub>	d <sub>1</sub>	h <sub>1</sub>	a <sub>1</sub>	b <sub>1</sub>	t <sub>1</sub>	t <sub>2</sub>	w <sub>1</sub>
78120.W0605-1	Front Mounting	Natural	44,0	2	32,0	43,5	M 5	40	8	12	10	9	12
78120.W0608-1	Front Mounting	Natural	88,1	2	75,5	87,5	M 5	40	8	12	10	9	12
78120.W0612-1	Front Mounting	Natural	132,5	2	120,0	132,0	M 5	40	8	12	10	9	12
78120.W0623-1	Front Mounting	Natural	266,0	2	253,5	265,5	M 5	40	8	12	10	9	12
78120.W0105-4	Front Mounting	Black	88,1	1	55,0	67,0	M 5	40	8	12	10	9	12
78120.W0108-4	Front Mounting	Black	132,5	1	88,0	100,0	M 5	40	8	12	10	9	12
78120.W0112-4	Front Mounting	Black	177,0	1	120,0	132,0	M 5	40	8	12	10	9	12
78120.W0118-4	Front Mounting	Black	221,5	1	180,0	192,0	M 5	40	8	12	10	9	12
78120.W0123-4	Front Mounting	Black	266,0	1	235,0	247,0	M 5	40	8	12	10	9	12
78120.W0605-4	Front Mounting	Black	44,0	2	32,0	43,5	M 5	40	8	12	10	9	12
78120.W0608-4	Front Mounting	Black	88,1	2	75,5	87,5	M 5	40	8	12	10	9	12
78120.W0612-4	Front Mounting	Black	132,5	2	120,0	132,0	M 5	40	8	12	10	9	12
78120.W0623-4	Front Mounting	Black	266,0	2	253,5	265,5	M 5	40	8	12	10	9	12



### Material


Profile aluminium Al Mg Si 0,5. Finish: vibration ground and anodized to a matt finish in natural or black colour. Stainless steel hexagon screws to DIN 912, with self locking nuts, are supplied for front mounting type.

### Technical Notes


Minimum stress resistance 500N.



mounting of 19" front panels

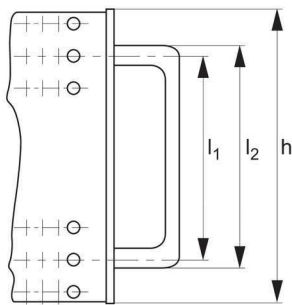

rear mounting

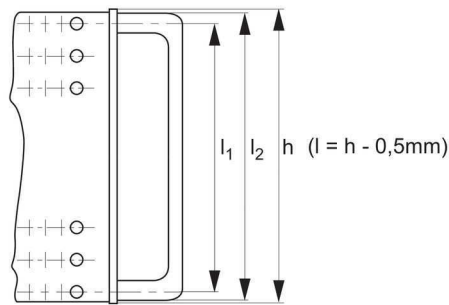

front mounting