




## Pull Handles stainless steel

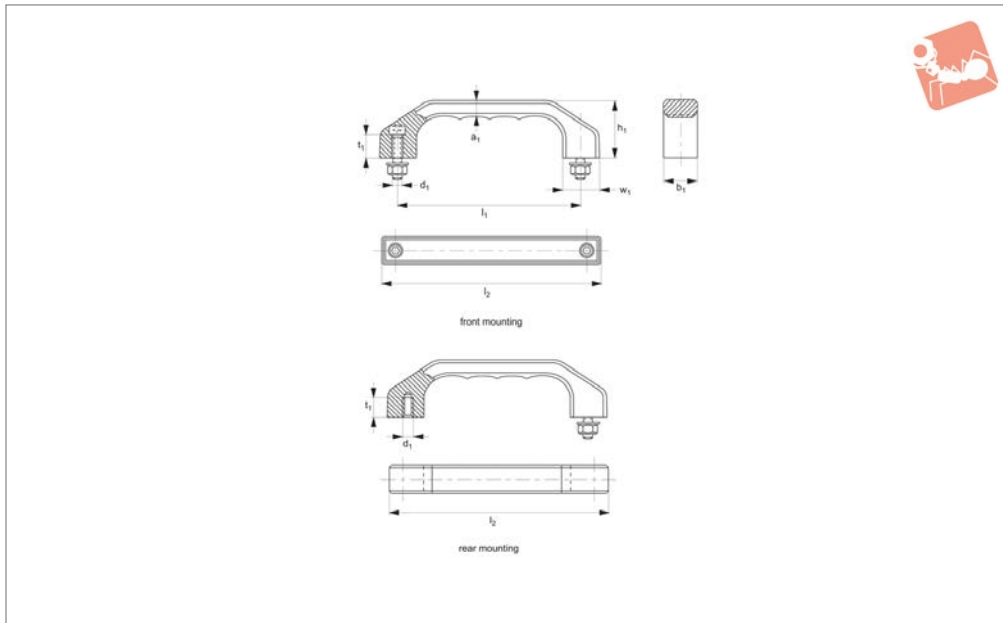

**78830**

PULL HANDLES

### Material

Stainless steel (304) precision casting (G X6 CrNi 18 9, material no. G4308). Finish: blasted and electropolished with a semi-

matt finish.

### Technical Notes

Front mounting: supplied with hex screws

to DIN 912, and suitable washer and nut. Rear Mounting: supplied with hex head screws to DIN 933 and suitable washer. Minimum stress resistance >1000N.

Order No.	Type	$l_1$	$l_2$	$a_1$	$b_1$	$d_1$	$h_1$	$t_1$	$w_1$
<b>78830.W0140</b>	Front Mounting	140	170	12	25	M_8x30	45	15	28
<b>78830.W0180</b>	Front Mounting	180	218	15	32	M10x40	58	18	36
<b>78830.W0540</b>	Rear Mounting	140	170	12	25	M_8x18	45	15	28
<b>78830.W0580</b>	Rear Mounting	180	218	15	32	M10x20	58	18	36