




Pull Handles - Heavy Duty

stainless steel and aluminium

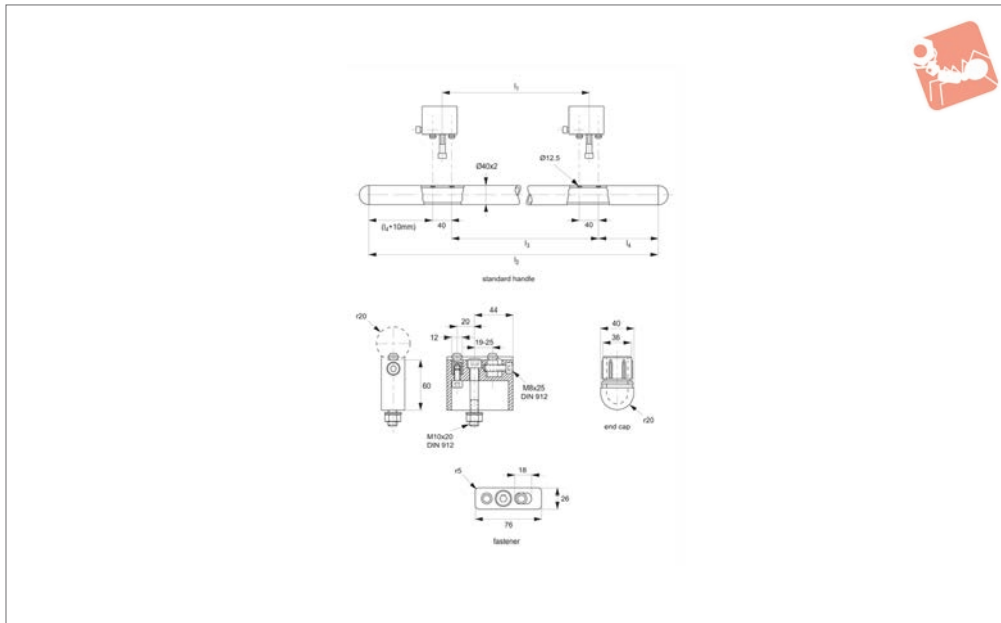

79410

PULL HANDLES

Material

Connection shank: die-cast aluminium, black powder coated, silk matte.
Connection tube: stainless steel 1.4301, $\varnothing 40 \times 2$, precision ground.
End cap: polyamide (PA 6), glass ball reinforced, black, silk matte.

Technical Notes

Simplest fixing of components from the front. The same length handle can be fixed at any support spacing.
Minimum stress resistance $> 1000N$.

Tips

Heavy-duty pipe handles for mechanical and process equipment engineering purposes. Part nos. 79410.W0380 to .W0700 supplied complete with two fasteners and end caps.

Order No.	Type	l_1	l_2	l_3	l_4
79410.W0380	Handle	380	600	380	85
79410.W0480	Handle	480	700	480	85
79410.W0500	Handle	500	800	500	125
79410.W0600	Handle	600	900	600	125
79410.W0700	Handle	700	1000	700	125
79410.W0901	Fastener	-	-	-	-
79410.W0902	End Cap	-	-	-	-