




Hinged Carrying Handle

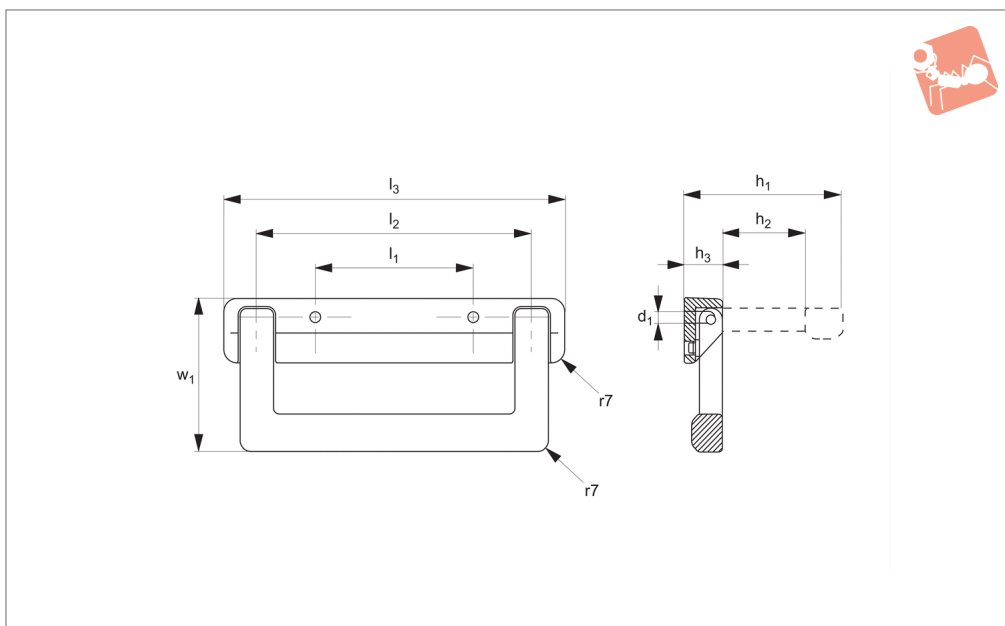

79582

PULL HANDLES

Material

Holder & handle: die-cast aluminium GD-ALSi9Cu3 (alloy 226). Powder coated, half matt in black (similar to RAL 9005) or orange (RAL 2009).

Arbors & restoring springs: stainless steel.
Self-acting resilient handle made of aluminium for backside screw mounting.

Technical Notes

Stress resistance: min. 800N.
Screw attachment from the front available on request. Other colour combinations available on request.

Order No.	Type	l_1	l_2	l_3	d_1	h_1	h_2	h_3	w_1
79582.W0145	Black	84	145	180	M 6	83	44	20	80
79582.W1145	Orange	84	145	180	M 6	83	44	20	80