 



# Square Drive Socket T-Wrench

standard - female



## Hex Keys & Wrenches

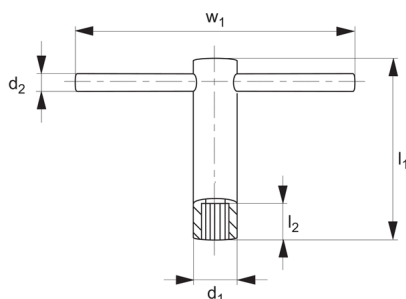

92000

HEX KEYS & WRENCHES

### Material

Steel (C35/C45).

Body and socket: tempered, hardened and

brown finish.

### Technical Notes

Produced to DIN 904.

| Order No.   | A/F | d <sub>1</sub> | d <sub>2</sub> | l <sub>1</sub> | l <sub>2</sub> | w <sub>1</sub> | Weight<br>g |
|-------------|-----|----------------|----------------|----------------|----------------|----------------|-------------|
| 92000.W0004 | 4   | 12.0           | 6.0            | 60             | 11             | 160            | 85          |
| 92000.W0005 | 5   | 12.0           | 6.0            | 60             | 11             | 160            | 85          |
| 92000.W0006 | 6   | 12.0           | 6.0            | 80             | 12             | 160            | 100         |
| 92000.W0007 | 7   | 14.6           | 6.0            | 80             | 15             | 160            | 130         |
| 92000.W0008 | 8   | 16.0           | 9.0            | 80             | 15             | 180            | 180         |
| 92000.W0009 | 9   | 18.0           | 9.0            | 100            | 18             | 180            | 245         |
| 92000.W0010 | 10  | 20.0           | 11.0           | 100            | 18             | 200            | 340         |
| 92000.W0012 | 12  | 24.0           | 12.0           | 100            | 21             | 250            | 520         |
| 92000.W0013 | 13  | 24.0           | 12.0           | 100            | 22             | 250            | 520         |
| 92000.W0014 | 14  | 28.0           | 14.6           | 120            | 24             | 320            | 875         |
| 92000.W0017 | 17  | 34.0           | 16.0           | 160            | 28             | 400            | 1625        |
| 92000.W0019 | 19  | 36.0           | 16.0           | 200            | 30             | 400            | 2035        |
| 92000.W0022 | 22  | 42.0           | 18.0           | 200            | 34             | 500            | 2900        |
| 92000.W0024 | 24  | 45.0           | 20.0           | 250            | 36             | 630            | 4270        |