


Face Spanner - with Pins adjustable

Spanners & Hook Spanners

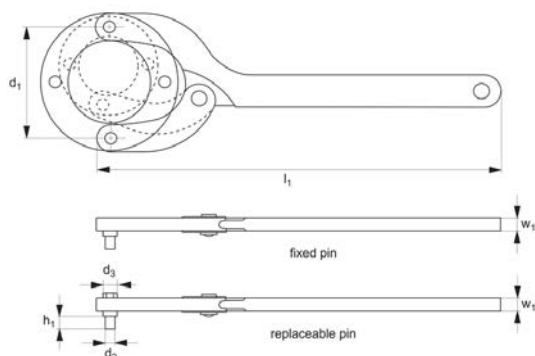

95350

SPANNERS & HOOK SPANNERS

Material

Steel (C35/C45), tempered and blackened.

welded.

For replacement pins see part no. 95360.

Technical Notes

Fixed or replaceable pins, fixed pin spot

Order No.	Type	d_1 for nut Ø	d_2 -0.1 tol. h12	d_3	h_1	l_1	w_1	Weight g
95350.W0041	Fixed Pin	18-40	3	-	4.0	150	5	100
95350.W0042	Fixed Pin	18-40	4	-	5.0	150	5	100
95350.W0081	Fixed Pin	40-80	4	-	5.0	220	6	265
95350.W0082	Fixed Pin	40-80	5	-	6.0	220	6	265
95350.W0083	Fixed Pin	40-80	6	-	7.0	220	6	265
95350.W0125	Fixed Pin	80-125	6	-	7.0	295	8	650
95350.W0126	Fixed Pin	80-125	7	-	7.5	295	8	650
95350.W0127	Fixed Pin	80-125	8	-	8.0	295	8	650
95350.W0201	Fixed Pin	125-200	8	-	8.0	405	10	1590
95350.W0202	Fixed Pin	125-200	10	-	10.0	405	10	1590
95350.W0541	Replaceable Pin	18-40	3	M 4	4.0	150	5	100
95350.W0542	Replaceable Pin	18-40	4	M 4	5.0	150	5	100
95350.W0581	Replaceable Pin	40-80	4	M 6	5.0	220	6	265
95350.W0582	Replaceable Pin	40-80	5	M 6	6.0	220	6	265
95350.W0583	Replaceable Pin	40-80	6	M 6	7.0	220	6	265
95350.W0625	Replaceable Pin	80-125	6	M 6	7.0	295	8	650
95350.W0626	Replaceable Pin	80-125	7	M 6	7.5	295	8	650
95350.W0627	Replaceable Pin	80-125	8	M 6	8.0	295	8	650
95350.W0701	Replaceable Pin	125-200	8	M 8	8.0	405	10	1590
95350.W0702	Replaceable Pin	125-200	10	M 8	10.0	405	10	1590