




Cam Latches - 3A Standard

hygienic line, stainless steel

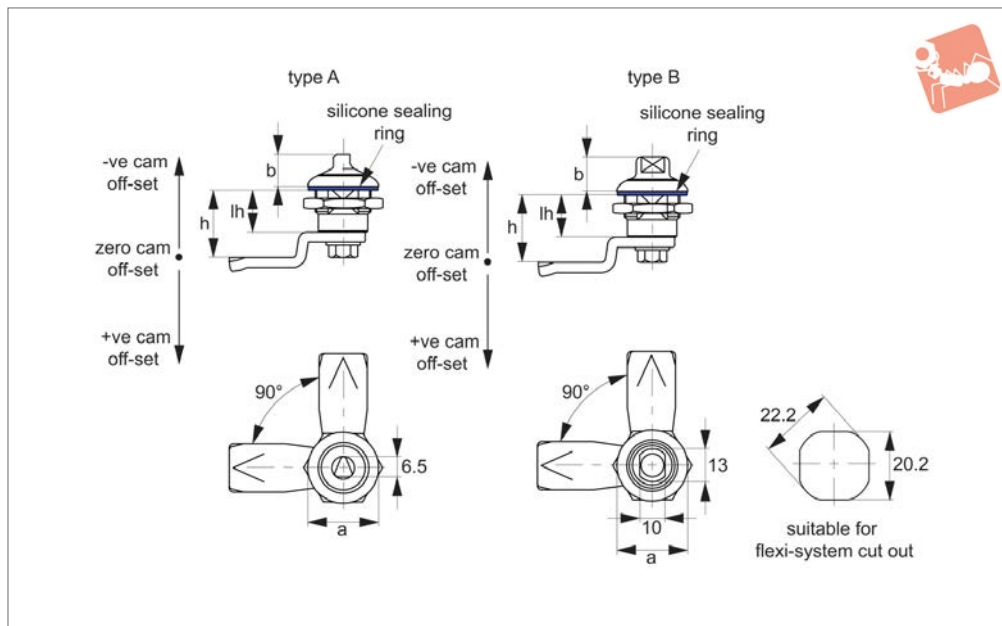

A1104

CAM LATCHES

Material

Body: Stainless steel AISI304

Handle: Stainless steel AISI304

Blue gasket: silicone

Gaskets provide IP69K rating.

Supplied with: Nut and screw: Stainless steel AISI304

Not Supplied: CAM nor KEY - order separately.

Technical Notes

Order cam and key separately.

Cams: see suitable cam A0203 (steel) and

A0210 (Stainless Steel)

A0224 and A0240.

Select „without projection“ cam type.

Dimensions ch and cl relate to cam.

Use formula to calculate ch (required cam off-set), and refer to cam selection chart; $ch = h - lh$ where;

ch = required cam off-set/height.

H = grip length (distance between inside of latch face and front of cam).

lh = body length of cam latch/lock to be used (see product table below).

Keys: see A0104.

Tips

Made to the high „3A“ standard.

This ensures it meets the high standards required for use in food, beverage, pharmaceutical and medical applications.

Hygienically designed for effective and easy cleaning, corrosion resistant, non-toxic.

Design precludes contamination by dirt, food particles and organic matter.

Order No.	Insert driver	a	b	lh
A1104.AW0010	triangle 7	28	13	18
A1104.AW0110	Stadium	28	13	18