




# Cam Latches - Flexi-System

insert driver - fixed grip - zinc



## Cam Latches

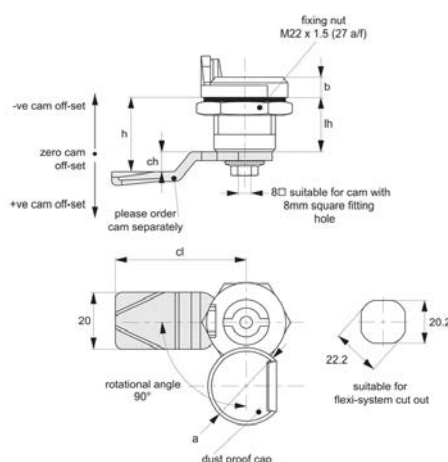

# A1168

CAM LATCHES

### Material

Body & Insert: die cast zinc, bright chrome plated. Insert fitted with O'ring to achieve IP54 rating.

### Supplied with:

Cap: dust-proof.

**Not supplied:** CAM nor KEY - order separately.

### Technical Notes

Order cam and key separately.

**Cams:** see suitable cam A0203, A0224 and A0240. Select „without projection“ cam type.

Dimensions  $ch$  and  $cl$  relate to cam. Use formula to calculate  $ch$  (required cam off-set), and refer to cam selection chart;

$ch = h - lh$  where;

$ch$  = required cam off-set/height.

$h$  = grip length (distance between inside of latch face and front of cam).

$lh$  = body length of cam latch/lock to be used (see product table below).

**Keys:** see A0102.

**Rods & Guides:** to achieve 3-point latching - A0303, A0321, A0325.

### Tips

Quarter turn opening or closing.

Order No.	Insert driver	a	b	lh
A1168.AW0007	Square 7	29	6.5	18
A1168.AW0008	Square 8	29	6.5	18
A1168.AW0017	Triangle 7	29	6.5	18
A1168.AW0018	Triangle 8	29	6.5	18
A1168.AW0103	3mm Double Bit	29	6.5	18
A1168.AW0104	4mm Double Bit	29	6.5	18
A1168.AW0124	Slotted (2x4)	29	6.5	18