




# Cam Latches - Flexi-System

tamper evident - for wire or cable tie - zinc



## Cam Latches

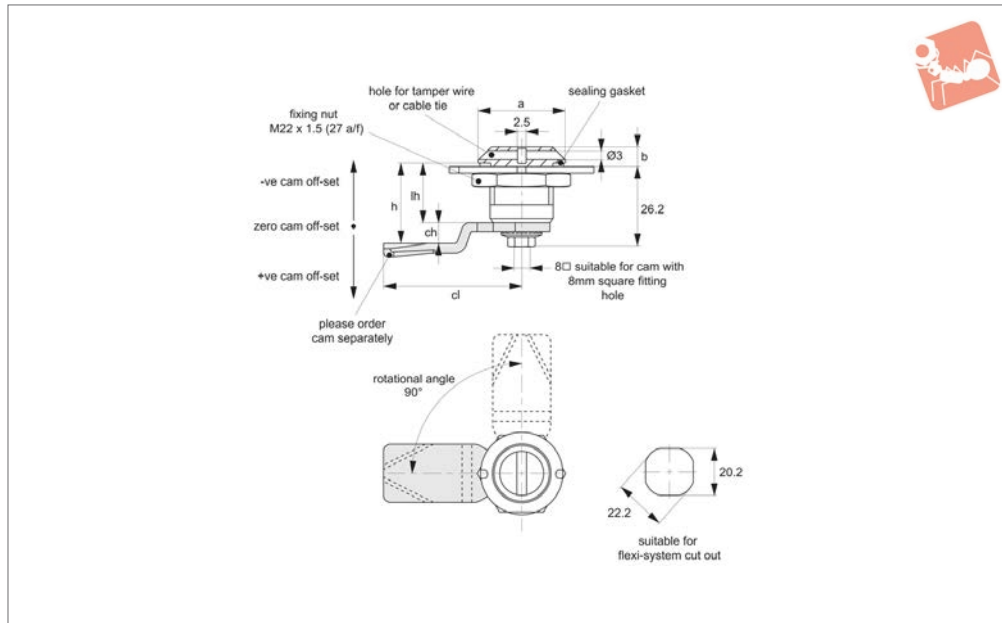

### A1210

CAM LATCHES

#### Material

Body & Insert: die cast zinc, bright chrome plated.

**Supplied With:** Nut: steel.

**Not supplied:** CAM - order separately.

#### Technical Notes

Order cam and key separately.

**Cams:** see suitable cam A0203, A0224 and

A0240. Select „without projection“ cam type.

Dimensions ch and cl relate to cam. Use formula to calculate ch (required cam off-set), and refer to cam selection chart;

**ch** = **h** - **lh** where;

**ch** = required cam off-set/height.

**h** = grip length (distance between inside of

latch face and front of cam).

**lh** = body length of cam latch/lock to be used (see product table below).

**Keys:** see A0102.

**Rods & Guides:** to achieve 3-point latching - A0303, A0321, A0325.

#### Tips

Quarter-turn opening or closing.

| Order No.    | a  | b   | lh |
|--------------|----|-----|----|
| A1210.AW0028 | 28 | 6.5 | 20 |