


# Swing Handles - Cam Control

40mm euro cylinder lock - dust proof cover - plastic

## Swing Handles

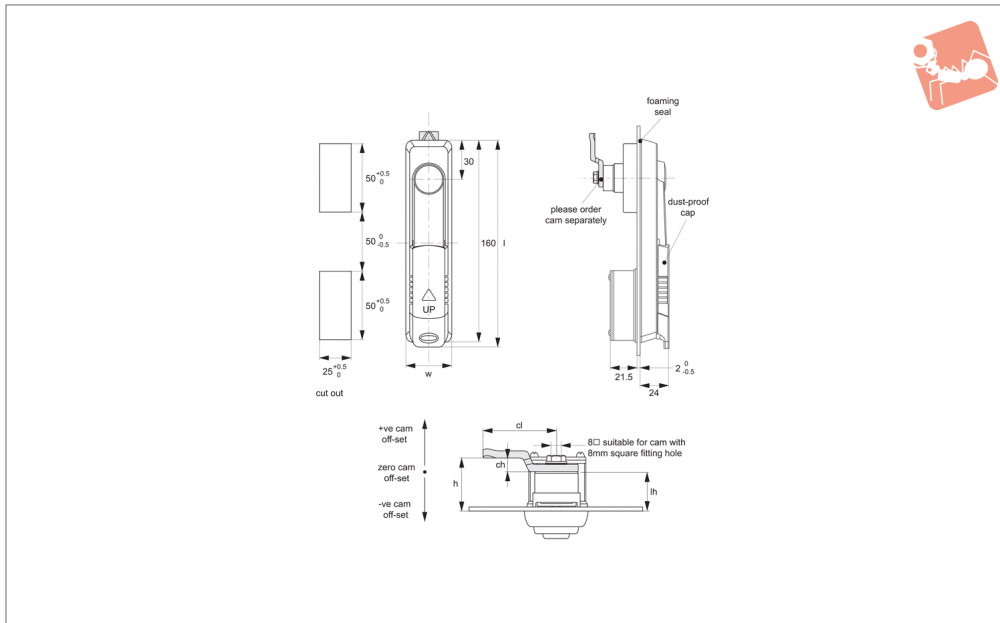

**B1092**

SWING HANDLES

### Material

Body & Handle: polyamide, PA6, black.  
Cylinder lock: die cast zinc, chrome plated.  
**Supplied with:** Keys: two per lock.  
**Not supplied:** Cam: order separately.

### Technical Notes

Order cam separately.  
**Cams:** see suitable cam A0203, A0224 and A0240. Select „without projection“ cam

type.  
Dimensions ch and cl relate to cam. Use formula to calculate ch (required cam off-set), and refer to cam selection chart;  
**ch = h - lh** where;  
**ch** = required cam off-set/height.  
**h** = grip length (distance between inside of latch face and front of cam).  
**lh** = body length of cam latch/lock to be

used (see product table below).  
**Rods & Guides:** to achieve 3-point latching - A0303, A0321, A0325.

### Tips

Ideal for electrical cabinets, telecom racks or enclosures max. panel thickness of 2mm. For use inside of cabinet gasket. Universal left/right.

Order No.	Finish	Lock type	Key type	l	w	lh
<b>B1092.AW0010</b>	Black, Plastic	40 Euro	Keyed Alike	165	35	16

