




# Push Knobs no latch

# Catches & Latches

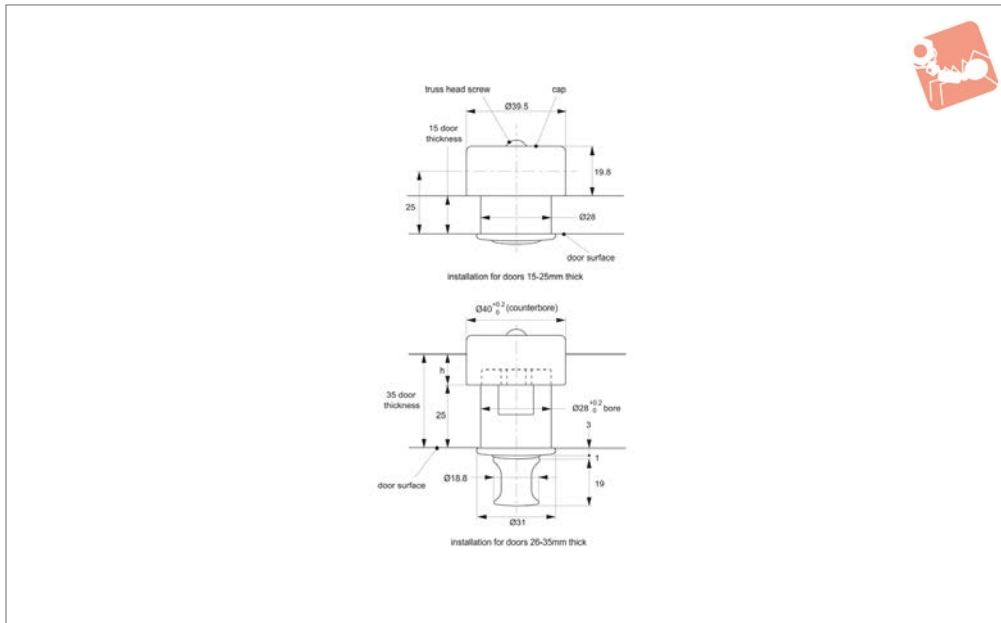

**E0300**

**Material**

Push knob: zinc alloy, plated gold or chrome.  
Body: ABS plastic, black.

35mm.

When installed push knob is near flush with surface, raised only 4mm.  
Supplied with screws (M 3x20).

bore is required.

For surfaces 26 to 35mm thick, 40mm dia. counter bore of depth „h“ is required.  
h = door thickness - 25mm.

**Technical Notes**

Suitable for door/wall thicknesses 15 to

**Tips**

For surfaces 15 to 25mm thick no counter

Order No.	Finish	Weight g
E0300.AC0030	Gold	67
E0300.AC0040	Chrome	67

