


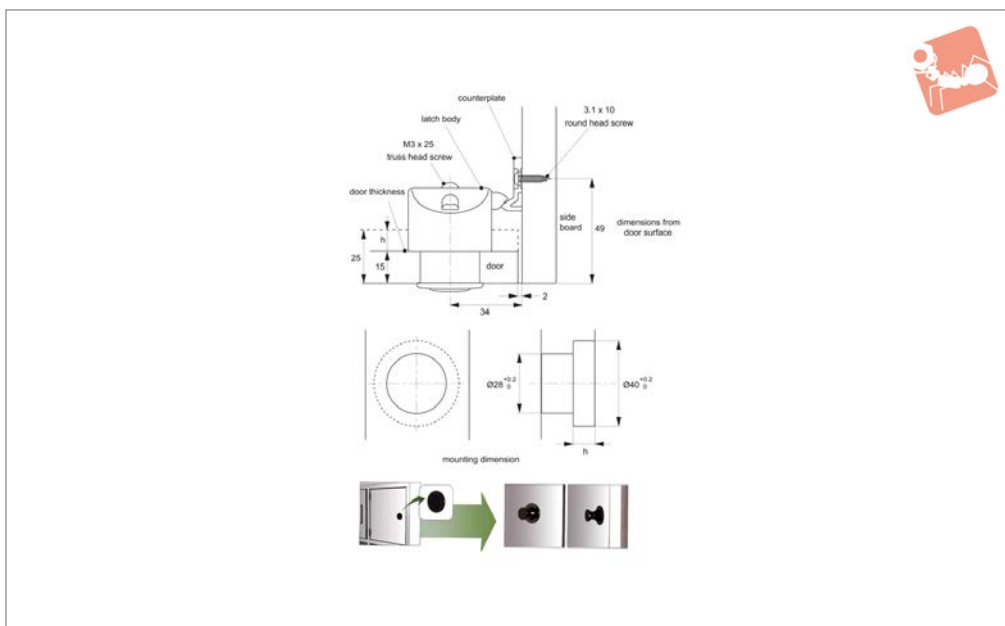

Push Knobs with latch - for inset doors

Catches & Latches



E0800

CATCHES & LATCHES

Material

Push knob: zinc alloy.
Body and catch plate: ABS plastic, black.

Technical Notes

Suitable for door/wall thicknesses 15 to 30mm. For 13mm door use a 2mm plastic spacer (order separately).
When installed the push knob is near flush, raised only 4mm from surface.
Supplied with screws (M 3.1x10 and M

3.1x28), and catch plate.

Tips

To operate the push knob:

Step 1: door closed, latch is engaged.

Step 2: depress knob to flush position to lock.

Step 3: depress knob to the out position to unlock latch.

For surfaces between 15 to 25mm thick no

counter bore is required.

For surfaces from 26 to 35mm thick, 40mm dia. counter bore of depth „h“ is required.
h = door thickness - 25mm.

Important Notes

Do not activate the latch before closing the door, it may damage the unit.
Other dimensions as per E0300 <X\ E0300#24>. See diagram for mounting dimensions.

Order No.	Finish	Description	Holding force kg	Weight g
E0800.AC0030	Gold	Push Knob	10	93
E0800.AC0040	Chrome	Push Knob	10	93
E0800.AC0050	Black Nickel	Push Knob	10	93
E0800.AC0720	Black	Spacer 2mm	-	2

