


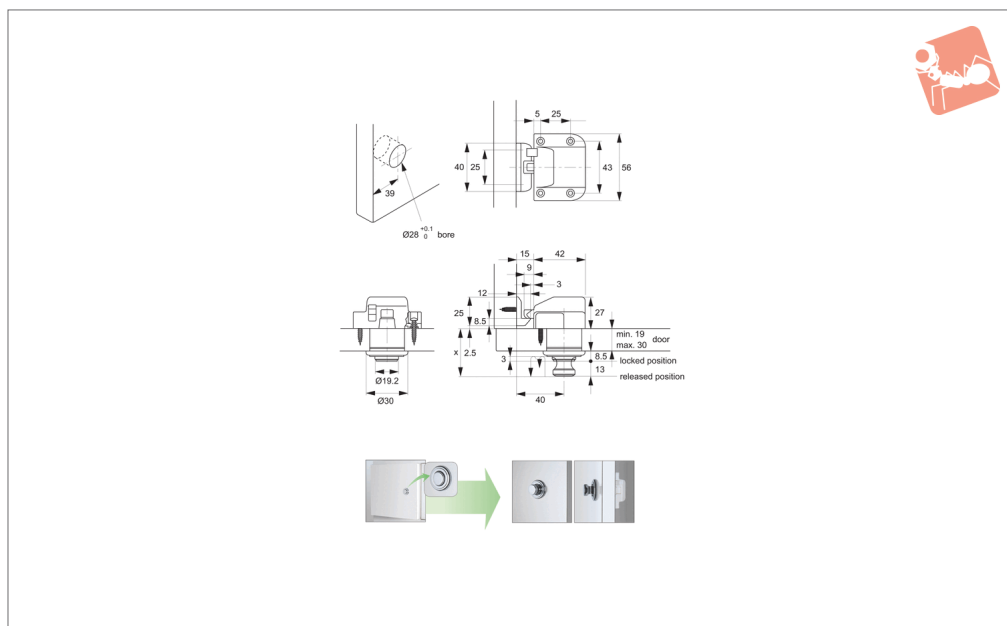

Push Knobs with latch - for overlay doors

Catches & Latches



E1400

CATCHES & LATCHES

Material

Push button: brass, finished in chrome, satin nickel, satin or polished brass plating.

Push button base: zinc alloy.

Latch body and catch: polyamide.

Technical Notes

Suitable for door thicknesses 19 to 30mm.

Supplied with stainless steel screw (3x16, 3x20).

Important Notes

For correct positioning of push knob from the door surface refer to dimension „x“ on installation diagram.

„x“ is calculated as:

$x = \text{door thickness} + 21,5\text{mm}$

Push knob supplied with two threaded studs of 24mm and 30mm, interchange of stud enables correct positioning of knob to door surface, i.e. dimension „x“.

| Order No. | Finish | Holding force kg | Weight g |
|--------------|----------------|---------------------|-------------|
| E1400.AC0040 | Chrome | 20 | 103 |
| E1400.AC0060 | Satin Nickel | 20 | 103 |
| E1400.AC0070 | Satin Brass | 20 | 103 |
| E1400.AC0080 | Polished Brass | 20 | 103 |

