


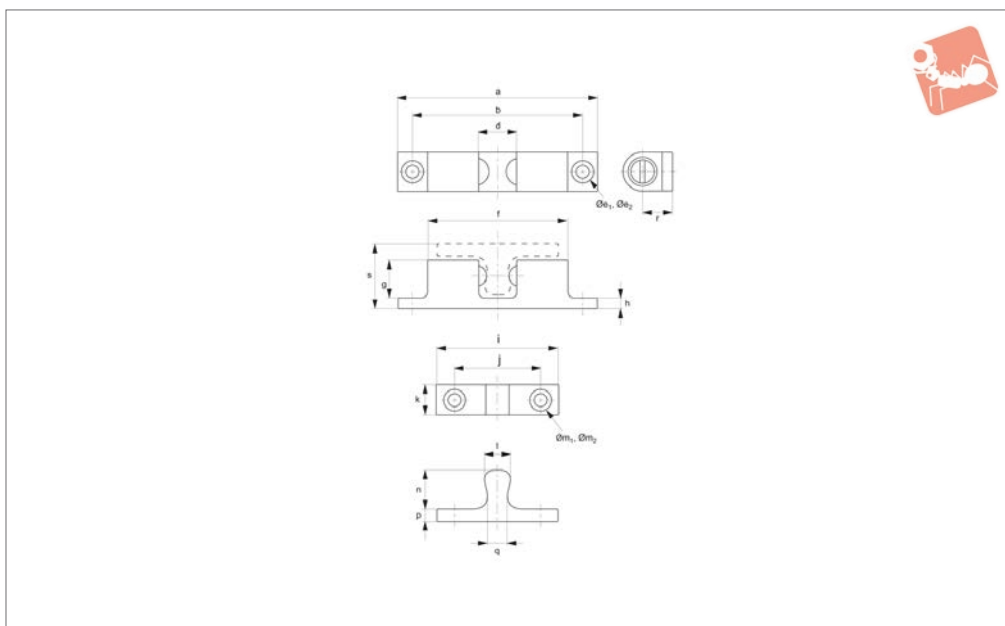

E4000

Material

Body: zinc alloy, chrome finish.
Ball: ball bearing stainless steel.

Order No.	Push in force kgf		Pulling force kgf		a	b	c	d	Ø e ₁	Ø e ₂	Weight g			
E4000.AC0040	4.4		3.0		42.5	35	8.0	6.3	3.2	6.2	16			
E4000.AC0050	4.1		3.3		50.0	40	10.0	8.4	4.2	8.2	26			
E4000.AC0070	4.6		3.5		70.0	60	13.5	13.0	4.2	8.2	70			

Order No.	f	g	h	i	j	k	l	Ø m ₁	Ø m ₂	n	p	q	r	s
E4000.AC0040	26.7	7.5	2.5	25	16	7.5	5.5	3.2	6.2	8.8	2.5	3.7	6.5	14.0
E4000.AC0050	29.8	9.5	3.0	30	20	9.0	7.3	4.2	8.2	9.8	2.5	4.7	7.4	16.0
E4000.AC0070	49.0	13.0	4.0	42	30	10.5	11.0	4.2	8.2	14.2	3.0	8.2	11.0	21.2