


Toggle Clamps - Horizontal Acting

economy - horizontal base - open arm

Economy Toggle Clamps

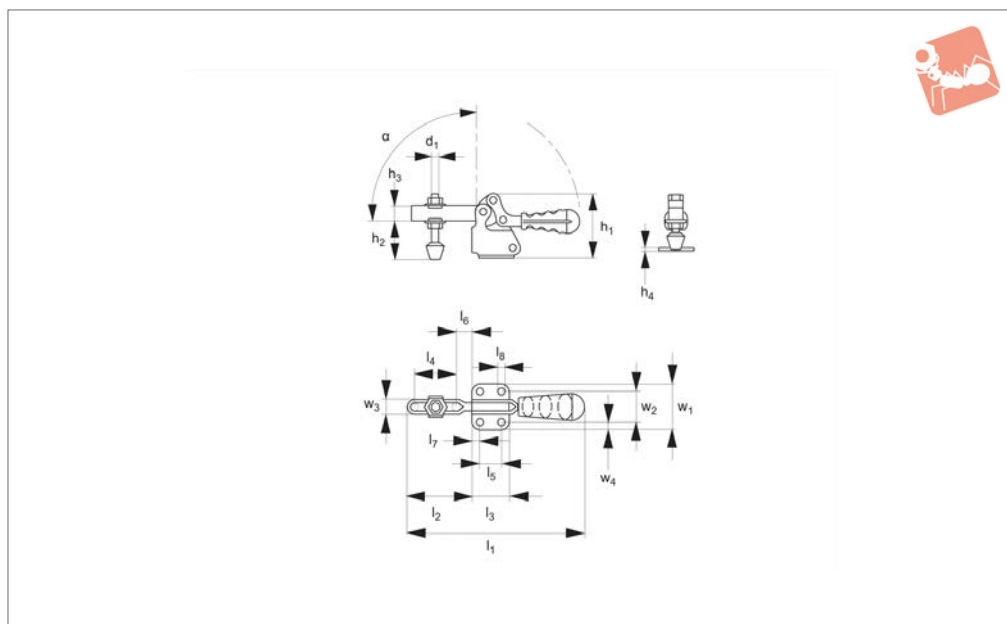

EC630

ECONOMY TOGGLE CLAMPS

Material

Body: steel, zinc plated.

Bushes: case hardened and greased.

Handle: plastic, red, oil resistant.

Supplied complete with clamping screw
(with rubber pad).

Order No.	Size	Holding force kN	d_1	d_2	h_1	h_2	h_3	h_4	l_1	Weight g
EC630-1	1	0.7	M 5	5.2	38.2	19	9.5	2.0	105	70
EC630-2	2	0.9	M 6	5.5	52.6	25	14.0	2.5	162	230
EC630-3	3	2.2	M 8	6.6	68.5	34	17.5	3.0	189	430
EC630-4	4	3.4	M10	8.7	90.0	45	23.8	4.0	269	910

Order No.	l_2	l_3	l_4	l_5	l_6	l_7	w_1	w_2	w_3	w_4	α
EC630-1	36.8	25	20.0	13.5	12.0	5.7	27	19	5.8	-	94°
EC630-2	61.4	38	36.5	26.0	19.0	6.0	40	28	6.2	3.0	96°
EC630-3	66.3	42	36.8	26.0	22.0	8.0	47	31	9.0	2.5	96°
EC630-4	103.0	59	64.8	41.2	28.5	9.0	59	43	11.4	1.8	95°