




# Toggle Latches

with padlock shackle, **stainless steel**

## Draw Latches

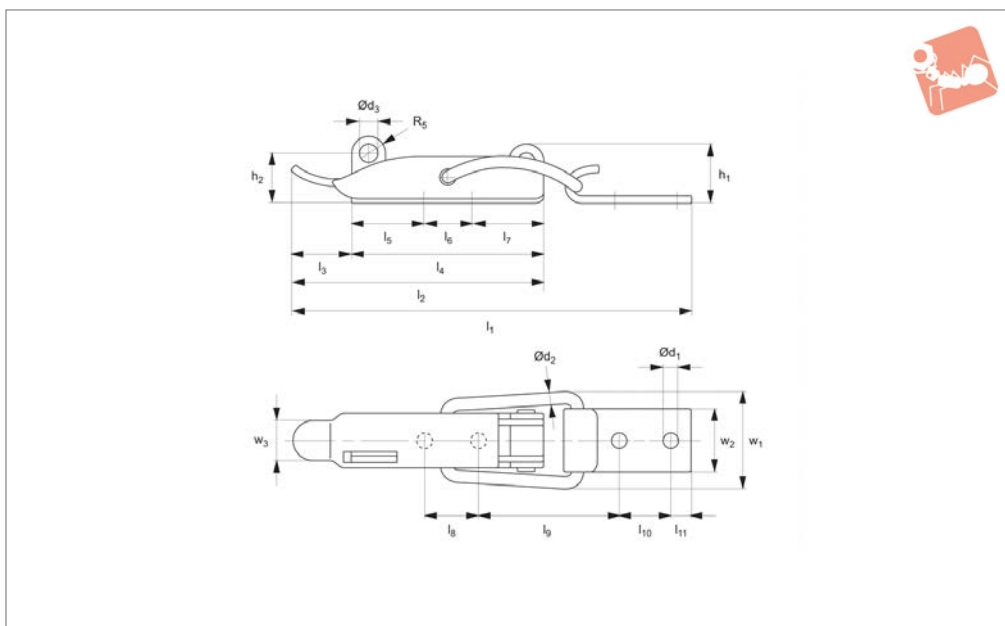

**J0552**

DRAW LATCHES

### Material

Steel, Fe P02 + P12, UNI5866, zinc plated.  
Or stainless steel AISI304, UNI x5crNi.

### Technical Notes

Supplied with counter strike. Use a padlock  
of 5,5mm dia. or less.

| Order No.    | Finish            | $l_1$ | $h_1$ | $w_1$ | $\varnothing d_1$ | $\varnothing d_2$ | $\varnothing d_3$ | $h_2$ | $l_2$ | $l_3$ | $l_4$ | Weight<br>g |
|--------------|-------------------|-------|-------|-------|-------------------|-------------------|-------------------|-------|-------|-------|-------|-------------|
| J0552.AC0004 | Zinc Plated Steel | 114   | 17    | 28    | 4.1               | 3                 | 5.5               | 14    | 72    | 17    | 55    | 55          |
| J0552.AC0030 | Stainless Steel   | 114   | 17    | 28    | 4.1               | 3                 | 5.5               | 14    | 72    | 17    | 55    | 55          |

| Order No.    | $l_5$ | $l_6$ | $l_7$ | $l_8$ | $l_9 \pm 0.5$ | $l_{10}$ | $w_2$ | $w_3$ | $l_{11}$ | Load<br>N<br>max. | Tension<br>N<br>max. |
|--------------|-------|-------|-------|-------|---------------|----------|-------|-------|----------|-------------------|----------------------|
| J0552.AC0004 | 21    | 15.5  | 18.7  | 15.5  | 40.5          | 15       | 19    | 12    | 5        | 1000              | 2500                 |
| J0552.AC0030 | 21    | 15.5  | 18.7  | 15.5  | 40.5          | 15       | 19    | 12    | 5        | 1000              | 2500                 |