




Draw Latches

flexible - T-handle

Draw Latches

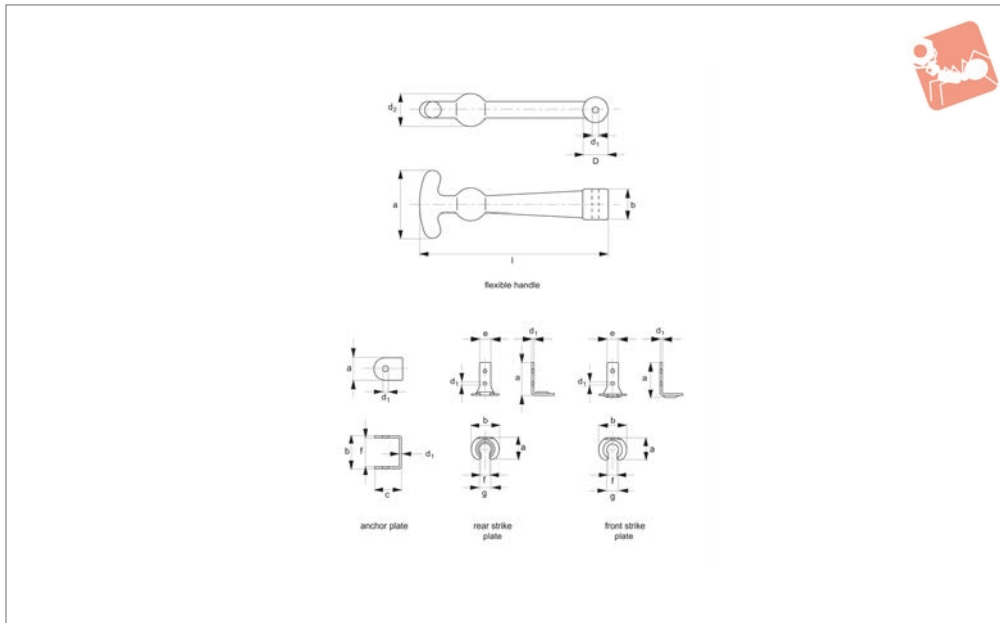

J0710

DRAW LATCHES

Material

Handle: black rubber, 65/70 shore hardness.

Anchor Plate and Strike Plate: steel, zinc plated.

Supplied with cotter pin for assembly.

Technical Notes

Flexible handle J0710.AC0148 supplied

with split cotter pin 3.2 dia x 55 long for mounting onto anchor plate.

Important Notes

Please order anchor plate and strike plate separately, to best suit your application. Front strike plate is mounted underneath the flexible handle. Rear strike plate is mounted away from the flexible handle.

| Order No. | Type | l | a | b | Ø d ₁ | Ø d ₂ | Ø d ₃ | c | e | f | g |
|--------------|--------------------|-----|----|----|------------------|------------------|------------------|----|----|----|----|
| J0710.AC0148 | Flexible Handle | 148 | 53 | 24 | 20 | 26 | 4 | - | - | - | - |
| J0710.AC0010 | Anchor Plate | - | 20 | 30 | 2 | - | 5 | 25 | - | 26 | - |
| J0710.AC0020 | Rear Strike Plate | - | 32 | 40 | 2 | - | 4 | 50 | 16 | 15 | 18 |
| J0710.AC0022 | Front Strike Plate | - | 32 | 38 | 2 | - | 4 | 44 | 16 | 15 | 18 |