


Lid Stays - Multi-Angled

heavy duty - stainless steel

Lid & Door Stays

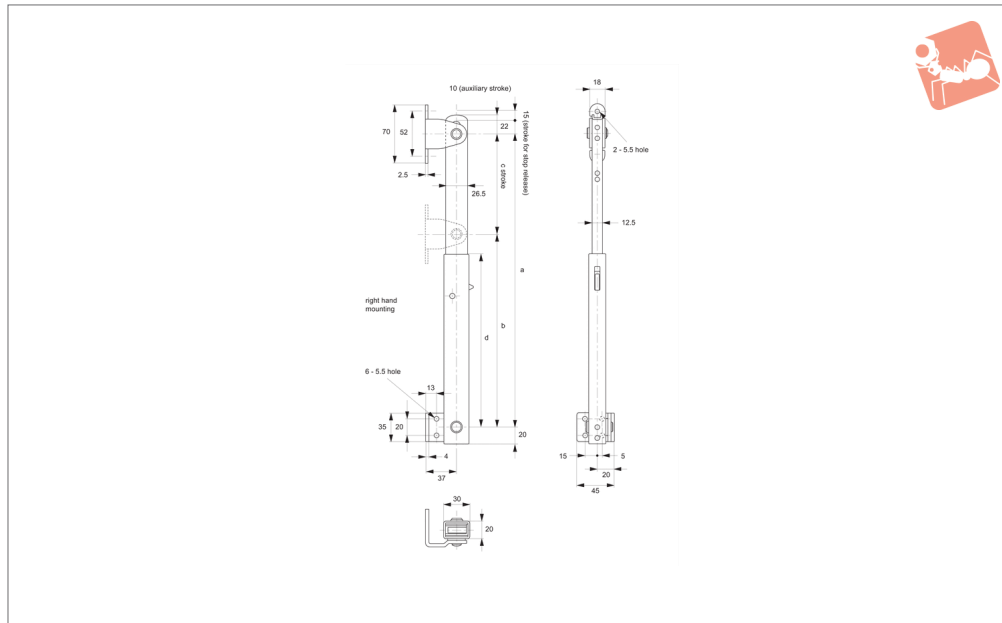

N0600

LID & DOOR STAYS

Material

Stainless steel, AISI 304, satin finish.

Technical Notes

Left or right hand specific, please refer to

table. Stay has ratchet mechanism to hold lid at multiple angles during opening motion. See 'Stop Positions' in table.

Order No.	Opening angle	Type	No. of stop positions	Stop release stroke r	a	b	c	d	Load kg max.	Weight g
	max.									
N0600.AC0010	90°	Right	4	15	350	230	120	352	70	715
N0600.AC0020	90°	Right	6	15	450	280	170	442	70	820
N0600.AC0110	90°	Left	4	15	350	230	120	352	70	715
N0600.AC0120	90°	Left	6	15	450	280	170	442	70	820

