



Lid & Door Stays




N2020

CHILD & DOOR STAYS

door closed. For mounting in the inside top panel of door.


Stay holds door in 90° open position.
When pushed to close, stay gently pulls

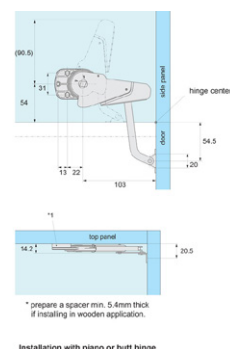




Installation

Installation dimensions

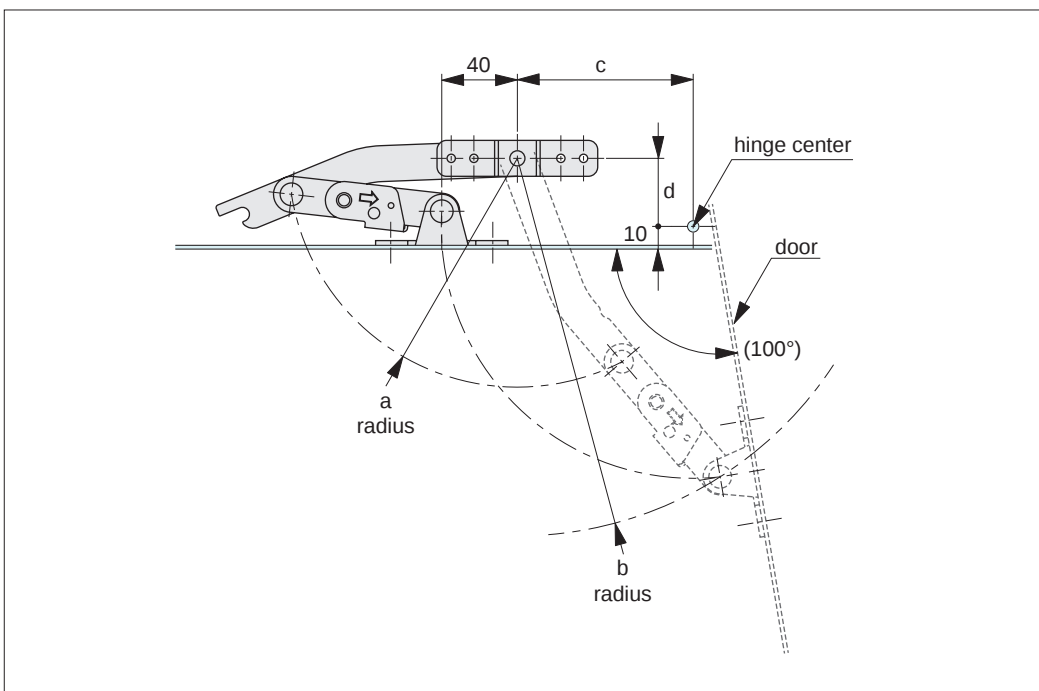


Easy actuation and release

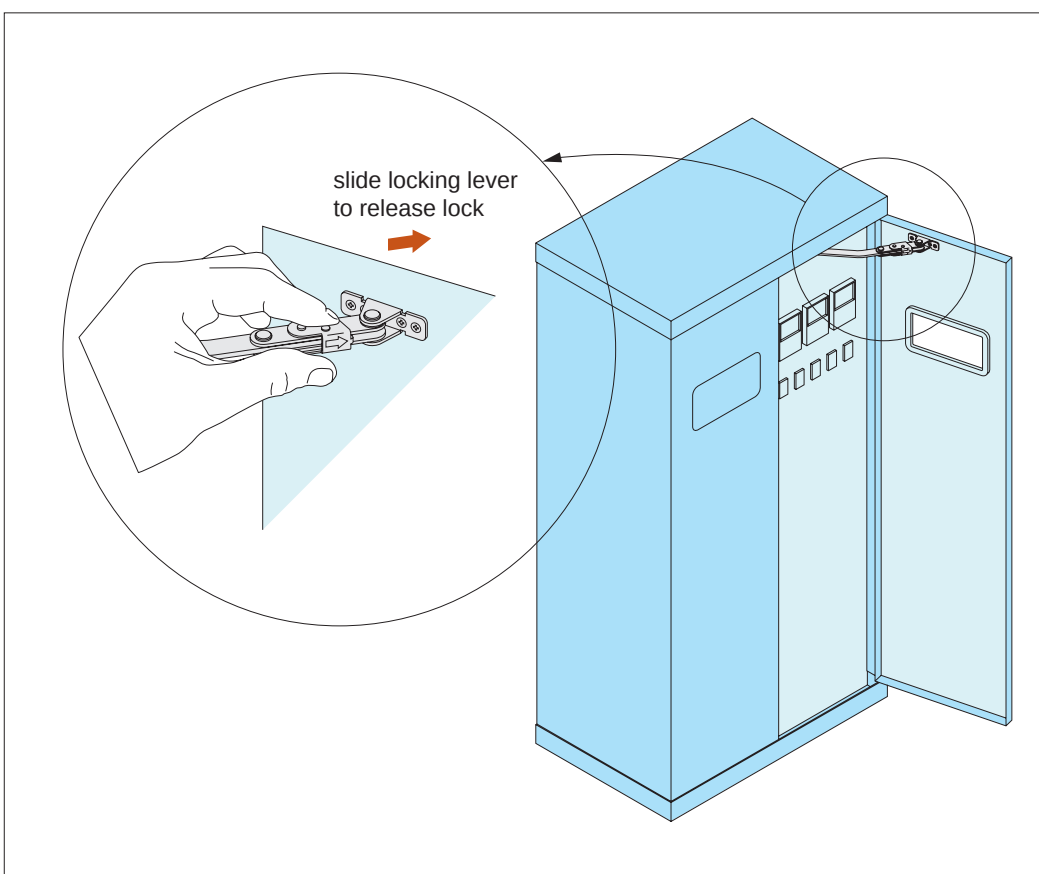



Wixroyd Door Stays

product selection charts

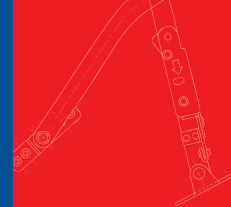

Stays


LID & DOOR STAYS

	Mounting			Door Opening			Material		Heavy Duty	Compression Force Kgf	Max Door Width mm	Tensile Force Kg	Max Angle
	Right	Left	Universal	Muti Stop	Soft Closing	Hold Open	Steel	Stainless Steel					
N2000 			✓	✓				✓			600-910		90°
N2020 	✓	✓			✓			✓		0,6-1,5	300		90°
N2050 			✓			✓	✓			50-60		50-60	100°
N2100 	✓	✓				✓		✓		50-60		150	100°
N2120 			✓			✓			✓	30		60	100°
N2200 	✓	✓				✓		✓	✓	50-60		150	100°


ov-WN2000-A-T-WN2000-A-TST05 10-door-stays-product-selection-charts-rmh- Updated -25-10-2022




Installation dimensions

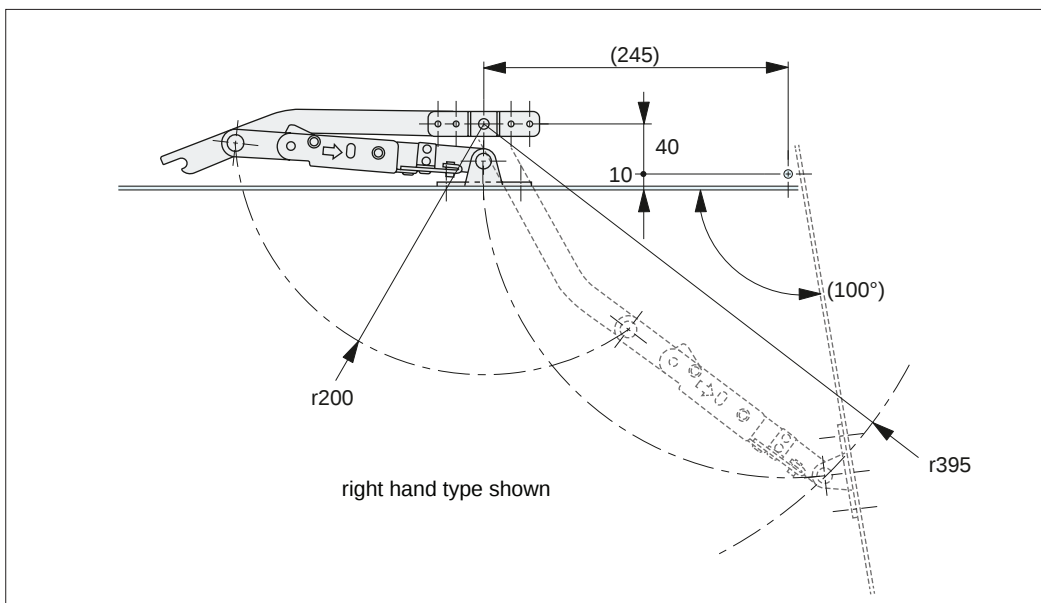

Installation of lock release wire

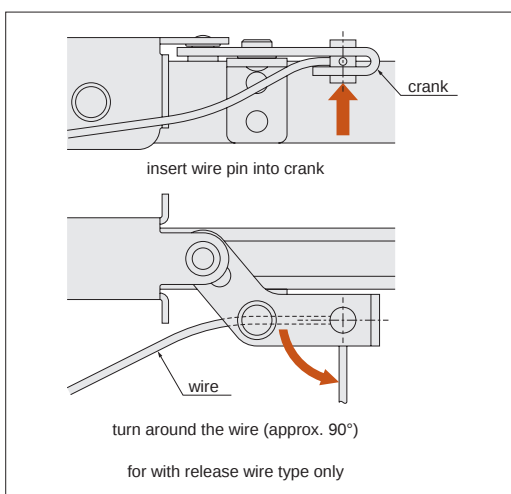

Installation of Lock Release Wire

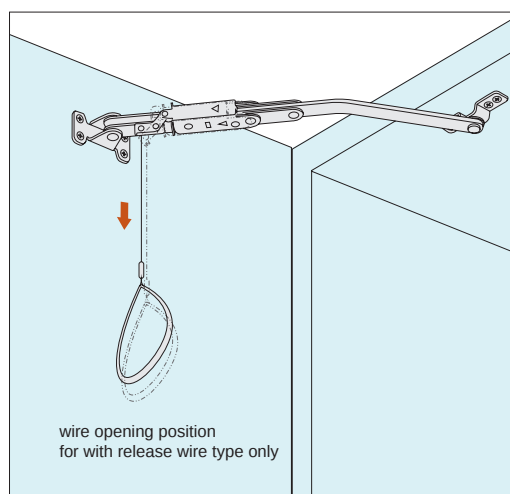


Release of Stay with Release Wire

Stay lock and release



Full Lock Out Indicator

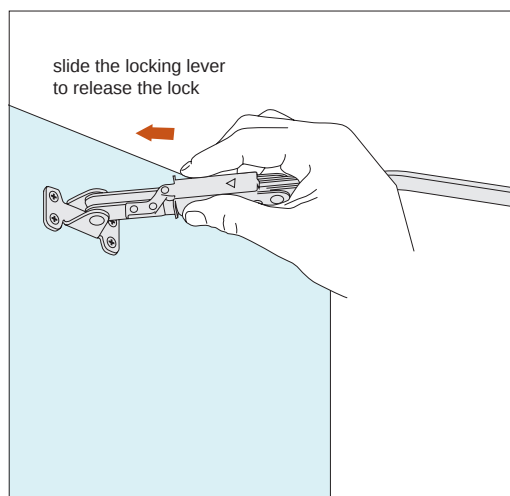

Manual Stay Release