


Door Stays - Heavy Duty

stainless steel - 100° opening

Lid & Door Stays

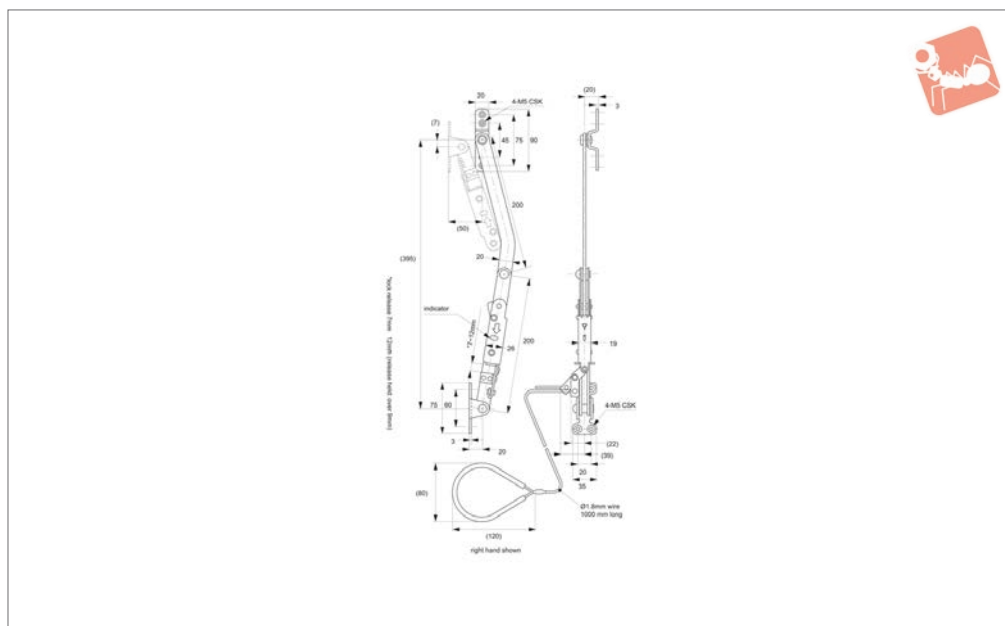

N2200

LID & DOOR STAYS

Material

All parts from stainless steel, AISI 304.

Technical Notes

Suitable for heavy duty horizontal door applications. Right and left versions

available, with or without lock release wire.

Tips

Locks automatically in open position, can be released via lock release or optional


release wire.
Easy to install.

Order No.	Type	Finish	Comp. force kg max.	Tensile force kg max.
N2200.AC0010	Right	With Release Wire	60	150
N2200.AC0020	Right	Without Release Wire	60	150
N2200.AC0110	Left	With Release Wire	60	150
N2200.AC0120	Left	Without Release Wire	60	150





Installation

Installation dimensions

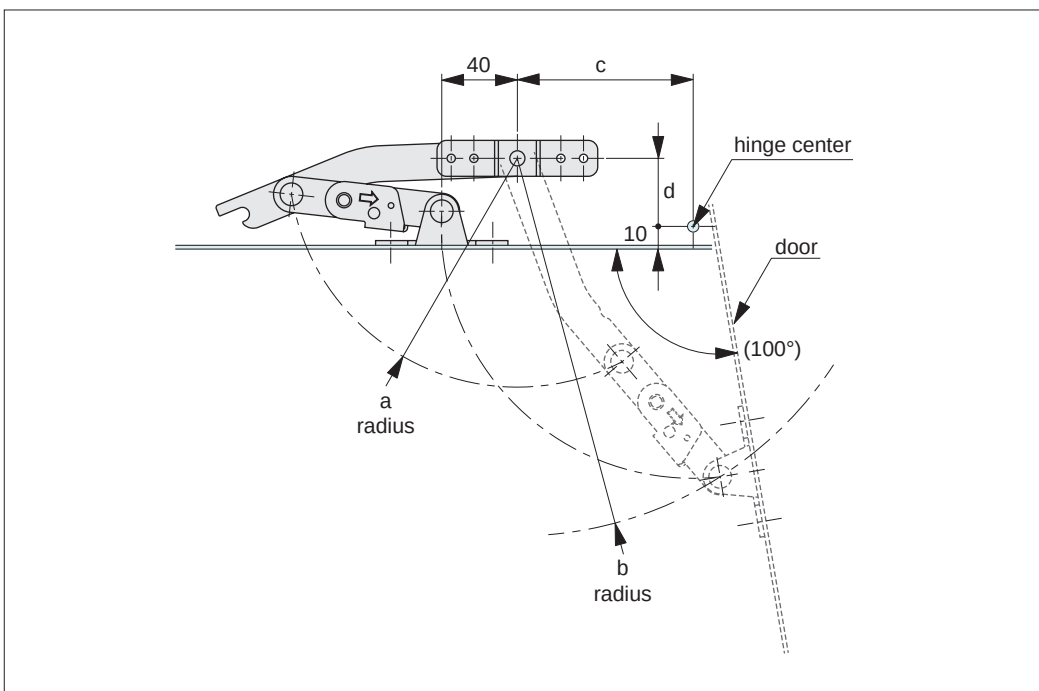

Easy actuation and release

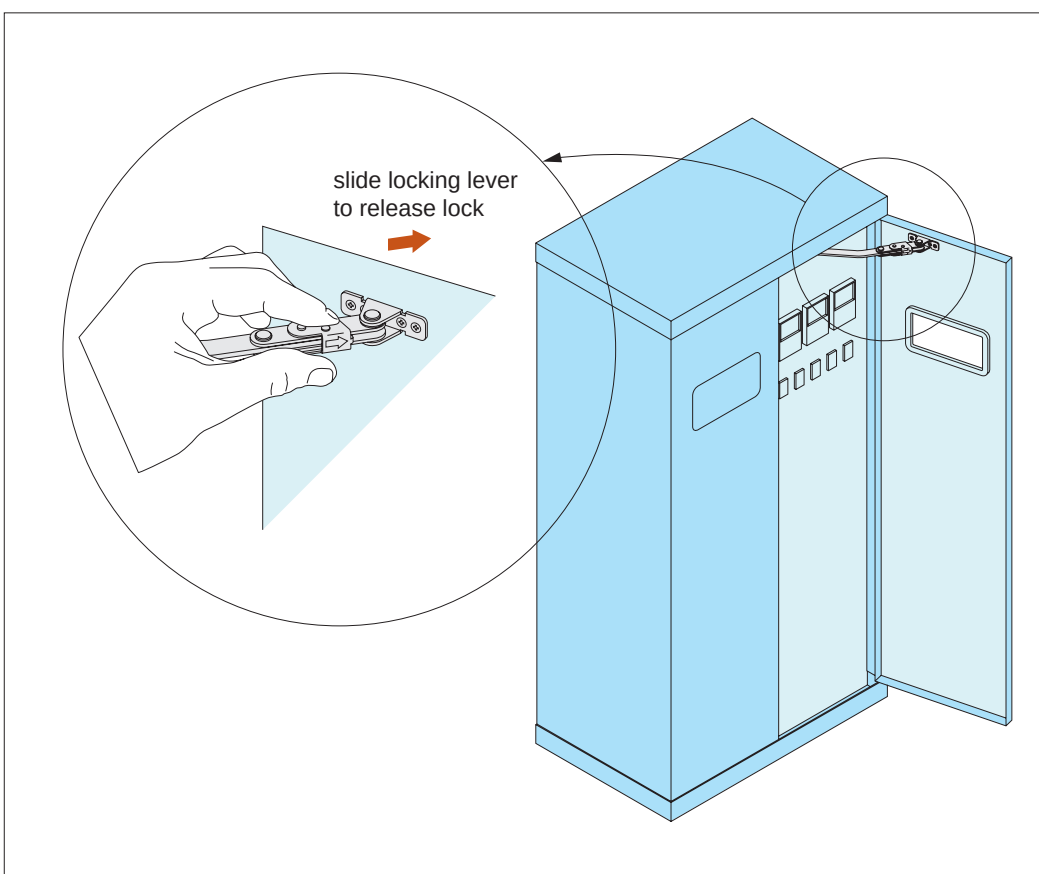

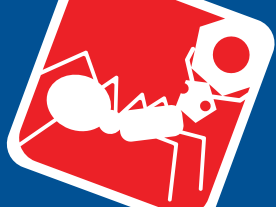

Wixroyd Door Stays

product selection charts

Stays


	Mounting			Door Opening			Material		Heavy Duty	Compression Force Kgf	Max Door Width mm	Tensile Force Kg	Max Angle
	Right	Left	Universal	Muti Stop	Soft Closing	Hold Open	Steel	Stainless Steel					
N2000 			✓	✓				✓			600-910		90°
N2020 	✓	✓			✓			✓		0,6-1,5	300		90°
N2050 			✓			✓	✓			50-60		50-60	100°
N2100 	✓	✓				✓		✓		50-60		150	100°
N2120 			✓			✓			✓	30		60	100°
N2200 	✓	✓				✓		✓	✓	50-60		150	100°

LID & DOOR STAYS


ov-WN2000-A-T-WN2200-A-TST05 10-door-stays-product-selection-charts-rmh- Updated -25-10-2022




Installation dimensions

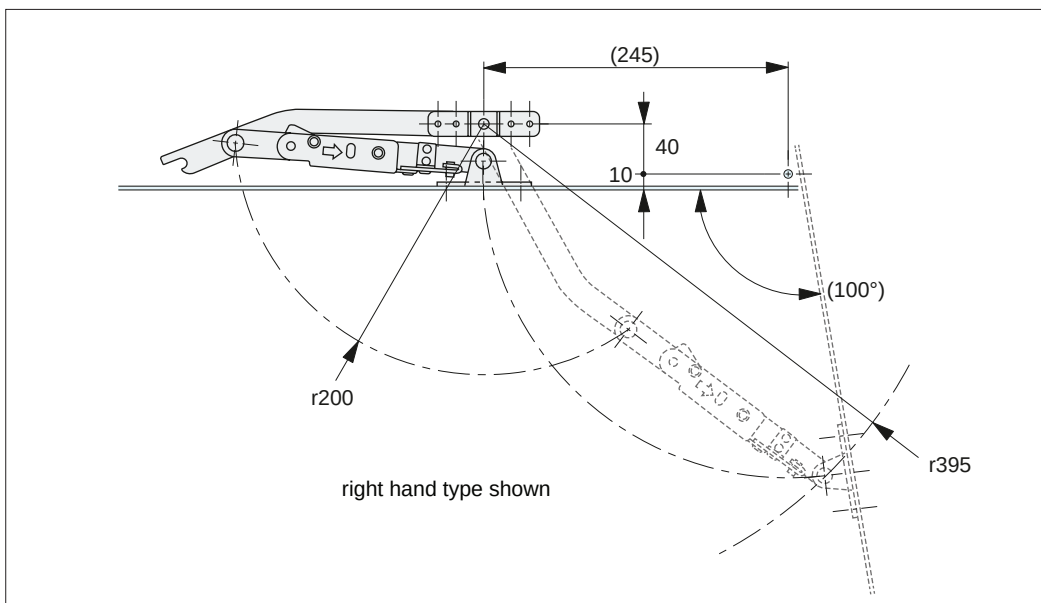

Installation of lock release wire

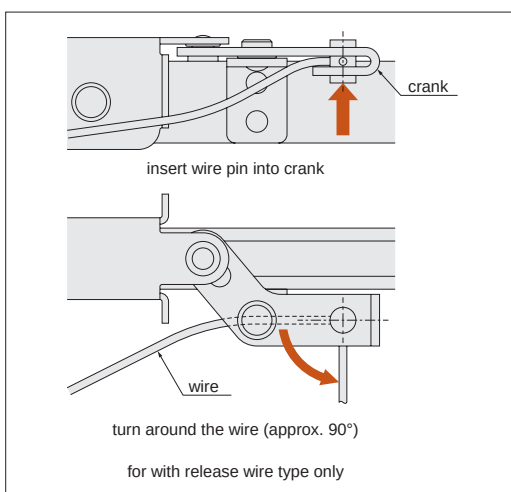

Installation of Lock Release Wire

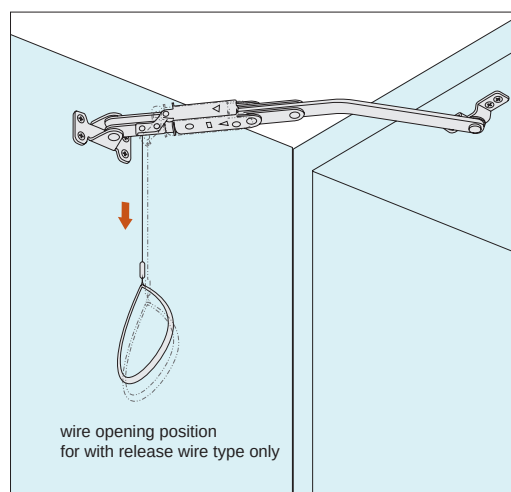


Release of Stay with Release Wire

Stay lock and release



Full Lock Out Indicator

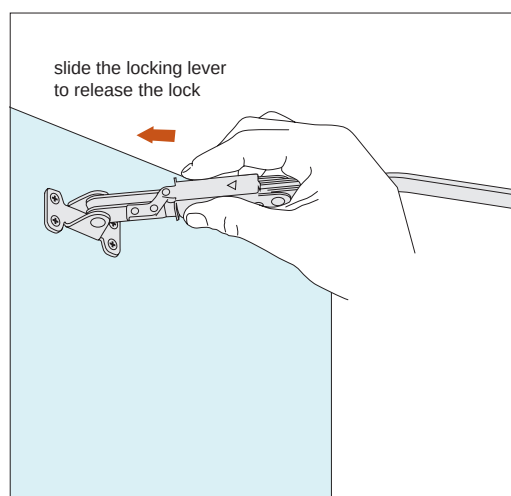

Manual Stay Release