




# Surface Mount - Double Pivot

screw mount - stainless steel



## Hinges

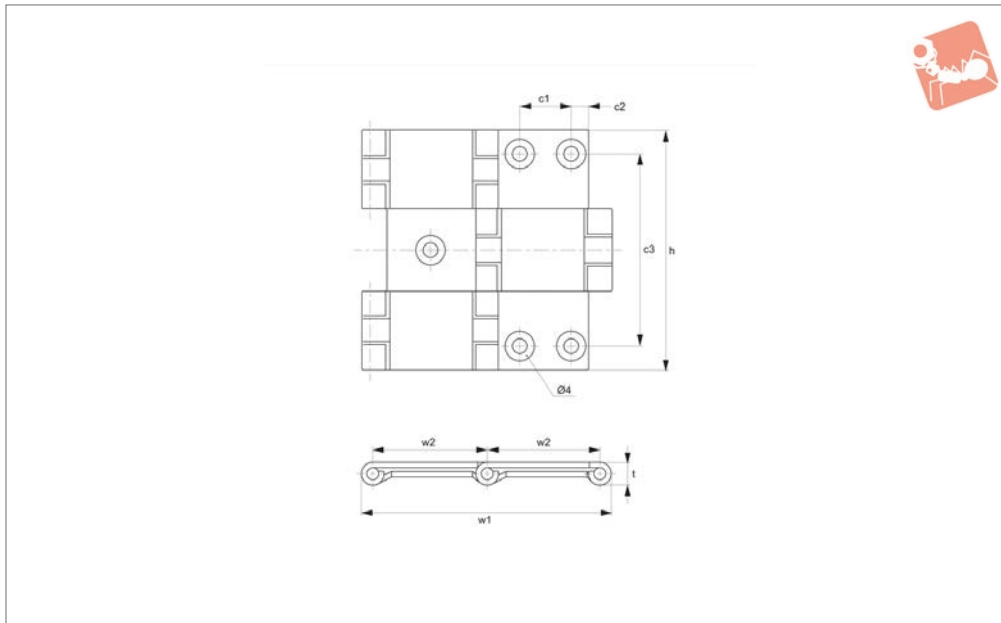

**S2010**

HINGES

**Material**


Stainless steel, AISI 304, satin finish.


Max. door size - 450w x 700h x 21mm thick. Max. door weight - 2,6Kg per hinge pair.

**Technical Notes**

Universal left and right swing of 180°.

Order No.	c <sub>1</sub>	c <sub>2</sub>	c <sub>3</sub>	t	w <sub>1</sub>	w <sub>2</sub>	y	Weight g
S2010.AC0060	13.5	4.8	47	5.6	64	29.0	60	65
S2010.AC0070	13.5	6.8	57	7.5	78	35.0	70	130
S2010.AC0080	22.0	6.5	66	7.5	94	43.2	80	175

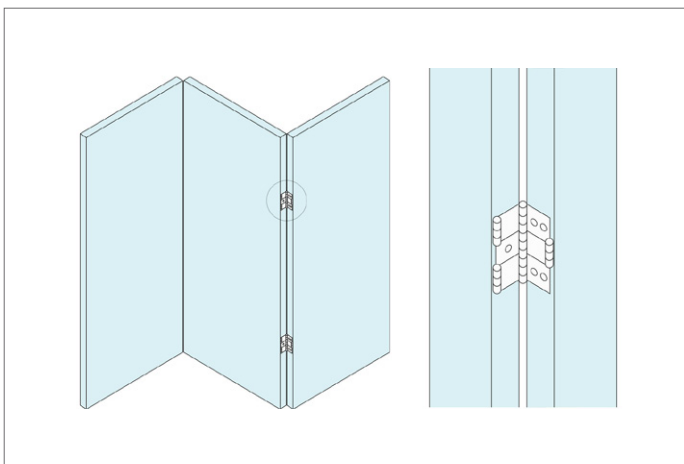


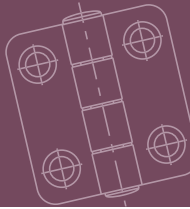

### A variety of mounting methods are available!

#### Mounting combinations

Wixroyd concealed hinges can be mounted in a variety of ways using additional nuts and bolts.

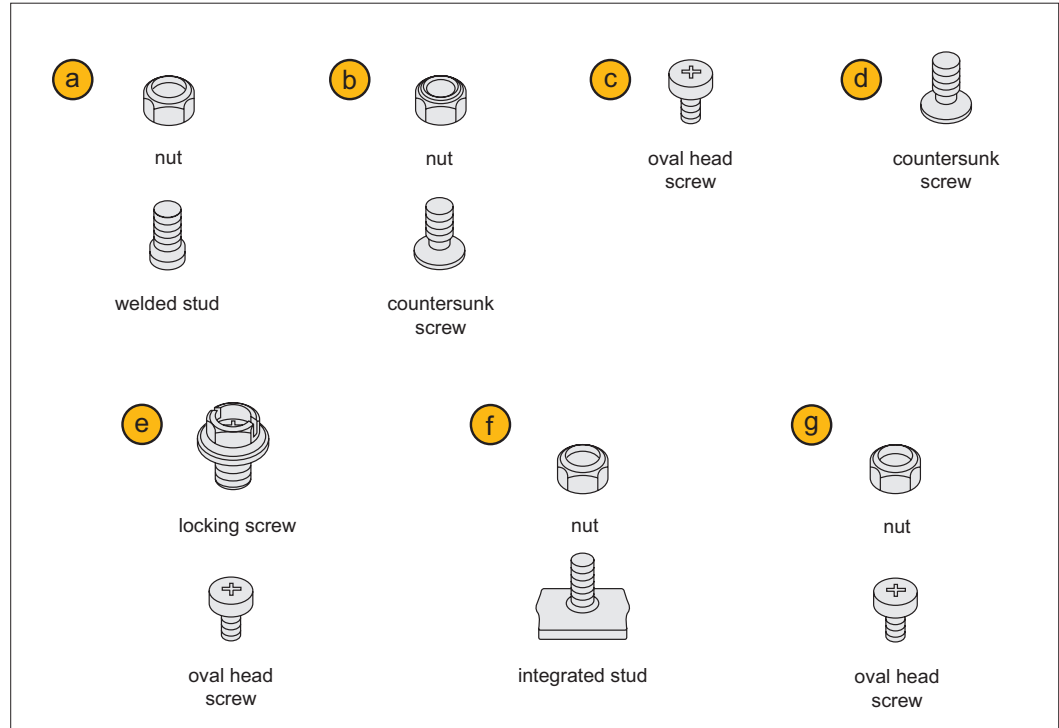

**Important Note:** Refer to individual product pages for suitable mounting options. If you have any problems please contact our Technical Sales Team.

#### Mounting example

In the example, mounting option ②, a nut with a countersunk screw, is used to mount the hinge onto the enclosure body.

