




# Flush Mount - Drop Lid Hinges

two pivot overlay - brass



Hinges

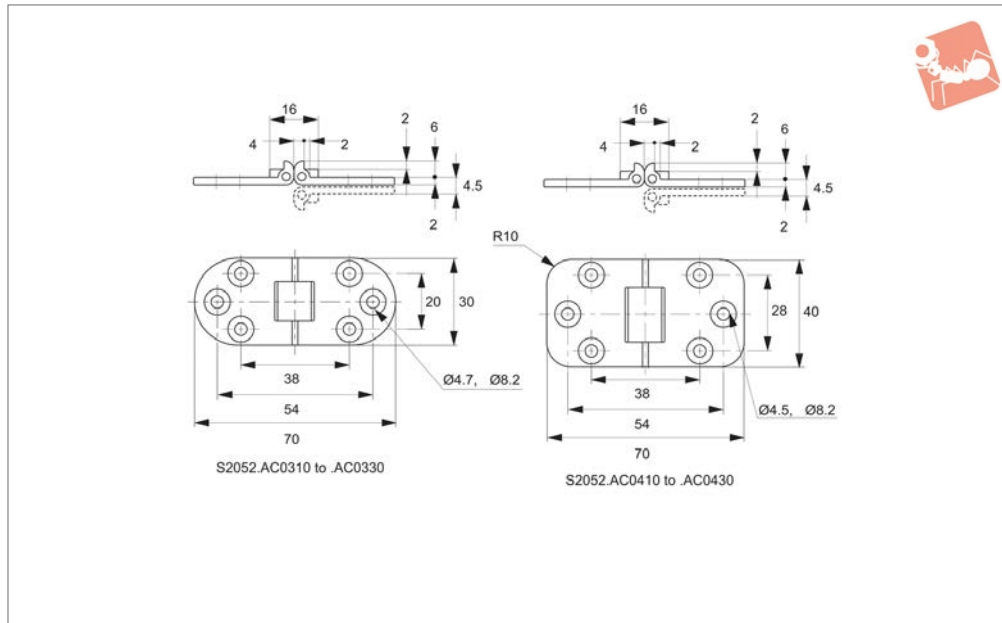

**S2052**

HINGES

## Material


Brass, finished either as polished brass, satin nickel or chrome plating.

## Technical Notes

Max. door size: 450w x 700h x 21mm thick.  
Provides 180° opening to table tops and

flat surfaces.

Order No.	Finish	Size	Weight capacity per pair kg max.	Weight g
<b>S2052.AC0310</b>	Satin Nickel	30	4.0	45
<b>S2052.AC0320</b>	Chrome	30	4.0	45
<b>S2052.AC0330</b>	Brass	30	4.0	45
<b>S2052.AC0410</b>	Satin Nickel	40	4.0	64
<b>S2052.AC0420</b>	Chrome	40	4.0	64
<b>S2052.AC0430</b>	Brass	40	4.0	64

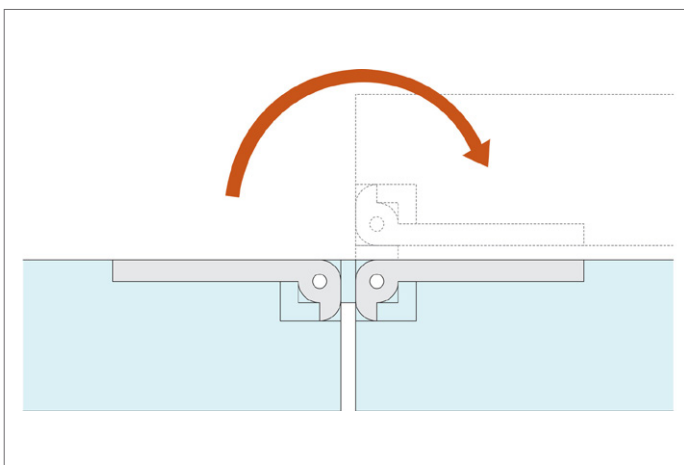




### A variety of mounting methods are available!

#### Mounting combinations

Wixroyd concealed hinges can be mounted in a variety of ways using additional nuts and bolts.

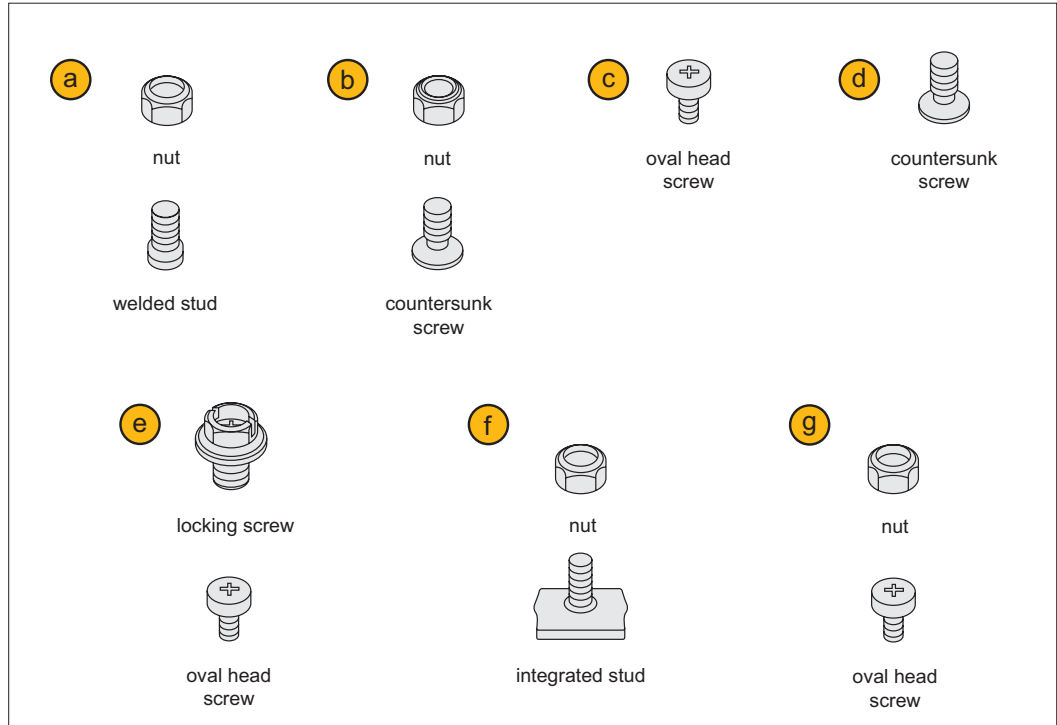

**Important Note:** Refer to individual product pages for suitable mounting options. If you have any problems please contact our Technical Sales Team.

#### Mounting example

In the example, mounting option ②, a nut with a countersunk screw, is used to mount the hinge onto the enclosure body.

