




Concealed Pivot Hinges - Lift Off

19mm door return - weld and oval head screw -



Hinges

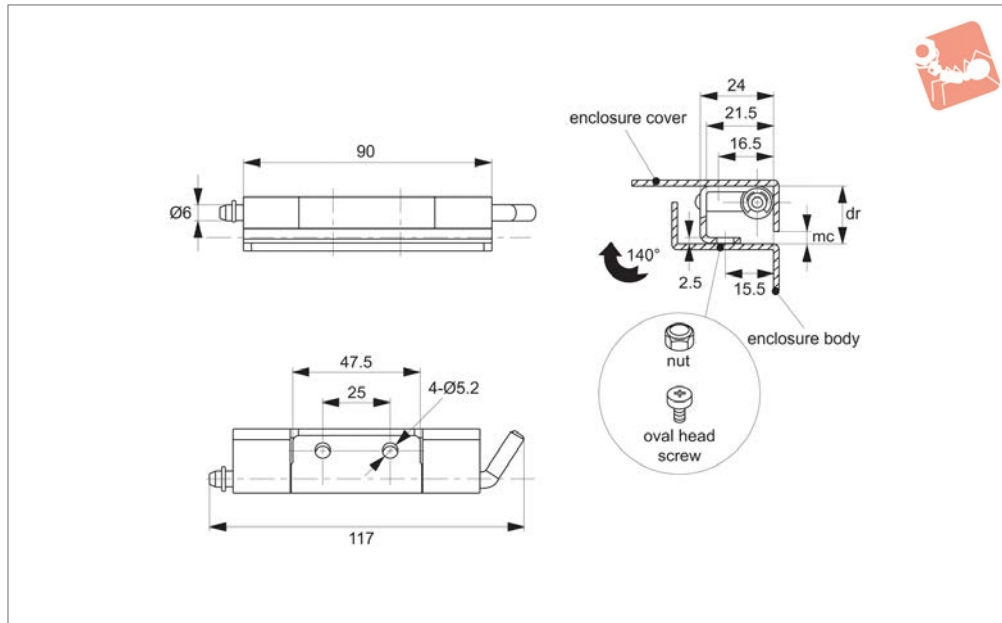

S2155

HINGES

Material

Hinge & pin: stainless steel.

Technical Notes

Opening angle 140°.



Important Notes

Suited to sheet metal and machine enclosures with a 19mm door return. Main body mounted via two M5 screws, hinge plate

welded to frame.

Removable hinge pin enables easy installation, and is held in place by split clip.

Order No.	Door return	Size	F_x N	F_y N	mc min.	ts panel thickness
S2155.AW0019	19	117 x 24 x 19	500	980	5	2.0

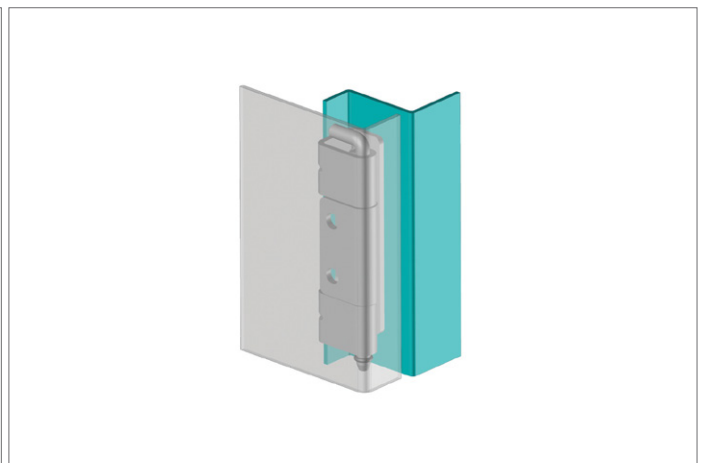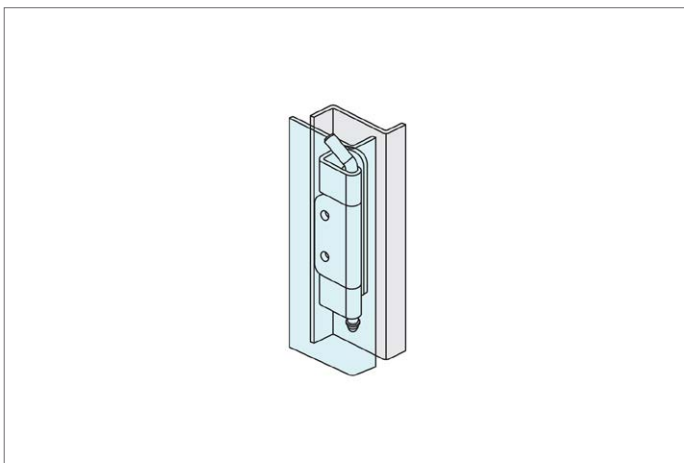




A variety of mounting methods are available!

Mounting combinations

Wixroyd concealed hinges can be mounted in a variety of ways using additional nuts and bolts.

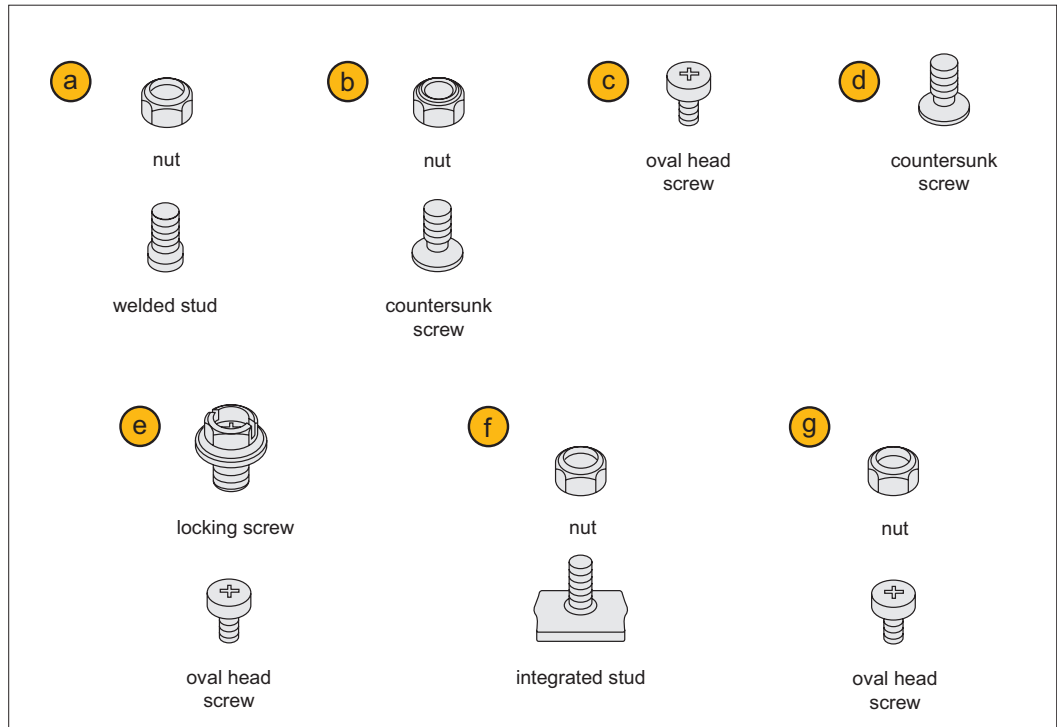

Important Note: Refer to individual product pages for suitable mounting options. If you have any problems please contact our Technical Sales Team.

Mounting example

In the example, mounting option ②, a nut with a countersunk screw, is used to mount the hinge onto the enclosure body.

