



# End Mount Concealed Pivot Hinge

spring loaded - weld-on - stainless steel

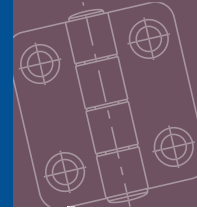

## Hinges

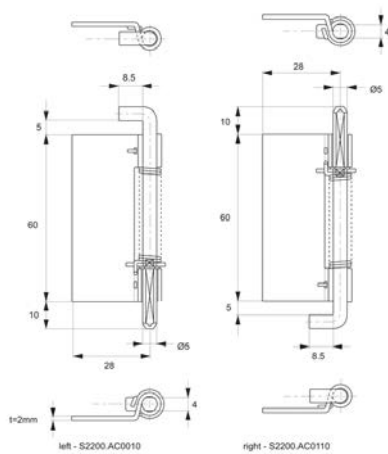

**S2200**

HINGES

### Material

Stainless steel, AISI 304.

### Technical Notes


Spring loaded for self-closing.

Lift pin for easy installation and removal.

Torsion moment (hinge closed): 0.76kgf/cm per piece.

Max. opening angle 100°.

Order No.	Type	Weight g
S2200.AC0010	Left	38
S2200.AC0110	Right	38

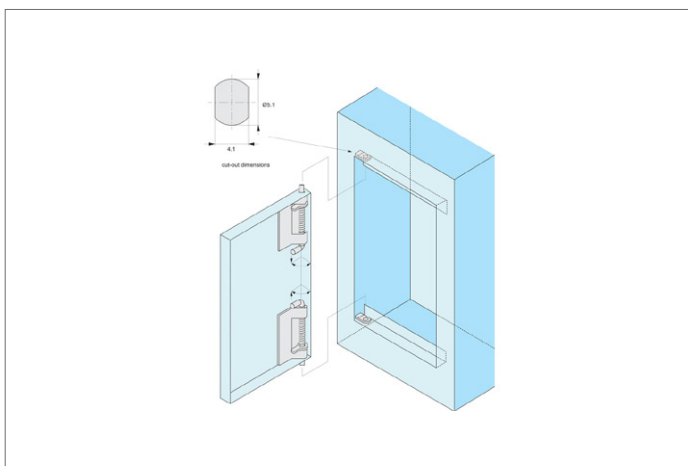




### A variety of mounting methods are available!

#### Mounting combinations

Wixroyd concealed hinges can be mounted in a variety of ways using additional nuts and bolts.

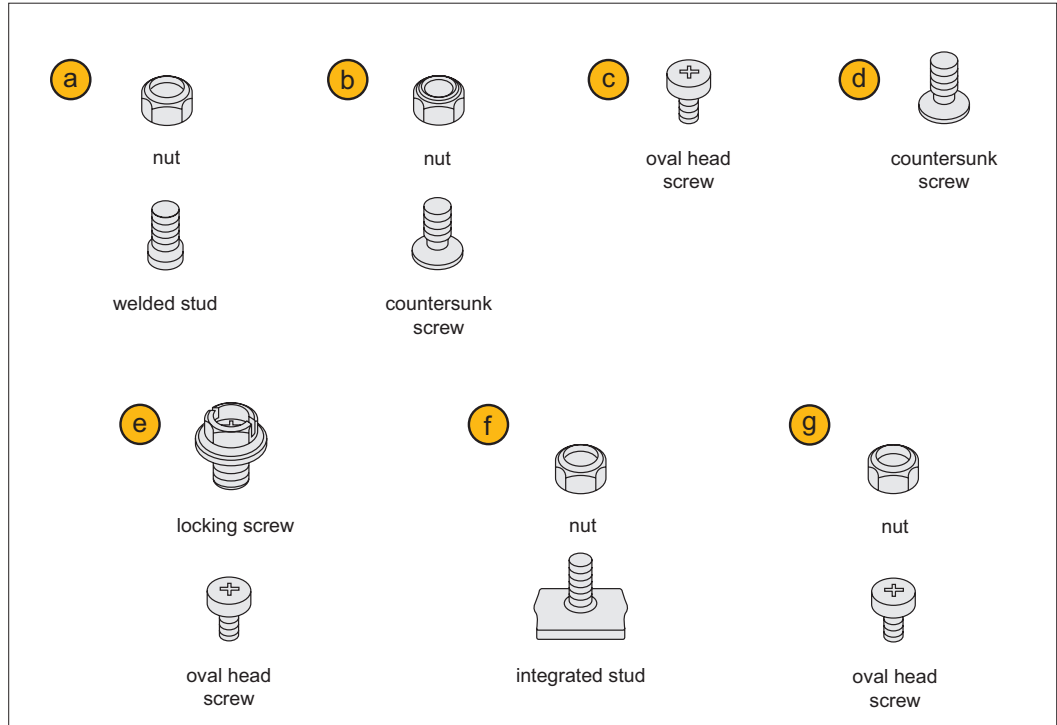

**Important Note:** Refer to individual product pages for suitable mounting options. If you have any problems please contact our Technical Sales Team.

#### Mounting example

In the example, mounting option ②, a nut with a countersunk screw, is used to mount the hinge onto the enclosure body.

