





# Constant Torque - Friction Torque Hinges

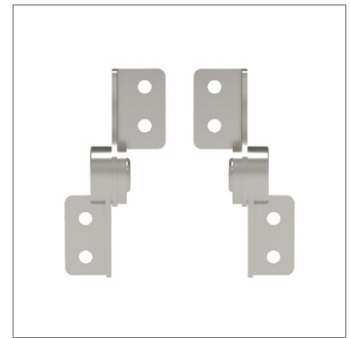

## Hinges

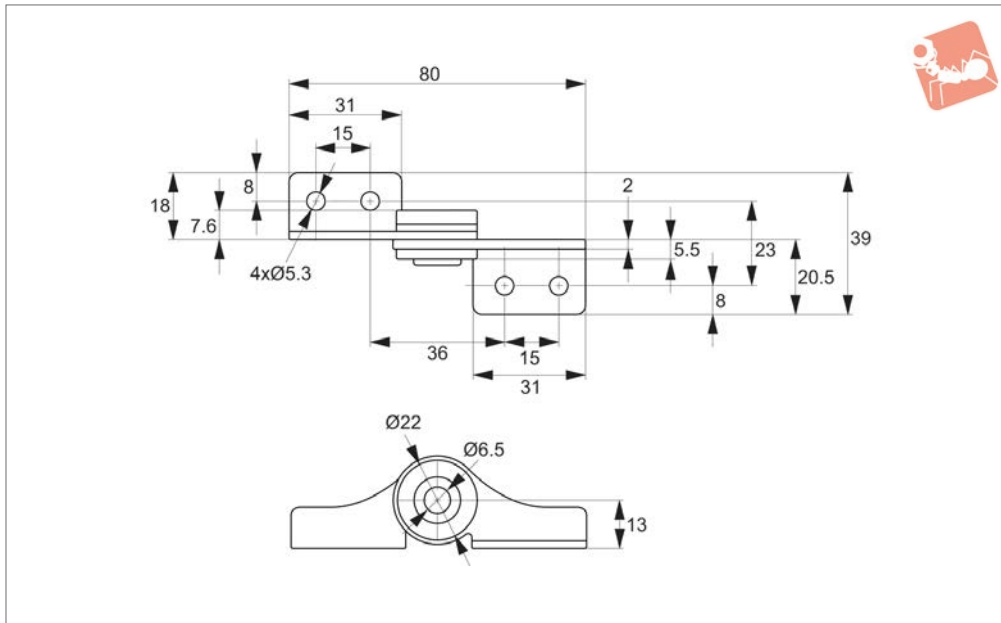

### S4024

HINGES

#### Material

Bracket and Base- 430 Stainless, Plate-steel, Shaft and washer- 303 and 430 stainless steel.

#### Technical Notes

Hole in shaft allows easy cable manage-

ment. Ideal for the holder of LCD and monitoring camera. Successfull Passed for the 50,000 open/close private cycle test. Operating temperature: 0°C- 40°C. For pair using: Use the same torque moment in both hinges.

Torque moment per piece is 4.5 Nm ±20%.

Order No.	Type	Weight g
S4024.AC0010	Right/Wiring Hole	60
S4024.AC0020	Left/Wiring Hole	60

