


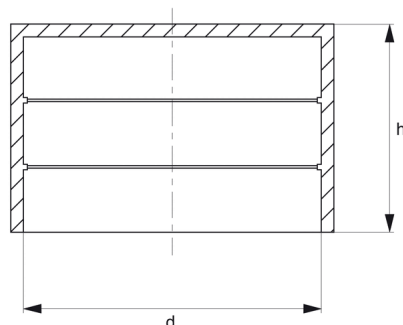

V0350

**Material**  
PVC, black.

flexible PVC.

**Technical Notes**

For a wide range of applications, durable a

**Important Notes**

Sold subject to minimum pack quantity.

| Order No.    | External tube dia. | d    | h    |
|--------------|--------------------|------|------|
| V0350.AC0250 | 6.0                | 6.0  | 13.0 |
| V0350.AC0252 | 8.0                | 8.0  | 15.5 |
| V0350.AC0254 | 10,0-11,0          | 10.0 | 16.5 |
| V0350.AC0256 | 12,0-13,0          | 12.0 | 19.0 |
| V0350.AC0264 | 16,0-17,0          | 16.0 | 26.0 |
| V0350.AC0266 | 18.0               | 18.0 | 26.0 |
| V0350.AC0268 | 19.0               | 19.0 | 26.0 |
| V0350.AC0270 | 20.0               | 20.0 | 26.5 |
| V0350.AC0272 | 21.0               | 21.0 | 27.5 |
| V0350.AC0274 | 22,0-23,0          | 22.0 | 29.0 |
| V0350.AC0276 | 24.0               | 24.0 | 31.0 |
| V0350.AC0278 | 25,0-26,0          | 25.0 | 31.0 |
| V0350.AC0280 | 27.0               | 27.0 | 31.0 |
| V0350.AC0282 | 28,0-29,0          | 28.0 | 32.0 |
| V0350.AC0284 | 30,0-31,0          | 30.0 | 32.0 |
| V0350.AC0286 | 32,0-33,0          | 32.0 | 32.0 |
| V0350.AC0288 | 34.0               | 34.0 | 33.0 |
| V0350.AC0290 | 35,0-36,0          | 35.0 | 32.5 |
| V0350.AC0292 | 38,0-39,0          | 38.0 | 32.0 |
| V0350.AC0294 | 40,0-41,0          | 40.0 | 34.0 |
| V0350.AC0296 | 42.0               | 42.0 | 32.0 |
| V0350.AC0298 | 43,0-44,0          | 43.0 | 32.0 |
| V0350.AC0300 | 45,0-46,0          | 45.0 | 36.0 |
| V0350.AC0304 | 48.0               | 48.0 | 36.0 |
| V0350.AC0306 | 49,0-51,0          | 49.0 | 36.0 |
| V0350.AC0308 | 54,0-55,0          | 54.0 | 39.0 |
| V0350.AC0310 | 59,0-60,0          | 59.0 | 36.0 |
| V0350.AC0312 | 63,0-64,0          | 63.0 | 37.0 |
| V0350.AC0314 | 69,0-70,0          | 69.0 | 37.0 |
| V0350.AC0316 | 75,0-76,0          | 75.0 | 39.0 |
| V0350.AC0318 | 90,0-91,0          | 90.0 | 39.0 |