




V0400

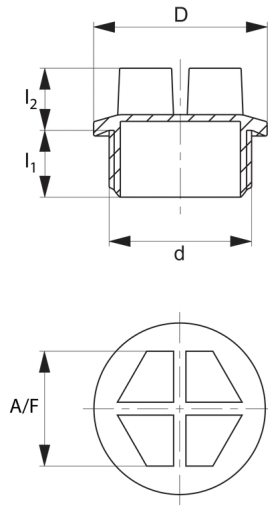

Material

Polyamide, yellow.

spanner.

Technical Notes

Threaded for installation via screwdriver or

Important Notes

Sold subject to minimum pack quantity.

Order No.	d_1	l_1	l_2	A/F	d_2
V0400.AC0881	14,2 - 0,2	7	10	10	M10
V0400.AC0883	17,2 - 0,2	10	10	13	M12
V0400.AC0885	19,2 - 0,2	10	10	13	M14
V0400.AC0887	22,0 - 0,2	10	10	17	M16
V0400.AC0889	24,0 - 0,2	10	11	17	M18
V0400.AC0891	26,0 - 0,2	10	14	19	M20
V0400.AC0893	27,2 - 0,2	10	14	19	M22
V0400.AC0895	32,0 - 0,3	13	14	24	M26
V0400.AC0897	32,3 - 0,3	13	14	24	M27
V0400.AC0899	40,0 - 0,4	13	14	27	M33
V0400.AC0901	50,0 - 0,4	13	15	36	M42
V0400.AC0949	16,8	9	10	13	1/8"
V0400.AC0951	19,0 - 0,2	9	10	13	1/4"
V0400.AC0953	22,2 - 0,2	9	11	17	3/8"
V0400.AC0955	27,0 - 0,2	12	13	19	1/2"
V0400.AC0957	32,3 - 0,3	12	13	24	3/4"
V0400.AC0959	40,0 - 0,4	15	14	27	1"
V0400.AC0961	50,0 - 0,4	15	15	36	1 1/4"
V0400.AC0963	55,4 - 0,4	15	15	41	1 1/2"
V0400.AC0965	68,4	15	15	55	2"