




Inserts ribbed - rectangular

Caps, Plugs, Masking and

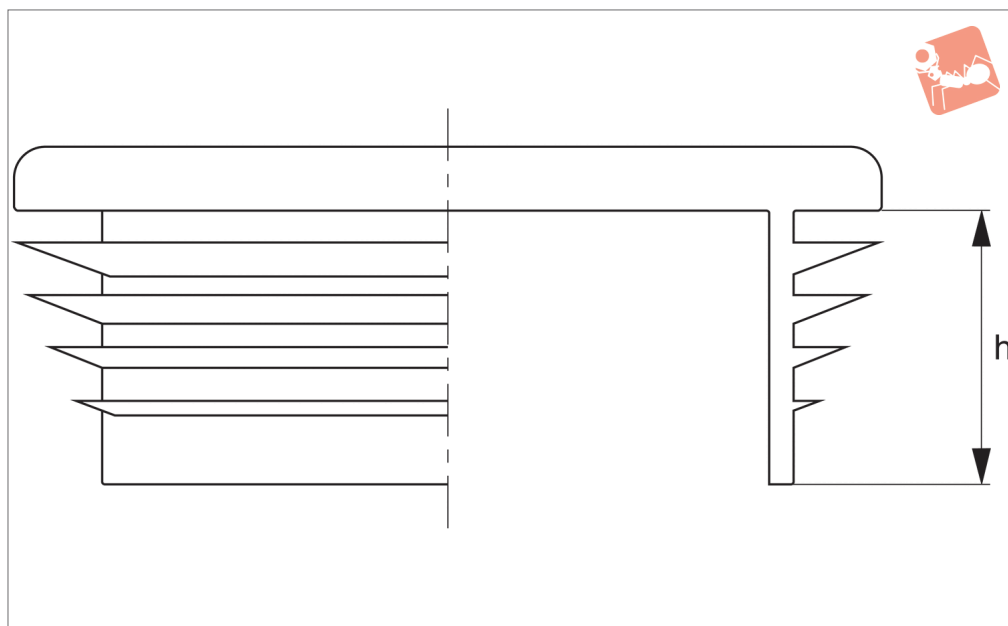

V0610

CAPS, PLUGS, MASKING AND INSERTS

Material

Low density polyethylene, black.

Important Notes

Sold subject to minimum pack quantity.

Technical Notes

Insert ribs provide secure fitting.

Order No.	External cap dim.	Tube wall thickness	h
V0610.AC0992	20x10	1,0-2,0	11,0
V0610.AC0994	20x15	1,0-2,0	11,5
V0610.AC0997	25x10	1,0-1,5	11,5
V0610.AC0999	25x15	1,0-2,5	11,5
V0610.AC1002	25x20	1,0-3,0	11,5
V0610.AC1004	30x10	1,0-1,5	11,5
V0610.AC1006	30x15	1,0-2,5	11,5
V0610.AC1008	30x20	1,5-3,0	11,5
V0610.AC1013	30x25	1,5	13,0
V0610.AC1015	35x10	1,0-2,0	11,5
V0610.AC1017	35x20	1,0-2,5	11,5
V0610.AC1016	35x15	1,0-3,0	11,5
V0610.AC1018	35x25	1,0-3,0	11,5
V0610.AC1022	40x10	1,5	10,5
V0610.AC1024	40x15	1,0-1,5	12,0
V0610.AC1027	40x20	1,0-2,0	12,0
V0610.AC1030	40x25	1,0-3,0	11,5
V0610.AC1032	40x30	1,0-3,0	12,0
V0610.AC1036	40x35	1,0-3,0	12,0
V0610.AC1037	45x15	1,5-2,0	11,0
V0610.AC1039	45x20	1,5-2,0	11,5
V0610.AC1041	45x25	1,5-2,0	14,0
V0610.AC1042	45x30	1,0-2,5	12,0
V0610.AC1043	45x35	1,0-3,5	12,0
V0610.AC1044	50x10	1,0-1,5	12,0
V0610.AC1046	50x20	1,0-3,0	14,0
V0610.AC1048	50x25	1,5-2,5	14,5
V0610.AC1049	50x30	1,5-2,0	13,5
V0610.AC1051	50x30	3,0	14,0
V0610.AC1053	50x35	1,0-3,5	14,5
V0610.AC1054	50x40	1,5-2,5	12,5
V0610.AC1056	55x34	1,5	14,0
V0610.AC1057	55x40	1,5-4,0	14,5
V0610.AC1058	60x15	1,0-2,0	14,5



Order No.	External cap dim.	Tube wall thickness	h
V0610.AC1060	60x20	1,0-3,0	14.5
V0610.AC1061	60x25	1,0-2,5	14.0
V0610.AC1063	60x30	1,5-2,0	15.0
V0610.AC1064	60x35	1,5-3,5	15.0
V0610.AC1065	60x40	1,0-3,0	14.0
V0610.AC1066	60x40	4,0-5,0	14.0
V0610.AC1067	60x45	1,5-4,0	15.0
V0610.AC1068	60x50	1,5-3,5	14.5
V0610.AC1069	65x35	1,0-3,0	15.0
V0610.AC1070	70x20	1,0-2,0	17.0
V0610.AC1071	70x25	1,5-2,0	17.0
V0610.AC1072	70x30	1,5-2,0	18.0
V0610.AC1073	70x40	1,5-2,0	18.0
V0610.AC1074	70x40	2,0-5,0	15.0
V0610.AC1077	80x20	1,5-2,0	18.0
V0610.AC1078	80x30	1,0-2,5	14.5
V0610.AC1080	80x30	2,5-4,0	14.5
V0610.AC1082	80x40	1,0-3,0	14.5
V0610.AC1084	80x40	3,2-4,0	24.5
V0610.AC1086	80x50	2,0-4,0	24.0
V0610.AC1087	80x60	2,5-3,0	24.0
V0610.AC1088	80x60	5.0	18.5
V0610.AC1089	100x30	1,5-3,0	15.0
V0610.AC1090	100x40	2,0-4,0	14.5
V0610.AC1094	100x50	2,0-3,0	24.0
V0610.AC1096	100x50	3,2-5,0	24.0
V0610.AC1097	120x30	1,5-2,0	14.5
V0610.AC1098	120x40	2.0	-
V0610.AC1100	120x40	3,0-5,0	21.5
V0610.AC1102	120x60	2,0-4,0	24.5
V0610.AC1105	120x80	2,0-3,0	24.0
V0610.AC1106	120x80	5,0-8,0	25.0
V0610.AC1108	140x80	2,0-4,5	20.0
V0610.AC1109	150x100	3,0-8,0	27.0