


Insert
ribbed - square

**Caps, Plugs,
Masking and**

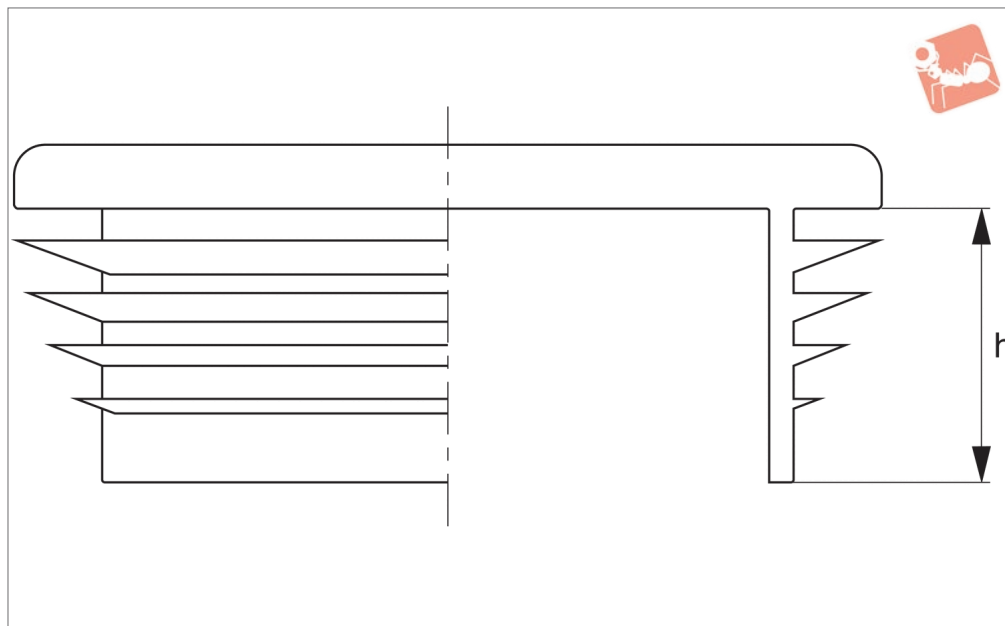

V0600

CAPS, PLUGS, MASKING AND INSERTS

Material

Low density polyethylene, black.

Important Notes

Sold subject to minimum pack quantity.


Technical Notes

Insert ribs provide secure fitting.

Order No.	External cap dim.	Tube wall thickness	h
V0600.AC0208	90x90	3,6-5,0	6.0
V0600.AC0151	10x10	1,5-2,0	12.0
V0600.AC0153	12x12	1,5-2,0	12.0
V0600.AC0155	13x13	1,5-2,0	12.0
V0600.AC0157	15x15	1,5-2,0	14.0
V0600.AC0159	16x16	1,5-2,0	11.5
V0600.AC0162	18x18	1,5-2,0	11.5
V0600.AC0164	20x20	1,0-3,0	11.0
V0600.AC0166	22x22	1,0-3,0	12.0
V0600.AC0168	25x25	1,0-3,0	11.5
V0600.AC0174	28x28	1,5-3,0	11.5
V0600.AC0176	30x30	1,0-2,5	11.5
V0600.AC0177	30x30	2,5-4,5	11.5
V0600.AC0182	35x35	1,0-3,0	14.5
V0600.AC0184	35x35	2,5-5,0	12.0
V0600.AC0186	40x40	1,0-3,0	14.0
V0600.AC0188	40x40	2,5-4,0	18.0
V0600.AC0189	40x40	5,0-5,5	14.0
V0600.AC0192	45x45	1,0-3,0	14.5
V0600.AC0194	50x50	1,0-2,5	14.5
V0600.AC0196	50x50	2,6-4,0	25.0
V0600.AC0198	50x50	3,5-6,0	14.5
V0600.AC0200	60x60	1,5-3,5	24.0
V0600.AC0201	60x60	3,0-5,0	17.5
V0600.AC0203	70x70	2,0-4,0	19.0
V0600.AC0204	80x80	2,0-4,0	21.0
V0600.AC0206	80x80	3,0-5,0	24.0
V0600.AC0207	90x90	2,0-5,0	25.0
V0600.AC0210	100x100	1,0-4,0	24.0
V0600.AC0211	100x100	5,0-8,0	24.0
V0600.AC0213	120x120	2,5-5,0	25.0
V0600.AC0219	150x150	5,0-8,0	-
V0600.AC0221	150x150	10,0-12,5	27.0



V0610

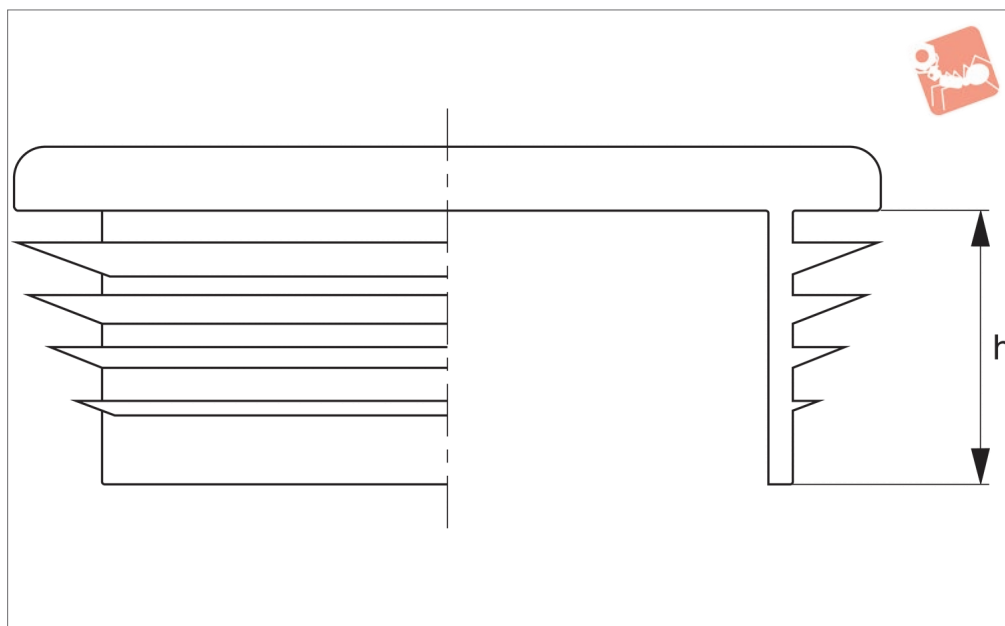

Material

Low density polyethylene, black.


Important Notes

Sold subject to minimum pack quantity.

Technical Notes

Insert ribs provide secure fitting.

Order No.	External cap dim.	Tube wall thickness	h
V0610.AC0992	20x10	1,0-2,0	11.0
V0610.AC0994	20x15	1,0-2,0	11.5
V0610.AC0997	25x10	1,0-1,5	11.5
V0610.AC0999	25x15	1,0-2,5	11.5
V0610.AC1002	25x20	1,0-3,0	11.5
V0610.AC1004	30x10	1,0-1,5	11.5
V0610.AC1006	30x15	1,0-2,5	11.5
V0610.AC1008	30x20	1,5-3,0	11.5
V0610.AC1013	30x25	1.5	13.0
V0610.AC1015	35x10	1,0-2,0	11.5
V0610.AC1017	35x20	1,0-2,5	11.5
V0610.AC1016	35x15	1,0-3,0	11.5
V0610.AC1018	35x25	1,0-3,0	11.5
V0610.AC1022	40x10	1.5	10.5
V0610.AC1024	40x15	1,0-1,5	12.0
V0610.AC1027	40x20	1,0-2,0	12.0
V0610.AC1030	40x25	1,0-3,0	11.5
V0610.AC1032	40x30	1,0-3,0	12.0
V0610.AC1036	40x35	1,0-3,0	12.0
V0610.AC1037	45x15	1,5-2,0	11.0
V0610.AC1039	45x20	1,5-2,0	11.5
V0610.AC1041	45x25	1,5-2,0	14.0
V0610.AC1042	45x30	1,0-2,5	12.0
V0610.AC1043	45x35	1,0-3,5	12.0
V0610.AC1044	50x10	1,0-1,5	12.0
V0610.AC1046	50x20	1,0-3,0	14.0
V0610.AC1048	50x25	1,5-2,5	14.5
V0610.AC1049	50x30	1,5-2,0	13.5
V0610.AC1051	50x30	3.0	14.0
V0610.AC1053	50x35	1,0-3,5	14.5
V0610.AC1054	50x40	1,5-2,5	12.5
V0610.AC1056	55x34	1.5	14.0
V0610.AC1057	55x40	1,5-4,0	14.5
V0610.AC1058	60x15	1,0-2,0	14.5

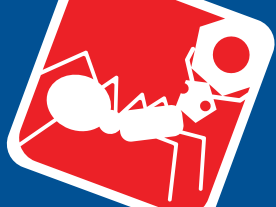

Inserts ribbed - rectangular




Caps, Plugs, Masking and

Order No.	External cap dim.	Tube wall thickness	h
V0610.AC1060	60x20	1,0-3,0	14.5
V0610.AC1061	60x25	1,0-2,5	14.0
V0610.AC1063	60x30	1,5-2,0	15.0
V0610.AC1064	60x35	1,5-3,5	15.0
V0610.AC1065	60x40	1,0-3,0	14.0
V0610.AC1066	60x40	4,0-5,0	14.0
V0610.AC1067	60x45	1,5-4,0	15.0
V0610.AC1068	60x50	1,5-3,5	14.5
V0610.AC1069	65x35	1,0-3,0	15.0
V0610.AC1070	70x20	1,0-2,0	17.0
V0610.AC1071	70x25	1,5-2,0	17.0
V0610.AC1072	70x30	1,5-2,0	18.0
V0610.AC1073	70x40	1,5-2,0	18.0
V0610.AC1074	70x40	2,0-5,0	15.0
V0610.AC1077	80x20	1,5-2,0	18.0
V0610.AC1078	80x30	1,0-2,5	14.5
V0610.AC1080	80x30	2,5-4,0	14.5
V0610.AC1082	80x40	1,0-3,0	14.5
V0610.AC1084	80x40	3,2-4,0	24.5
V0610.AC1086	80x50	2,0-4,0	24.0
V0610.AC1087	80x60	2,5-3,0	24.0
V0610.AC1088	80x60	5,0	18.5
V0610.AC1089	100x30	1,5-3,0	15.0
V0610.AC1090	100x40	2,0-4,0	14.5
V0610.AC1094	100x50	2,0-3,0	24.0
V0610.AC1096	100x50	3,2-5,0	24.0
V0610.AC1097	120x30	1,5-2,0	14.5
V0610.AC1098	120x40	2,0	-
V0610.AC1100	120x40	3,0-5,0	21.5
V0610.AC1102	120x60	2,0-4,0	24.5
V0610.AC1105	120x80	2,0-3,0	24.0
V0610.AC1106	120x80	5,0-8,0	25.0
V0610.AC1108	140x80	2,0-4,5	20.0
V0610.AC1109	150x100	3,0-8,0	27.0



V0620

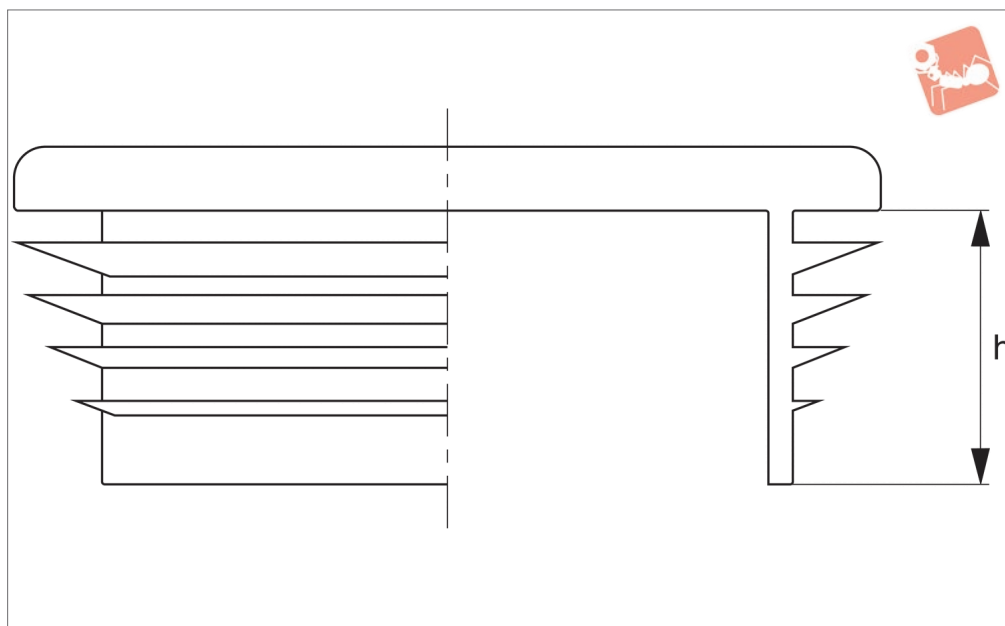

Material

Low density polyethylene, black.


Important Notes

Sold subject to minimum pack quantity.

Technical Notes


Insert ribs provide secure fitting.

Order No.	External tube dimension a x b	Tube wall thickness	h_1	h_2
V0620.AC0001	20x10	2,0	5	10
V0620.AC0003	30x15	1,0-2,5	5	12
V0620.AC0005	35x15	1,2-2,5	5	12
V0620.AC0007	35x20	1,0-3,0	5	12
V0620.AC0009	38x20	1,0-3,0	5	12
V0620.AC0011	40x20	1,0-3,0	5	12
V0620.AC0013	45x20	1,5-3,0	5	12
V0620.AC0015	48x20	1,0-2,5	5	12
V0620.AC0017	50x15	1,0-2,5	5	12
V0620.AC0019	50x20	1,0-3,0	5	12
V0620.AC0021	50x25	1,0-2,5	5	12
V0620.AC0023	50x30	1,0-2,5	5	12
V0620.AC0025	60x20	1,0-2,0	5	13
V0620.AC0027	60x25	1,5-3,0	5	13
V0620.AC0029	60x30	1,0-2,0	5	13

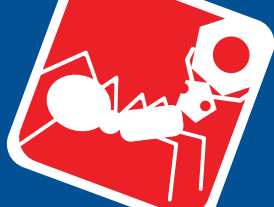

Inserts ribbed - round

Caps, Plugs, Masking and

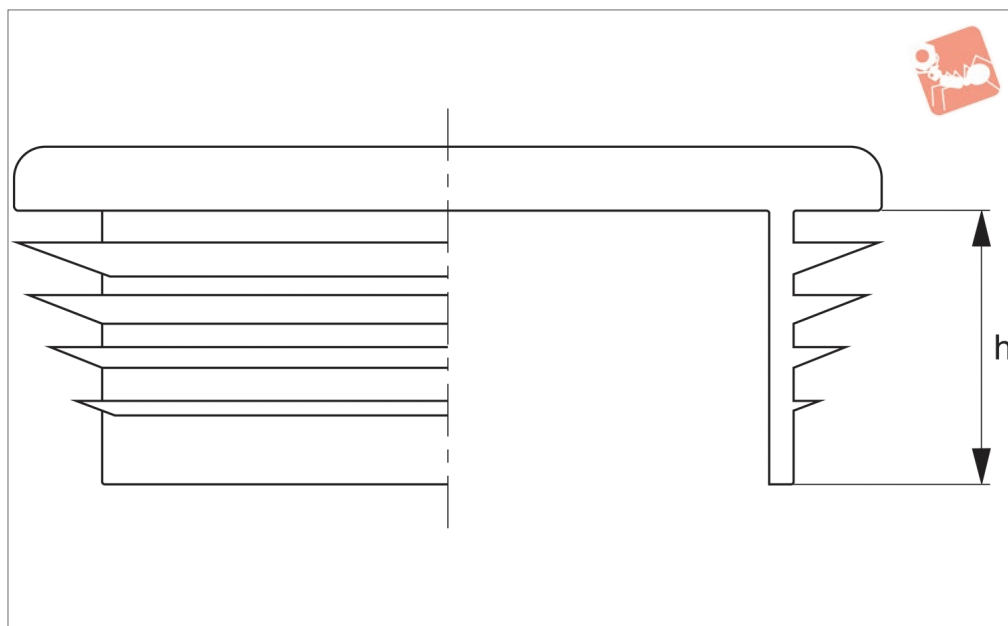

V0630

CAPS, PLUGS, MASKING AND INSERTS

Material

Low density polyethylene, black.

Important Notes

Sold subject to minimum pack quantity.

Technical Notes

insert ribs provide secure fitting.

Order No.	External cap dia.	Tube wall thickness	h
V0630.AC0301	10	1,0-2,0	11.0
V0630.AC0303	12	1,0-2,0	11.0
V0630.AC0305	13	1,0-2,0	11.0
V0630.AC0307	14	1,0-2,0	11.5
V0630.AC0309	15	1,0-2,0	13.0
V0630.AC0311	16	1,0-2,0	11.0
V0630.AC0313	18	1,0-2,0	11.4
V0630.AC0314	19	1,0-2,0	11.4
V0630.AC0315	20	1,0-2,0	11.4
V0630.AC0316	21	1,0-2,0	11.5
V0630.AC0317	22	1,0-2,0	11.5
V0630.AC0318	23	1,0-2,5	11.5
V0630.AC0320	25	1,0-3,0	11.5
V0630.AC0322	27	1,0-3,0	11.5
V0630.AC0323	28	1,0-2,0	11.5
V0630.AC0325	30	1,0-2,0	11.6
V0630.AC0327	32	1,0-2,0	11.5
V0630.AC0328	34	1,0-3,0	11.5
V0630.AC0331	35	1,0-2,0	11.5
V0630.AC0333	36	1,0-2,0	11.5
V0630.AC0336	38	1,0-3,5	11.5
V0630.AC0338	40	1,0-3,0	11.5
V0630.AC0339	42	1,0-2,0	11.5
V0630.AC0340	42	2,0-4,0	11.5
V0630.AC0342	45	1,0-3,5	11.0
V0630.AC0344	48	1,2-3,6	11.5
V0630.AC0345	50	1,0-2,0	11.5
V0630.AC0346	52	1,5-3,5	14.5
V0630.AC0348	55	1,0-3,0	11.5
V0630.AC0350	60	1,5-3,0	18.5
V0630.AC0351	60	3,0-4,0	21.0
V0630.AC0352	65	1,5-3,5	21.0
V0630.AC0353	70	2,0-4,5	21.0
V0630.AC0355	76	1,6-4,0	21.5



Order No.	External cap dia.	Tube wall thickness	h
V0630.AC0358	80	1,5-3,0	21.0
V0630.AC0359	90	2,5-5,0	19.9
V0630.AC0360	95	1,5-4,0	21.0
V0630.AC0361	102	2,0-4,0	20.2
V0630.AC0362	100	2,0-4,5	28.5
V0630.AC0363	105	2,0-4,5	29.0
V0630.AC0364	110	2,0-4,5	28.5
V0630.AC0365	120	2,0-4,0	28.5