


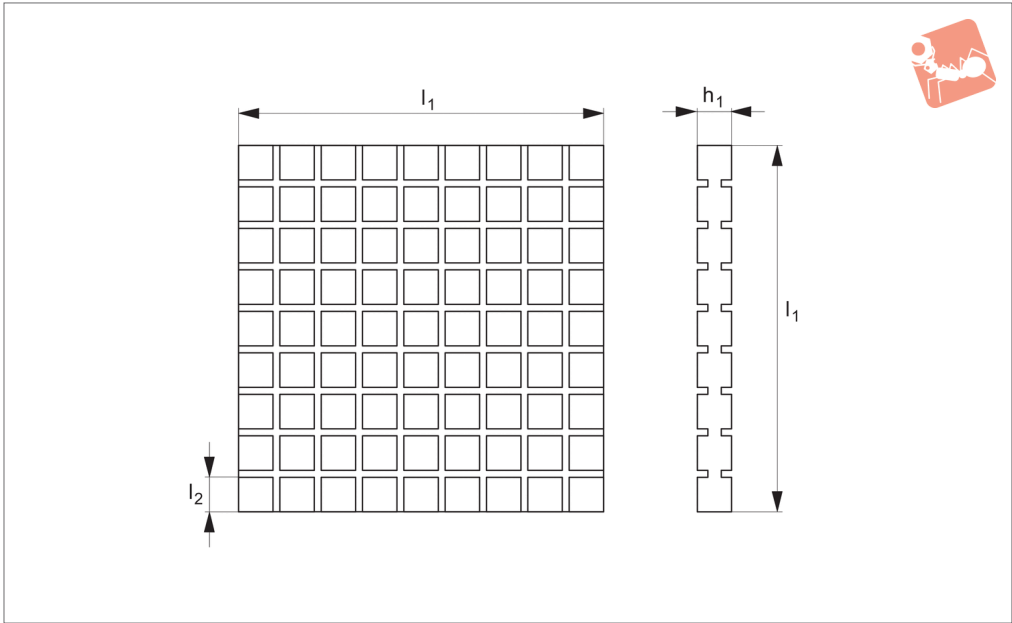

61780

ANTI-VIBRATION

Material

Rubber (hardness - 55 Shore A).

Technical Notes

The pad can be cut to suit the application

as required.

Differs from a plain rubber mat as the squared units can deform - improving its anti-vibration features.


Tips

High frequency isolation (30-40Hz).
Own frequency 18Hz.

Order No.	l_1	l_2	h_1	Compression max.	Load kgf/cm^2 max.
61780.W0210	210	10	14	2	8
61780.W0302	300	10	5	1	8
61780.W0301	300	10	7	1.6	8
61780.W0500	500	10	7	1	8


61800

ANTI-VIBRATION

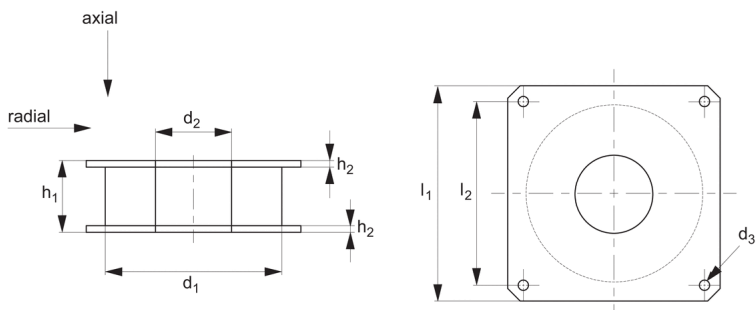
Material

Rubber on silver zinc plated steel (rubber hardness - 65 Shore A).

Order No.	l_1	d_1	d_2	d_3	l_2	h_1	h_2	Axial compression max.	Radial compression max.	Axial load kgf max.	Radial load kgf max.
61800.W0135	135	120	50	9	105	42	3	15	10	2500	300
61800.W0170	170	140	65	15	145	100	4	15	10	2500	300
61800.W0180	180	160	60	9	140	46	4	15	10	2500	300
61800.W0210	210	185	70	11	165	55	5	15	10	2500	300
61800.W0250	250	230	100	16	215	48	4	15	10	2500	300