


Six Lobed Knobs



Grips

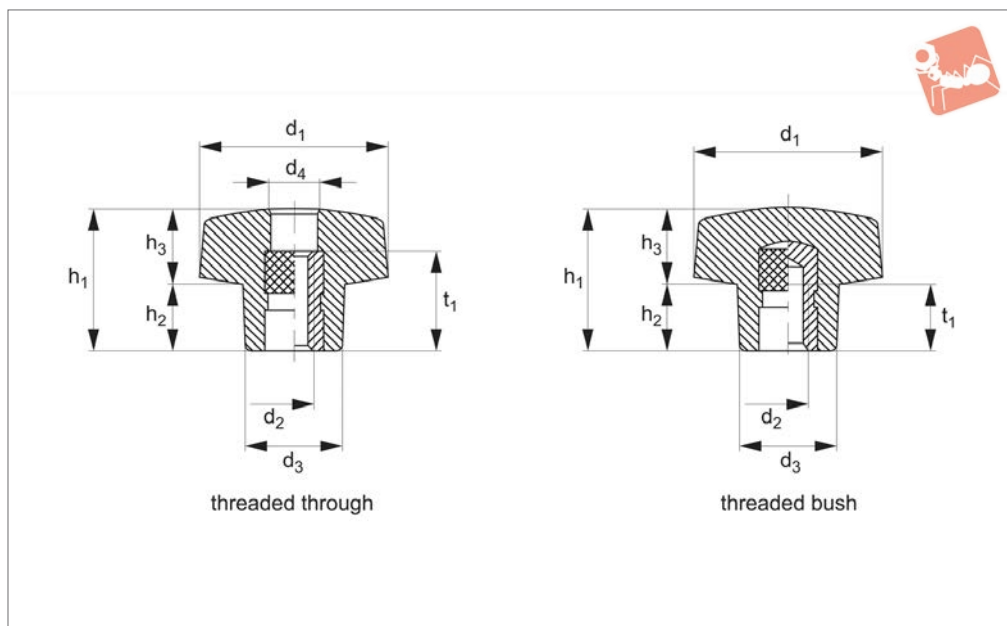


70680

GRIPS


Material

Brass bush. Duroplast, black.

Order No.	Type	d ₁	d ₂	d ₃	d ₄	h ₁	h ₂	h ₃	t ₁	Weight g
70680.W0021	Threaded Through	20	M 4	13	7.5	15	7	8.0	11	6
70680.W0022	Threaded Through	20	M 5	13	7.5	15	7	8.0	11	7
70680.W0023	Threaded Through	20	M 6	13	7.5	15	7	8.0	11	10
70680.W0031	Threaded Through	30	M 5	17	9.0	24	11	12.5	15	15
70680.W0032	Threaded Through	30	M 6	17	9.0	24	11	12.5	15	16
70680.W0033	Threaded Through	30	M 8	17	9.0	24	11	12.5	15	17
70680.W0204	Threaded Bush	20	M 4	13	-	15	7	8.0	9	5
70680.W0205	Threaded Bush	20	M 5	13	-	15	7	8.0	9	5
70680.W0206	Threaded Bush	20	M 6	13	-	15	7	8.0	9	5
70680.W0305	Threaded Bush	30	M 5	17	-	24	11	13.0	9	14
70680.W0306	Threaded Bush	30	M 6	17	-	24	11	13.0	9	15
70680.W0308	Threaded Bush	30	M 8	17	-	24	11	13.0	15	17
70680.W0406	Threaded Bush	40	M 6	21	-	28	12	16.0	13	35
70680.W0408	Threaded Bush	40	M 8	21	-	28	12	16.0	15	34
70680.W0410	Threaded Bush	40	M10	21	-	28	12	16.0	16	36
70680.W0508	Threaded Bush	50	M 8	25	-	33	13	20.0	15	54
70680.W0510	Threaded Bush	50	M10	25	-	33	13	20.0	16	56
70680.W0512	Threaded Bush	50	M12	25	-	33	13	20.0	18	58

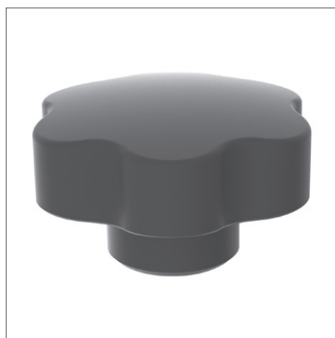


70700

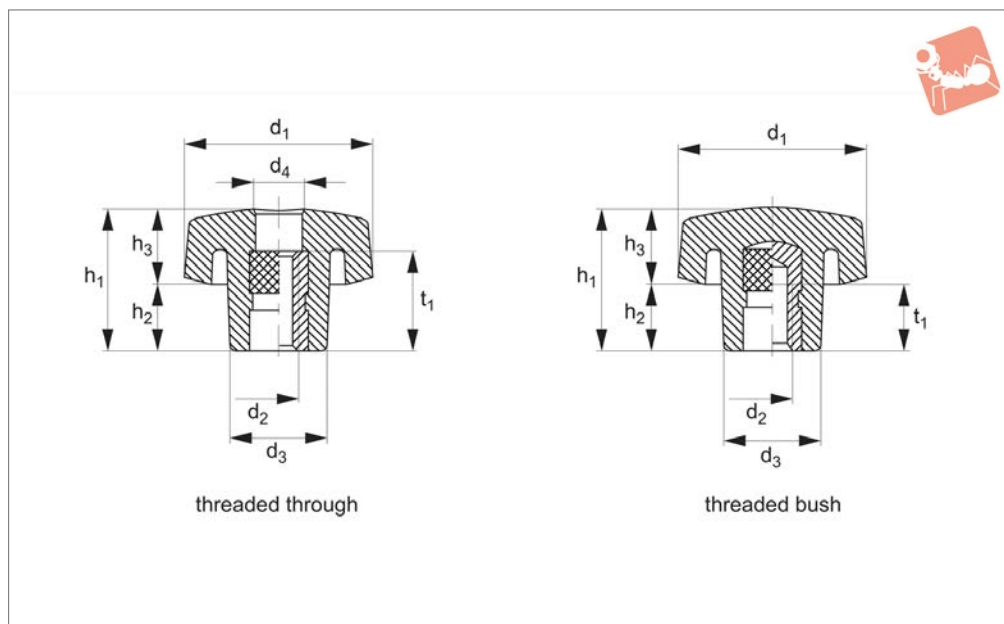
**Material**

Brass bush. Duroplast, black.


Order No.	Type	d ₁	d ₂	d ₃	d ₄	h ₁	h ₂	h ₃	t ₁	Weight g
70700.W0041	Threaded Through	40	M 6	21	11	28	13	15	18	28
70700.W0042	Threaded Through	40	M 8	21	11	28	13	15	18	29
70700.W0043	Threaded Through	40	M10	21	11	28	13	15	18	31
70700.W0051	Threaded Through	50	M 8	25	13	33	15	18	18	43
70700.W0052	Threaded Through	50	M10	25	13	33	15	18	18	45
70700.W0053	Threaded Through	50	M12	25	13	33	15	18	18	47
70700.W0061	Threaded Through	60	M10	28	11	35	15	20	25	70
70700.W0062	Threaded Through	60	M12	28	13	35	15	20	25	70
70700.W0063	Threaded Through	60	M14	28	15	35	15	20	25	70
70700.W0064	Threaded Through	60	M16	28	17	35	15	20	25	68
70700.W0071	Threaded Through	70	M10	32	11	42	21	21	25	92
70700.W0072	Threaded Through	70	M12	32	13	42	21	21	25	96
70700.W0073	Threaded Through	70	M14	32	15	42	21	21	25	94
70700.W0074	Threaded Through	70	M16	32	17	42	21	21	25	93
70700.W0406	Threaded Bush	40	M 6	21	-	28	13	15	13	26
70700.W0408	Threaded Bush	40	M 8	21	-	28	13	15	15	30
70700.W0410	Threaded Bush	40	M10	21	-	28	13	15	16	31
70700.W0508	Threaded Bush	50	M 8	25	-	33	15	18	15	48
70700.W0510	Threaded Bush	50	M10	25	-	33	15	18	16	49
70700.W0512	Threaded Bush	50	M12	25	-	33	15	18	18	50
70700.W0608	Threaded Bush	60	M 8	28	-	35	15	20	15	67
70700.W0610	Threaded Bush	60	M10	28	-	35	15	20	16	68
70700.W0612	Threaded Bush	60	M12	28	-	35	15	20	18	70
70700.W0614	Threaded Bush	60	M14	28	-	35	15	20	20	75
70700.W0620	Threaded Bush	60	M16	28	-	35	15	20	20	77
70700.W0710	Threaded Bush	70	M10	32	-	42	21	21	16	92
70700.W0712	Threaded Bush	70	M12	32	-	42	21	21	18	95
70700.W0714	Threaded Bush	70	M14	32	-	42	21	21	20	100
70700.W0716	Threaded Bush	70	M16	32	-	42	21	21	20	102
70700.W0912	Threaded Bush	90	M12	42	-	55	26	29	18	202
70700.W0914	Threaded Bush	90	M14	42	-	55	26	29	20	201
70700.W0916	Threaded Bush	90	M16	42	-	55	26	29	20	201
70700.W0918	Threaded Bush	90	M18	42	-	55	26	29	20	217

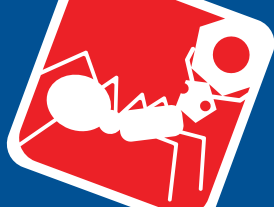

Six Lobed Knobs with grub screw

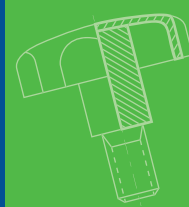

Grips

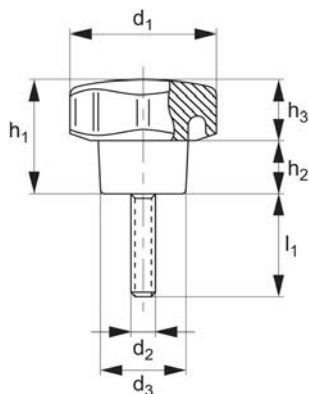

70720

GRIPS

Material

Zinc plated steel stud. Duroplast, black.


Order No.	d ₁	d ₂	l ₁	d ₃	h ₁	h ₂	h ₃	Weight g
70720.W0040	40	M 6	25	21	28	13	15	34
70720.W0041	40	M 6	40	21	28	13	15	37
70720.W0042	40	M 8	20	21	28	13	15	38
70720.W0043	40	M 8	25	21	28	13	15	39
70720.W0044	40	M 8	30	21	28	13	15	40
70720.W0045	40	M 8	40	21	28	13	15	44
70720.W0046	40	M 8	50	21	28	13	15	46
70720.W0047	40	M 8	70	21	28	13	15	55
70720.W0048	40	M10	50	21	28	13	15	60
70720.W0049	40	M10	70	21	28	13	15	70
70720.W0050	50	M 8	25	25	33	15	18	55
70720.W0051	50	M 8	40	25	33	15	18	60
70720.W0052	50	M 8	60	25	33	15	18	67
70720.W0053	50	M10	25	25	33	15	18	63
70720.W0054	50	M10	40	25	33	15	18	70
70720.W0055	50	M10	50	25	33	15	18	76
70720.W0056	50	M10	15	25	33	15	18	84
70720.W0057	50	M12	40	25	33	15	18	93
70720.W0058	50	M12	60	25	33	15	18	108
70720.W0060	60	M 8	20	28	35	15	20	75
70720.W0061	60	M 8	40	28	35	15	20	80
70720.W0062	60	M 8	60	28	35	15	20	87
70720.W0063	60	M10	20	28	35	15	20	82
70720.W0064	60	M10	40	28	35	15	20	96
70720.W0065	60	M10	60	28	35	15	20	107
70720.W0066	60	M12	30	28	35	15	20	107
70720.W0067	60	M12	50	28	35	15	20	122
70720.W0068	60	M12	60	28	35	15	20	127
70720.W0069	60	M12	80	28	35	15	20	133
70720.W0070	70	M10	30	32	42	21	21	115
70720.W0071	70	M10	40	32	42	21	21	116
70720.W0072	70	M12	30	32	42	21	21	133
70720.W0073	70	M12	40	32	42	21	21	138
70720.W0074	70	M12	50	32	42	21	21	145



Six Lobed Knobs with grub screw



Order No.	d ₁	d ₂	l ₁	d ₃	h ₁	h ₂	h ₃	Weight g
70720.W0075	70	M12	70	32	42	21	21	156
70720.W0076	70	M14	40	32	42	21	21	170
70720.W0077	70	M14	50	32	42	21	21	181
70720.W0090	90	M12	60	42	55	26	29	255
70720.W0091	90	M12	70	42	55	26	29	260
70720.W0092	90	M14	60	42	55	26	29	283
70720.W0093	90	M14	70	42	55	26	29	288
70720.W0094	90	M16	60	42	55	26	29	322
70720.W0095	90	M16	70	42	55	26	29	328

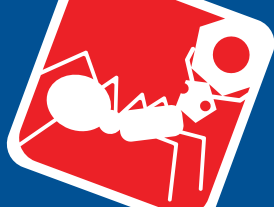


Six Lobed Knobs


stainless steel insert/thread



Grips

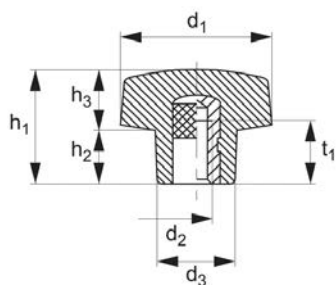

threaded bush

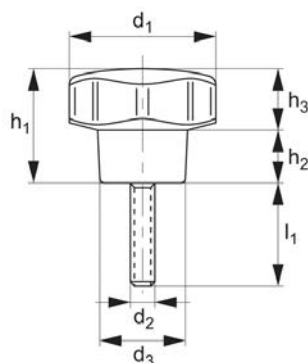

grub screw



70740

GRIPS


Material

Stainless steel bush or thread AISI 303
(1.4305). Duroplast, black.

Order No.	Type	d ₁	d ₂	l ₁	d ₃	h ₁	h ₂	h ₃	t ₁	Weight g
70740.W0030	Threaded Bush	30	M 6	-	17	24	11	13	9	15
70740.W0040	Threaded Bush	40	M 8	-	21	28	12	16	15	33
70740.W0050	Threaded Bush	50	M10	-	25	33	13	20	16	55
70740.W0060	Threaded Bush	60	M12	-	28	37	15	22	18	85
70740.W0301	Grub Screw	30	M 6	10	17	24	11	13	-	18
70740.W0302	Grub Screw	30	M 6	20	17	24	11	13	-	21
70740.W0303	Grub Screw	30	M 6	35	17	24	11	13	-	22
70740.W0401	Grub Screw	40	M 8	20	21	28	12	16	-	42
70740.W0402	Grub Screw	40	M 8	25	21	28	12	16	-	44
70740.W0403	Grub Screw	40	M 8	30	21	28	12	16	-	46
70740.W0404	Grub Screw	40	M 8	45	21	28	12	16	-	51
70740.W0501	Grub Screw	50	M10	20	25	33	13	20	-	73
70740.W0502	Grub Screw	50	M10	30	25	33	13	20	-	78
70740.W0503	Grub Screw	50	M10	50	25	33	13	20	-	87
70740.W0601	Grub Screw	60	M12	30	28	37	15	22	-	118
70740.W0602	Grub Screw	60	M12	40	28	37	15	22	-	125
70740.W0603	Grub Screw	60	M12	50	28	37	15	22	-	132
70740.W0701	Grub Screw	70	M12	70	32	42	18	24	-	184



70760

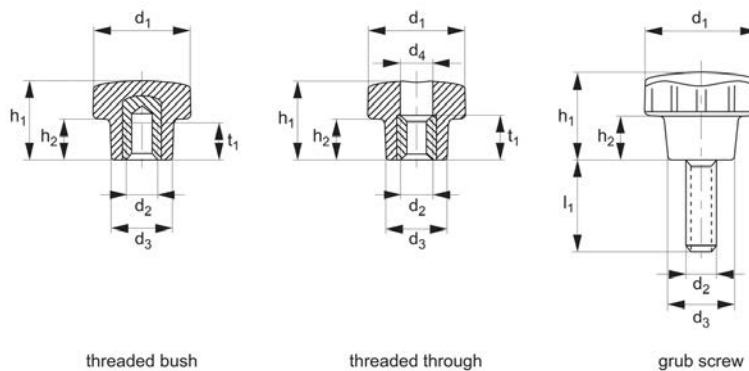**Material**

Brass bush. Thermoplastic, black.

Order No.	Type	d ₁	d ₂	l ₁	d ₃	d ₄	h ₁	h ₂	t ₁	Weight g
70760.W0004	Threaded Bush	21	M 4	-	13	-	15	8	8	8
70760.W0005	Threaded Bush	21	M 5	-	13	-	15	8	8	8
70760.W0006	Threaded Bush	21	M 6	-	13	-	15	8	8	8
70760.W0104	Threaded Through	21	M 4	-	13	7	15	8	11	7
70760.W0105	Threaded Through	21	M 5	-	13	7	15	8	11	7
70760.W0106	Threaded Through	21	M 6	-	13	7	15	8	11	7
70760.W0410	Grub Screw	21	M 4	10	13	-	16	8	-	5
70760.W0425	Grub Screw	21	M 4	25	13	-	16	8	-	5
70760.W0510	Grub Screw	21	M 5	10	13	-	16	8	-	6
70760.W0515	Grub Screw	21	M 5	15	13	-	16	8	-	6