




Three Lobe Knob with stainless steel bush

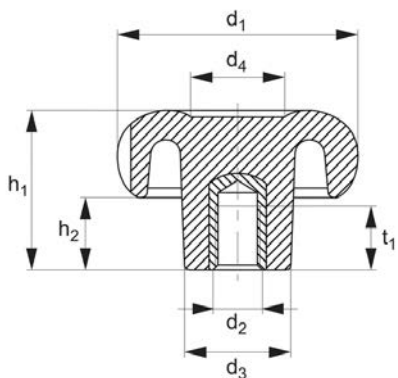

Grips



70580

GRIPS

Material

Grip: thermoplastic, black.

Bush: stainless steel.

Order No.	d ₁	d ₂	d ₃	d ₄	h ₁	h ₂	t ₁	Weight g
70580.W0060	30	M 6	14	11	22	11	9	11
70580.W0080	40	M 8	18	15	28	13	13	26
70580.W0100	50	M10	22	20	33	15	16	43




Three Lobe Knob

with **stainless steel** grub screw



70590

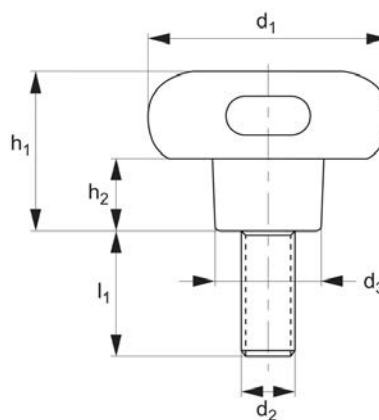

Material

Grip: thermoplastic, black.

Grub screw: stainless steel.


Order No.	d ₁	d ₂	l ₁	d ₃	h ₁	h ₂	Weight g
70590.W0061	30	M 6	20	14	22	11	18
70590.W0062	30	M 6	30	14	22	11	20
70590.W0081	40	M 8	20	18	28	13	20
70590.W0082	40	M 8	30	18	28	13	23
70590.W0101	50	M10	25	22	33	15	60
70590.W0102	50	M10	30	22	33	15	64



Three Lobed Knobs



Grips

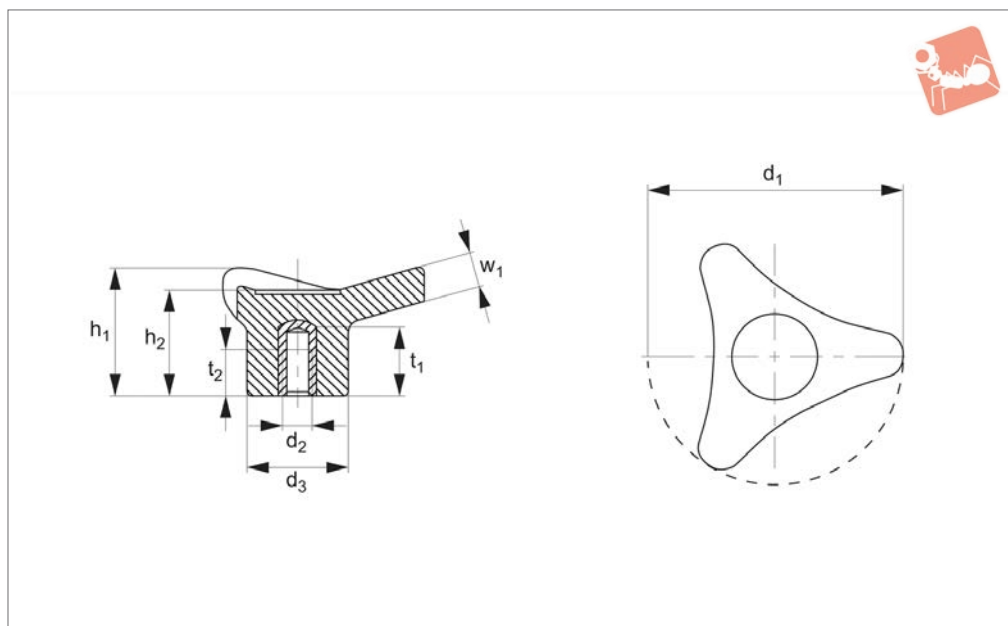

70620

GRIPS

Material

Brass bush. Duroplast, black.


Order No.	d ₁	d ₂	d ₃	h ₁	h ₂	t ₁	t ₂	w ₁	Weight g
70620.W0345	34	M 5	17	22	20	12	9	7.0	11
70620.W0346	34	M 6	17	22	20	12	9	7.0	11
70620.W0348	34	M 8	17	22	20	12	9	7.0	12
70620.W0456	45	M 6	25	30	27	18	13	8.5	26
70620.W0458	45	M 8	25	30	27	18	15	8.5	27
70620.W0459	45	M10	25	30	27	18	16	8.5	28
70620.W0658	65	M 8	30	39	36	25	15	10.0	51
70620.W0659	65	M10	30	39	36	25	16	10.0	51
70620.W0660	65	M12	30	39	36	25	18	10.0	56
70620.W0858	85	M 8	35	48	43	30	15	12.0	89
70620.W0859	85	M10	35	48	43	30	16	12.0	89
70620.W0860	85	M12	35	48	43	30	18	12.0	94
70620.W0861	85	M16	35	48	43	30	20	12.0	100



Three Lobed Knobs with grub screw




70630

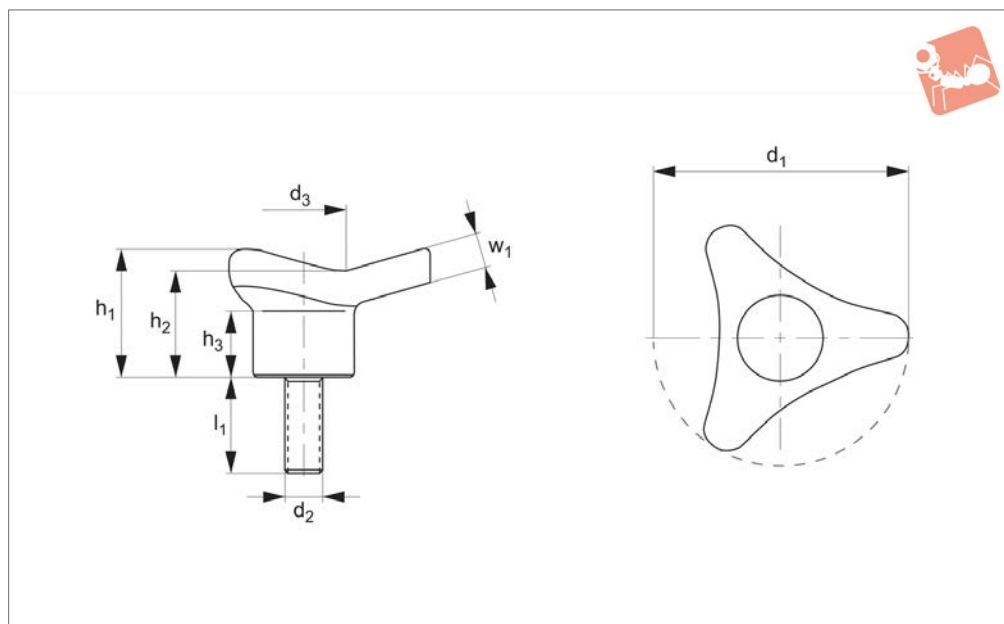

Material

Zinc plated steel stud. Duroplast, black.


Order No.	d ₁	d ₂	l ₁	d ₃	h ₁	h ₂	h ₃	w ₁	Weight g
70630.W0341	34	M 6	20	17	22	20	12	7.0	15.0
70630.W0342	34	M 6	25	17	22	20	12	7.0	16.0
70630.W0343	34	M 6	30	17	32	20	12	7.0	17.0
70630.W0344	34	M 8	20	17	22	20	12	7.0	19.0
70630.W0345	34	M 8	25	17	22	20	12	7.0	20.0
70630.W0451	41	M 8	20	25	30	27	18	8.5	35.0
70630.W0452	41	M 8	30	25	30	27	18	8.5	37.0
70630.W0453	41	M 8	40	25	30	27	18	8.5	41.0
70630.W0454	41	M10	30	25	30	27	18	8.5	46.0
70630.W0651	65	M 8	40	30	39	36	25	10.0	65.0
70630.W0652	65	M10	30	30	39	36	25	10.0	71.0
70630.W0851	85	M12	20	35	48	43	30	12.0	124.0
70630.W0852	85	M12	35	35	48	43	30	12.0	130.0

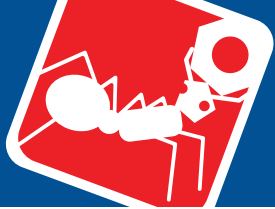

Three Lobed Knobs



Grips

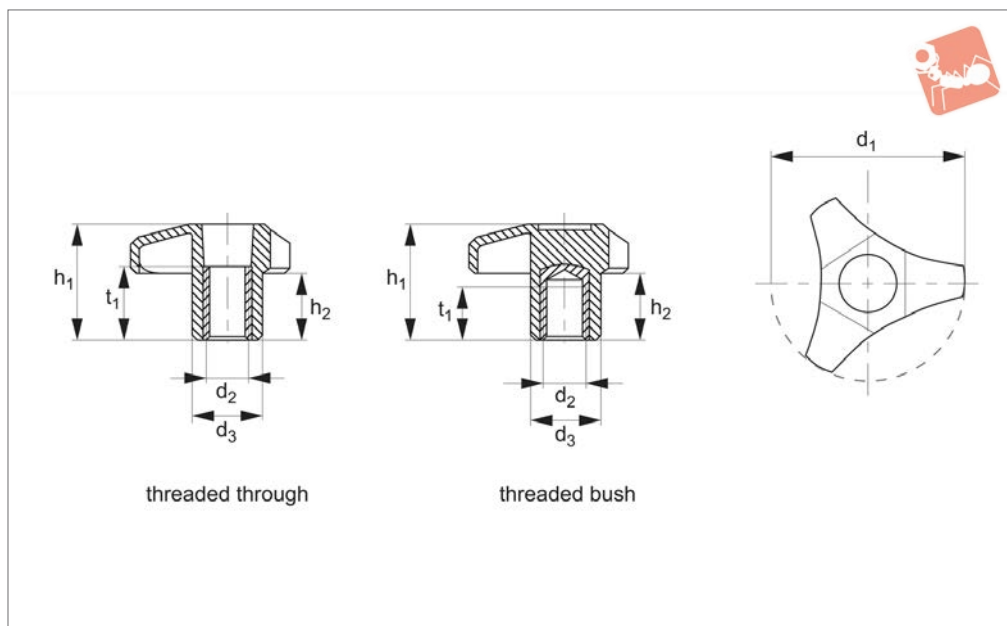

70640

GRIPS


Material

Brass bush. Thermoplastic, matt black.

Order No.	Type	d ₁	d ₂	d ₃	h ₁	h ₂	t ₁	Weight g
70640.W0045	Threaded Through	45	M 6	18	27	16	15	12.4
70640.W0046	Threaded Through	45	M 8	18	27	16	15	13.2
70640.W0047	Threaded Through	45	M10	18	27	16	15	13.2
70640.W0055	Threaded Through	55	M 8	20	33	19	15	18.2
70640.W0056	Threaded Through	55	M10	20	33	19	15	19.2
70640.W0057	Threaded Through	55	M12	20	33	19	15	19.8
70640.W0146	Threaded Bush	45	M 6	18	27	16	14	13.8
70640.W0148	Threaded Bush	45	M 8	18	27	16	14	15.6
70640.W0150	Threaded Bush	45	M10	18	27	16	14	17.2
70640.W0155	Threaded Bush	55	M 8	20	33	19	14	22.8
70640.W0156	Threaded Bush	55	M10	20	33	19	14	23.4
70640.W0157	Threaded Bush	55	M12	20	33	19	14	25.6



70660

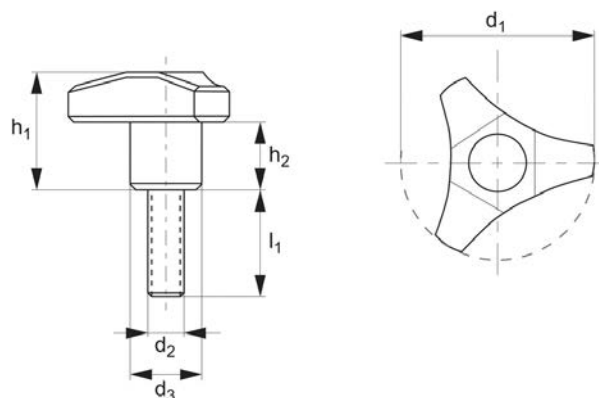

Material

Zinc plated steel stud. Thermoplastic, matt black.

Order No.	d ₁	d ₂	l ₁	d ₃	h ₁	h ₂	Weight g
70660.W0451	45	M 6	20	18	27	16	16.4
70660.W0452	45	M 6	25	18	27	16	17.0
70660.W0453	45	M 6	40	18	27	16	20.0
70660.W0454	45	M 8	20	18	27	16	20.2
70660.W0455	45	M 8	25	18	27	16	23.6
70660.W0456	45	M 8	40	18	27	16	27.0
70660.W0457	45	M10	20	18	27	16	30.0
70660.W0458	45	M10	30	18	27	16	35.0
70660.W0551	55	M 6	20	20	33	19	22.8
70660.W0552	55	M 6	25	20	33	19	23.6
70660.W0553	55	M 6	40	20	33	19	26.8
70660.W0554	55	M 8	20	20	33	19	27.2
70660.W0556	55	M 8	40	20	33	19	33.4
70660.W0560	55	M 8	30	20	33	19	30.1
70660.W0557	55	M10	20	20	33	19	36.4
70660.W0558	55	M10	30	20	33	19	42.0