




Quarter Turn Screw, Male

stainless steel



Grips

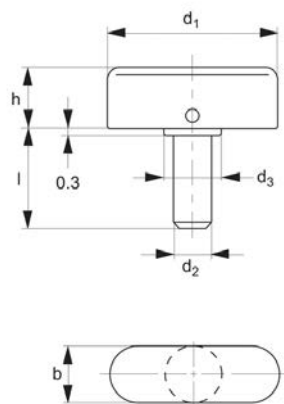

37380

GRIPS

Material

Stainless steel 1.4404 (AISI 316), body
sintered, matte, shot-blasted. Screw:
stainless steel, 1.4301 (AISI 304), matte,

shot-blasted.

Technical Notes


These quarter turn screws are used to

develop higher clamping torques than is
possible with knurled handles.

Order No.	d ₁	d ₂	d ₃	b	h	l	Weight g
37380.W0061	25	M 6	8	8	10.0	16	12
37380.W0062	25	M 6	8	8	10.0	20	16
37380.W0063	25	M 6	8	8	10.0	25	10
37380.W0081	30	M 8	10	10	12.0	16	26
37380.W0082	30	M 8	10	10	12.0	20	28
37380.W0083	30	M 8	10	10	12.0	25	30
37380.W0084	30	M 8	10	10	12.0	32	32
37380.W0085	36	M 8	12	12	14.5	16	44
37380.W0086	36	M 8	12	12	14.5	20	45
37380.W0087	36	M 8	12	12	14.5	25	50
37380.W0088	36	M 8	12	12	14.5	32	49
37380.W0101	36	M10	12	12	14.5	20	48
37380.W0102	36	M10	12	12	14.5	30	53
37380.W0103	36	M10	12	12	14.5	40	55



37400

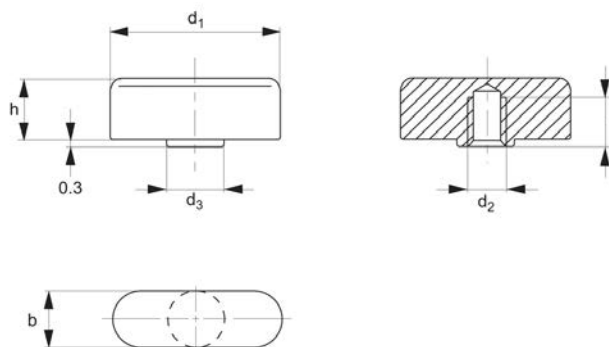

Material

Stainless steel 1.4404 (AISI 316), sintered, matte, shot-blasted.

Technical Notes


These quarter turn screws are used to develop higher clamping torques than is

possible with knurled handles.


Order No.	d ₁	d ₂	d ₃	b	h	t min.	Weight g
37400.W0061	25	M 6	8	8	10.0	7	11
37400.W0062	30	M 6	10	10	12.0	9	18
37400.W0081	30	M 8	10	10	12.0	9	18
37400.W0082	36	M 8	12	12	14.5	10	36
37400.W0101	36	M10	12	12	14.5	10	36



Wing Nut stainless steel

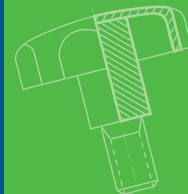

Grips

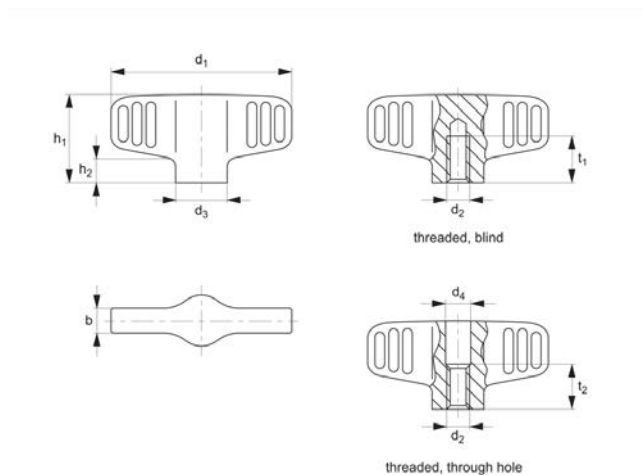

37420

GRIPS

Material

Stainless steel 1.4308, matt finish.


Order No.	Type	d ₁	d ₂	d ₃	d ₄ tol. H13	b	h ₁	h ₂ ≈	t ₁ min.	t ₂
37420.W0010	Threaded, blind	46	M 6	13	6.5	6	22.5	6.0	12	10
37420.W0012	Threaded, blind	46	M 8	13	8.5	6	22.5	6.0	15	13
37420.W0014	Threaded, blind	58	M 8	16	8.5	7	26.5	7.0	15	13
37420.W0016	Threaded, blind	58	M10	16	10.5	7	26.5	7.0	18	16
37420.W0210	Threaded, through hole	46	M 6	13	6.5	6	22.5	6.0	12	10
37420.W0212	Threaded, through hole	46	M 8	13	8.5	6	22.5	6.0	15	13
37420.W0214	Threaded, through hole	58	M 8	16	8.5	7	26.5	7.0	15	13
37420.W0216	Threaded, through hole	58	M10	16	10.5	7	26.5	7.0	18	16




37020 - Steel flat
knurled screw




37040 - Stainless steel
flat knurled screw

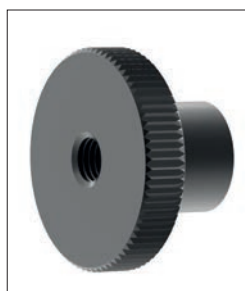

37100 - Steel knurled nut
with collar

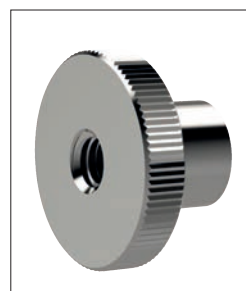

37110 - Stainless steel
knurled nut with collar

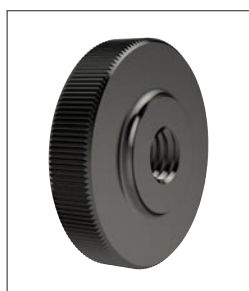

37120 - Steel flat
knurled nut



37130 - Stainless steel
flat knurled nut




37140 - Steel knurled
screw with collar



37150 - Stainless steel
knurled screw with collar



37160 - Steel knurled nut

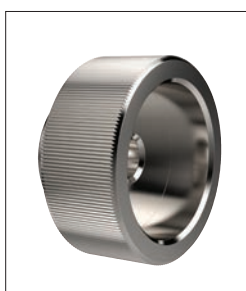

37170 - Stainless steel
knurled nut



37200 - Stainless steel
knurled thumb screw



37330 - Plastic knurled
nut



37352 - Plastic knurled
steel screw



37354 - Plastic knurled
stainless steel screw




37380 - 1/4 turn screw




37400 - 1/4 turn nut



37460 - Thumb knob

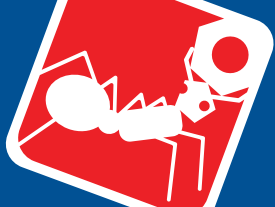

Wide Selection of Thumb Screws, Knurled Screws & Wing Nuts

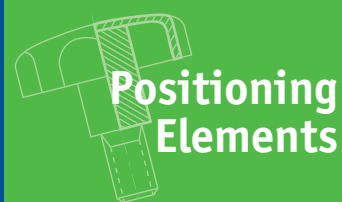

GRIPS



72180 - Plastic wing nut



72190 - Plastic wing nut
with screw



72210 - Plastic wing nuts



72270 - 1/4 turn nut




72280 - 1/4 turn nut



72290 - 1/4 turn screw




72300 - 1/4 turn screw

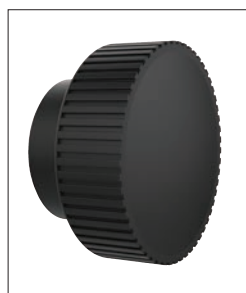

72410 - Knurled knob



72430 - Knurled knob
with screw

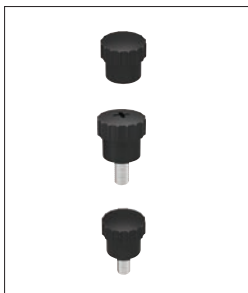

72440 - Knurled knobs





72460 - Knurled knobs





73200 - Mushroom knobs



72180

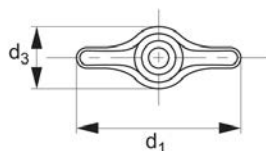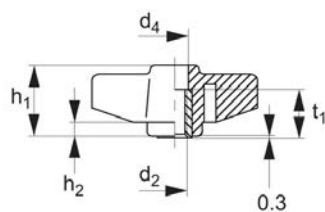

threaded through

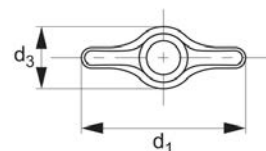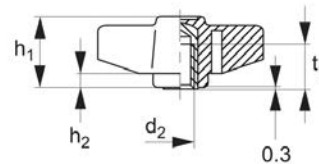

threaded bush

Material

Brass bush. Thermoplastic, black, matte.

Order No.	Type	d ₁	d ₂	d ₃	d ₄	h ₁	h ₂	t ₁	Weight g
72180.W0034	Threaded Through	34	M 5	14	7	18	4	15	7
72180.W0035	Threaded Through	34	M 6	14	7	18	4	15	7
72180.W0040	Threaded Through	40	M 6	15	9	19	4	15	10
72180.W0041	Threaded Through	40	M 8	15	9	19	4	15	10
72180.W0048	Threaded Through	48	M 6	17	9	20	4	15	10
72180.W0049	Threaded Through	48	M 8	17	9	20	4	15	11
72180.W0135	Threaded Bush	34	M 5	14	-	18	4	8	5
72180.W0136	Threaded Bush	34	M 6	14	-	18	4	9	5
72180.W0138	Threaded Bush	34	M 8	14	-	18	4	9	6
72180.W0146	Threaded Bush	40	M 6	15	-	19	4	9	7
72180.W0148	Threaded Bush	40	M 8	15	-	19	4	9	7
72180.W0149	Threaded Bush	48	M 6	17	-	20	4	13	7
72180.W0150	Threaded Bush	48	M 8	17	-	20	4	13	9




Wing Nuts

plastic, with grub screw



Grips

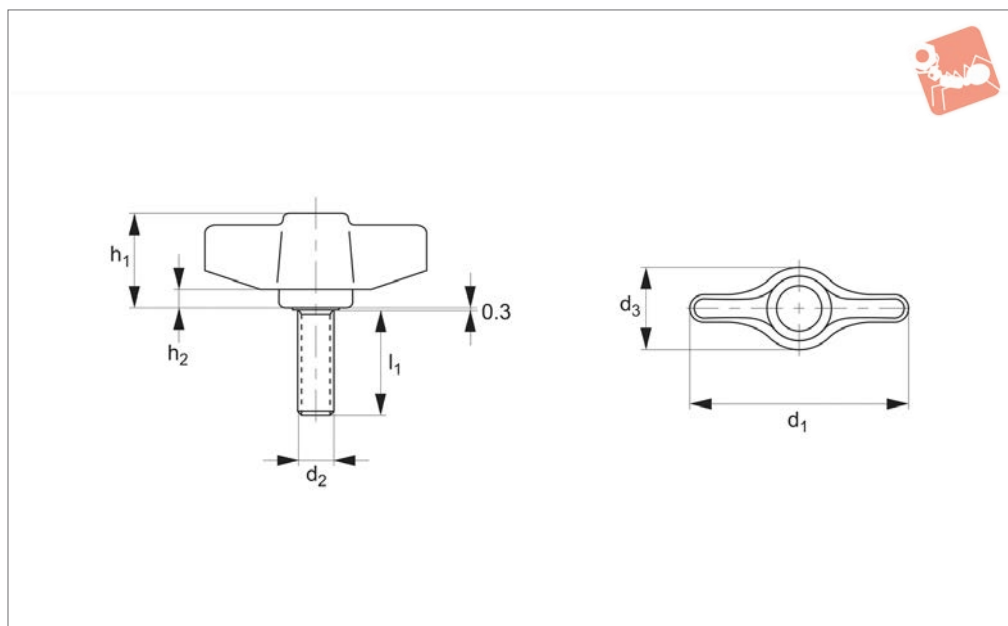


72190

GRIPS


Material

Zinc plated steel stud. Thermoplastic,
black, matt.


Order No.	d ₁	d ₂	d ₃	h ₁	h ₂	l ₁	Weight g
72190.W0341	34	M 4	14	18	4	15	5
72190.W0342	34	M 5	14	18	4	15	7
72190.W0343	34	M 6	14	18	4	15	9
72190.W0344	34	M 6	14	18	4	25	11
72190.W0345	34	M 8	14	18	4	15	13
72190.W0346	34	M 8	14	18	4	25	15
72190.W0401	40	M 6	15	19	4	15	10
72190.W0402	40	M 6	15	19	4	20	11
72190.W0403	40	M 8	15	19	4	15	14
72190.W0404	40	M 8	15	19	4	20	15
72190.W0405	40	M 8	15	19	4	25	16
72190.W0481	48	M 6	17	20	4	15	12
72190.W0482	48	M 6	17	20	4	20	12
72190.W0483	48	M 6	17	20	4	25	13
72190.W0484	48	M 8	17	20	4	15	15
72190.W0485	48	M 8	17	20	4	25	18
72190.W0486	48	M 8	17	20	4	30	19
72190.W0487	48	M 8	17	20	4	40	22

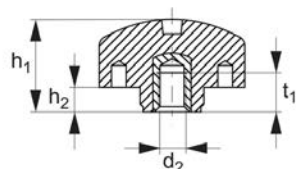**72210**

threaded bush


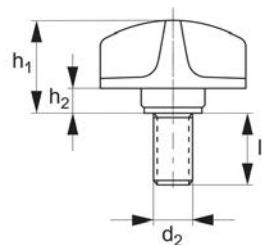


grub screw

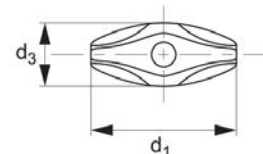**Material**

Brass bush. Zinc plated steel stud. Thermo-plastic, black, matt.

Order No.	Type	d ₁	d ₂	d ₃	h ₁	h ₂	l ₁	t ₁	Weight g
72210.W0004	Threaded Bush	30	M 4	13	19	5	-	8	5.8
72210.W0005	Threaded Bush	30	M 5	13	19	5	-	8	5.4
72210.W0006	Threaded Bush	30	M 6	13	19	5	-	8	5.6
72210.W0008	Threaded Bush	30	M 8	13	19	5	-	8	6.0
72210.W0341	Grub Screw	30	M 4	13	19	5	15	-	5.4
72210.W0342	Grub Screw	30	M 4	13	19	5	20	-	5.4
72210.W0351	Grub Screw	30	M 5	13	19	5	15	-	6.4
72210.W0352	Grub Screw	30	M 5	13	19	5	25	-	7.6
72210.W0353	Grub Screw	30	M 5	13	19	5	30	-	9.4
72210.W0361	Grub Screw	30	M 6	13	19	5	15	-	8.0
72210.W0362	Grub Screw	30	M 6	13	19	5	25	-	9.8
72210.W0363	Grub Screw	30	M 6	13	19	5	30	-	10.0
72210.W0364	Grub Screw	30	M 6	13	19	5	40	-	12.2
72210.W0381	Grub Screw	30	M 8	13	19	5	15	-	11.4
72210.W0383	Grub Screw	30	M 8	13	19	5	30	-	16.6
72210.W0384	Grub Screw	30	M 8	13	19	5	40	-	19.8

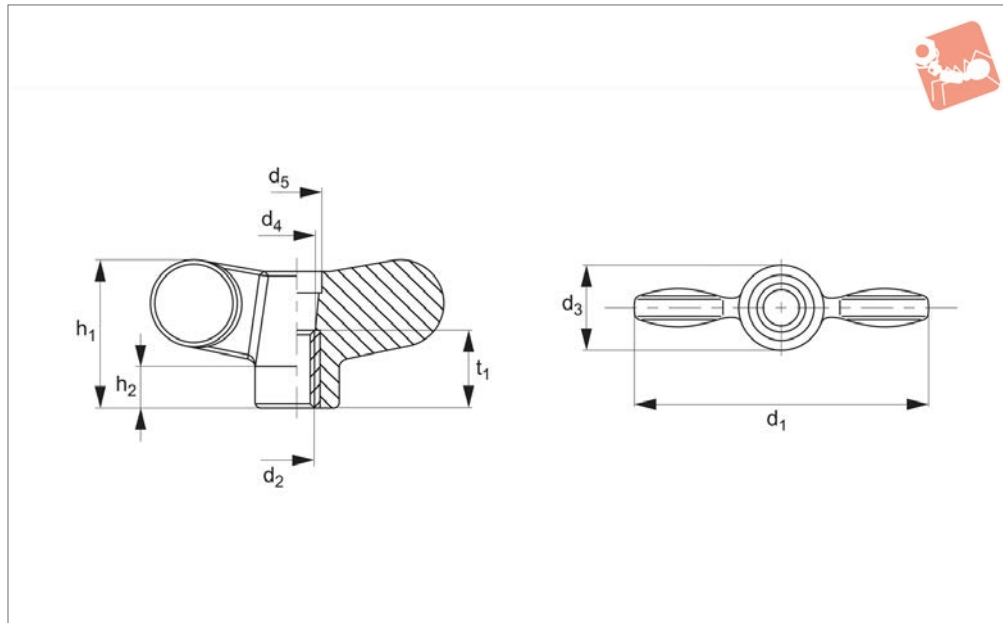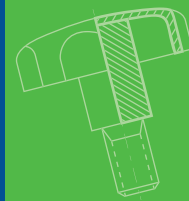

72270

GRIPS

Material

Thermoplastic, black.
Brass bush.

Order No.	d ₁	d ₂	d ₃	d ₄	d ₅	h ₁	h ₂	t ₁	Weight g
72270.W0052	55	M 6	16	8	11	28	8	18	14
72270.W0054	55	M 8	16	10	11	28	8	18	15
72270.W0074	70	M 8	20	10	11	36	10	18	23
72270.W0076	70	M10	20	11	11	36	10	18	24




Wing Nut

plastic, with colour insert



72280

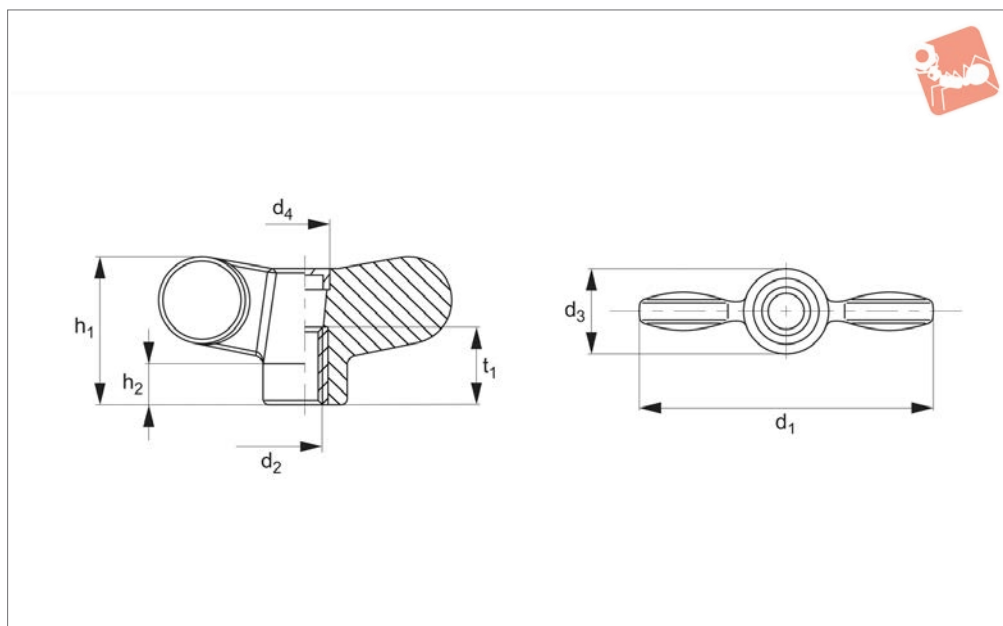

Material

Thermoplastic, black.

Plastic insert: black RAL9005, red


RAL3000, blue RAL5019.

subject to minimum quantity.

Tips

Other colour inserts available on request,

Order No.	Insert colour	d ₁	d ₂	d ₃	d ₄	h ₁	h ₂	t ₁	Weight g
72280.W0052	Black	55	M 6	16	11	28	8	18	14.5
72280.W0054	Black	55	M 8	16	11	28	8	18	15.5
72280.W0074	Black	70	M 8	20	11	36	10	18	23.5
72280.W0076	Black	70	M10	20	11	36	10	18	24.5
72280.W0152	Red	55	M 6	16	11	28	8	18	14.5
72280.W0154	Red	55	M 8	16	11	28	8	18	15.5
72280.W0174	Red	70	M 8	20	11	36	10	18	23.5
72280.W0176	Red	70	M10	20	11	36	10	18	24.5
72280.W0252	Blue	55	M 6	16	11	28	8	18	14.5
72280.W0254	Blue	55	M 8	16	11	28	8	18	15.5
72280.W0274	Blue	70	M 8	20	11	36	10	18	23.5
72280.W0276	Blue	70	M10	20	11	36	10	18	24.5

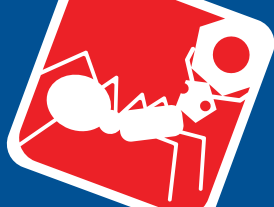


Wing Nut

plastic, with grub screw and colour insert



Grips

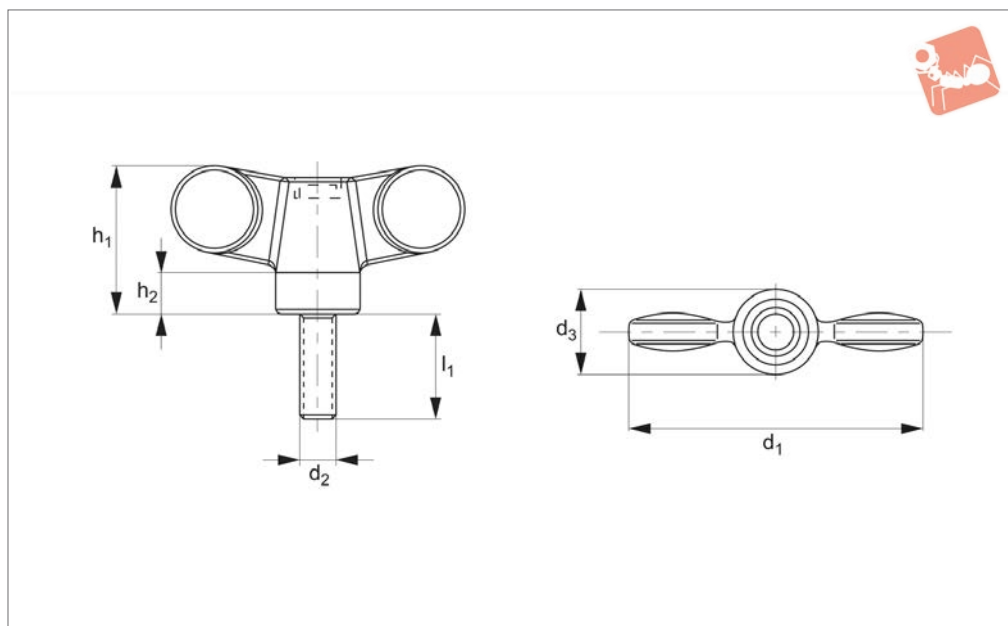

72290

GRIPS

Material

Thermoplastic black.
Plastic insert: black RAL9005, red

RAL3000, blue RAL 5019.

subject to minimum quantity.

Tips

Other colour inserts available on request,


Order No.	Insert colour	d ₁	d ₂	d ₃	h ₁	h ₂	l ₁	Weight g
72290.W0054	Black	55	M 8	16	28	8	20	24
72290.W0055	Black	55	M 8	16	28	8	40	26
72290.W0056	Black	55	M10	16	28	8	20	30
72290.W0057	Black	55	M10	16	28	8	40	40
72290.W0074	Black	70	M 8	20	36	10	20	30
72290.W0076	Black	70	M10	20	36	10	20	39
72290.W0077	Black	70	M10	20	36	10	40	47
72290.W0154	Red	55	M 8	16	28	8	20	24
72290.W0155	Red	55	M 8	16	28	8	40	26
72290.W0156	Red	55	M10	16	28	8	20	30
72290.W0157	Red	55	M10	16	28	8	40	40
72290.W0174	Red	70	M 8	20	36	10	20	30
72290.W0176	Red	70	M10	20	36	10	20	39
72290.W0177	Red	70	M10	20	36	10	40	47
72290.W0254	Blue	55	M 8	16	28	8	20	24
72290.W0255	Blue	55	M 8	16	28	8	40	26
72290.W0256	Blue	55	M10	16	28	8	20	30
72290.W0257	Blue	55	M10	16	28	8	40	40
72290.W0274	Blue	70	M 8	20	36	10	20	30
72290.W0276	Blue	70	M10	20	36	10	20	39
72290.W0277	Blue	70	M10	20	36	10	40	47



Wing Nut - Stainless Steel plastic, with grub screw and colour insert



72300

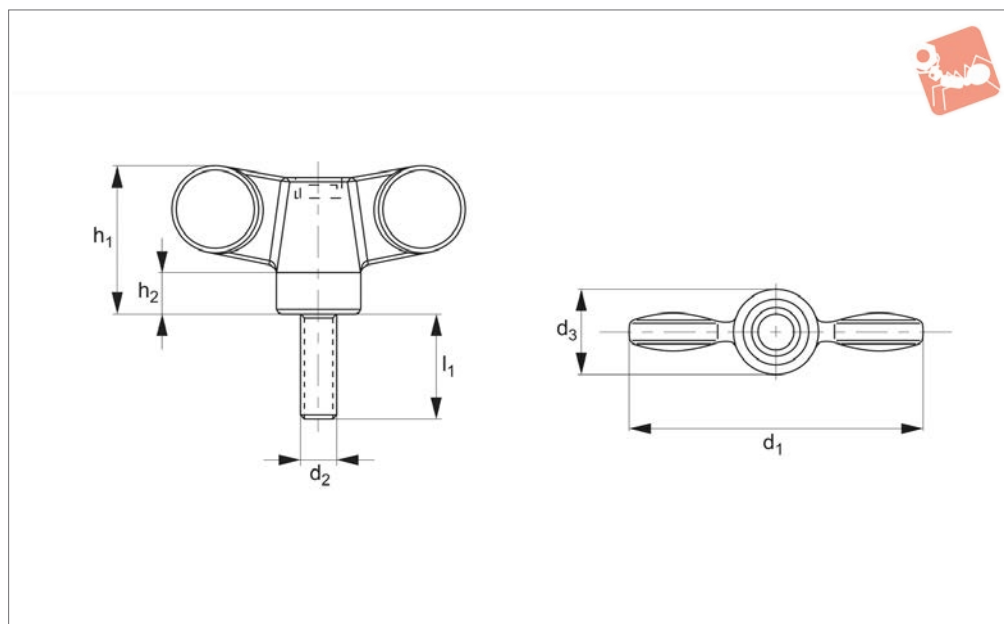

Material

Thermoplastic black, with stainless steel thread.

Plastic insert: black RAL9005, red

RAL3000, blue RAL5019.

subject to minimum quantity.

Tips

Other colour inserts available on request,

Order No.	Insert colour	d ₁	d ₂	d ₃	h ₁	h ₂	l ₁	Weight g
72300.W0054	Black	55	M 8	16	28	8	20	24
72300.W0055	Black	55	M 8	16	28	8	30	25
72300.W0077	Black	70	M10	20	36	10	30	43
72300.W0154	Red	55	M 8	16	28	8	20	24
72300.W0155	Red	55	M 8	16	28	8	30	25
72300.W0177	Red	70	M10	20	36	10	30	43
72300.W0254	Blue	55	M 8	16	28	8	20	24
72300.W0255	Blue	55	M 8	16	28	8	30	25
72300.W0277	Blue	70	M10	20	36	10	30	43