




Pull Handles plastic

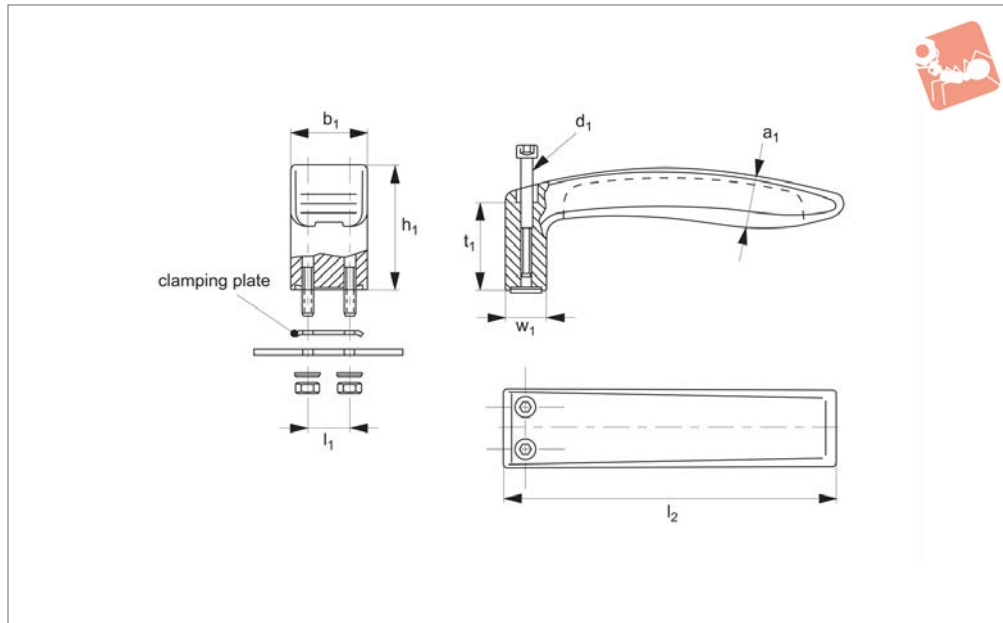

78190

PULL HANDLES

Material

Thermoplastic PA 6, glass ball reinforced, matt black.

Technical Notes


Ideal for applications where one-sided fastening required. Minimum stress resi-

stance 800N per handle.

Order No.	l_1	l_2	a_1	b_1	d_1	h_1	t_1	w_1
78190.W0017	17	128	20	30	M 5x45	48	33	18
78190.W0020	20	154	24	36	M 6x55	58	40	22



79100

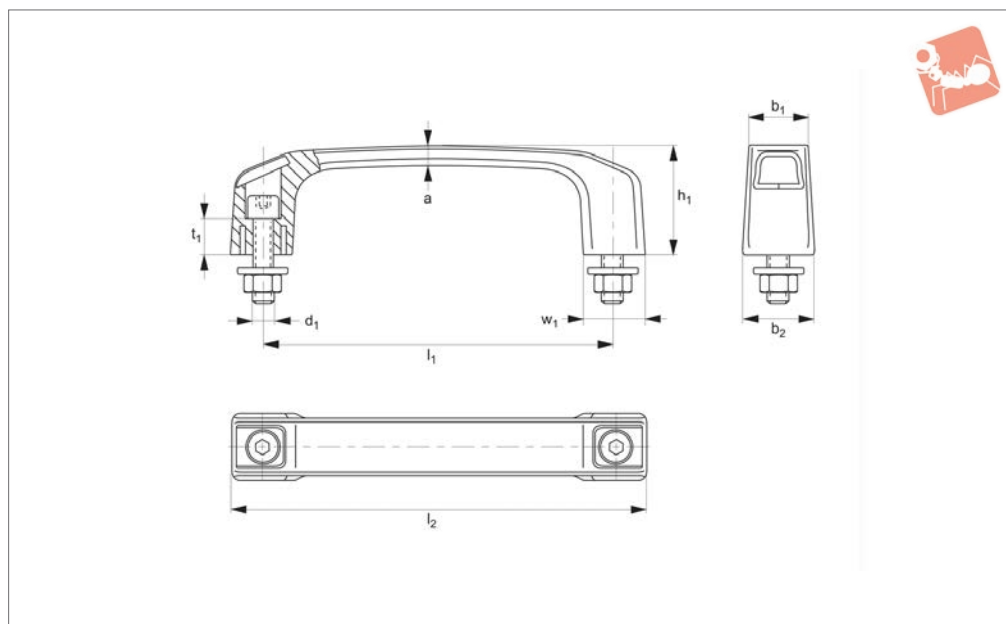

Material

Handle: thermoplastic PA 6 glass-ball reinforced. Matt black with attractive fine-grain structure. Blanking caps: in the same surface structure available in black, red, green, blue and yellow.

Technical Notes

Includes electrogalvanized socket-head cap bolts DIN 912, nuts DIN 934 and washers DIN 125.
Minimum stress resistance 1000N.


Tips

Red - similar to RAL 3020
Green - similar to RAL 6024
Blue - similar to RAL 5017
Yellow - similar to RAL 1023

Order No.	Cap colour	l_1	l_2	a	b_1	b_2	d_1	h_1	t_1	w_1
79100.W0120-9	Black	120	141	7	21	24	M_6x25	39	13	21
79100.W0140-9	Black	140	164	8	24	28	M_8x30	45	15	24
79100.W0120-3	Red	120	141	7	21	24	M_6x25	39	13	21
79100.W0140-3	Red	140	164	8	24	28	M_8x30	45	15	24
79100.W0120-6	Green	120	141	7	21	24	M_6x25	39	13	21
79100.W0140-6	Green	140	164	8	24	28	M_8x30	45	15	24
79100.W0120-5	Blue	120	141	7	21	24	M_6x25	39	13	21
79100.W0140-5	Blue	140	164	8	24	28	M_8x30	45	15	24
79100.W0120-1	Yellow	120	141	7	21	24	M_6x25	39	13	21
79100.W0140-1	Yellow	140	164	8	24	28	M_8x30	45	15	24
79100.W0120-0	W/o Caps & Screws	120	141	7	21	24	M_6x25	39	13	21
79100.W0140-0	W/o Caps & Screws	140	164	8	24	28	M_8x30	45	15	24



Pull Handles plastic

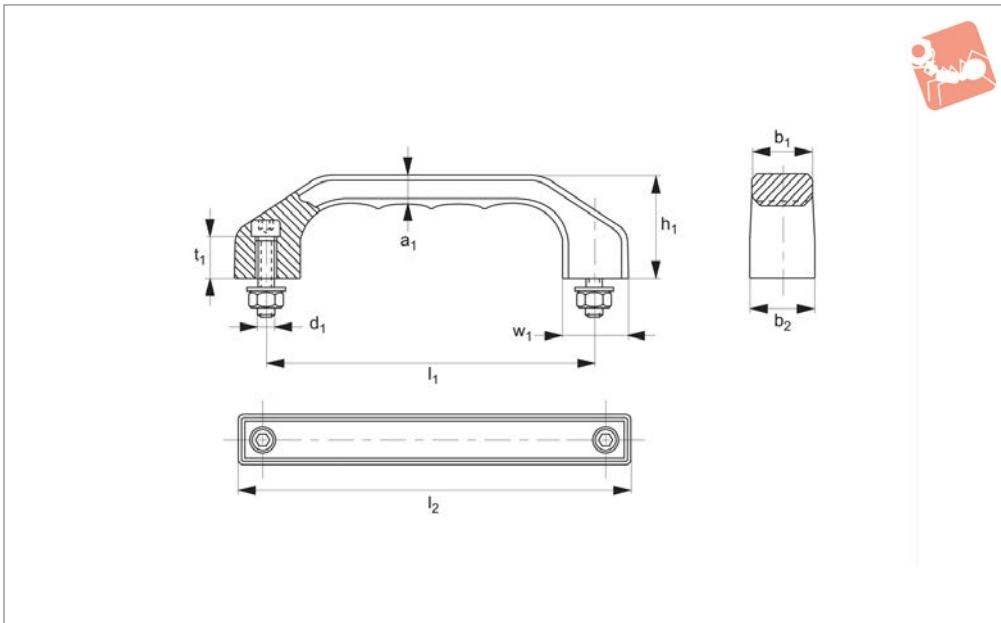

79120

PULL HANDLES

Material

Solid thermoplastic PA 6, glass ball reinforced. Matt black or orange with attractive, fine grain structure.

Technical Notes

Including hex screws DIN912 with suitable

nuts and washer. Solid plastic. Modern industrial design for the highest demands. Extremely resistant to torsion and easy to grip.


Minimum stress resistance >1000N. And scope of supply.

Including black galvanised cheese head screws (chromium VI free) with hexagon sockets DIN 912 and galvanised nuts DIN 934 with washers DIN 125.

Order No.	Finish	l_1	l_2	a_1	b_1	b_2	d_1	h_1	t_1	w_1
79120.W0100-8	Black	100	122	8.5	17.0	19	M 5x22	33	13	20
79120.W0120-8	Black	120	146	10.5	20.5	24	M 6x25	39	15	24
79120.W0140-8	Black	140	170	12.0	24.0	27	M 8x30	45	16	28
79120.W0160-8	Black	160	194	13.5	27.5	31	M 8x35	52	20	32
79120.W0180-8	Black	180	218	15.5	31.0	35	M10x40	58	20	36
79120.W0100-0	Orange	100	122	8.5	17.0	19	M 5x22	33	13	20
79120.W0120-0	Orange	120	146	10.5	20.5	24	M 6 x25	39	15	24
79120.W0140-0	Orange	140	170	12.0	24.0	27	M 8 x30	45	16	28
79120.W0160-0	Orange	160	194	13.5	27.5	31	M 8x35	52	20	32
79120.W0180-0	Orange	180	218	15.5	31.0	35	M10x40	58	20	36



79150

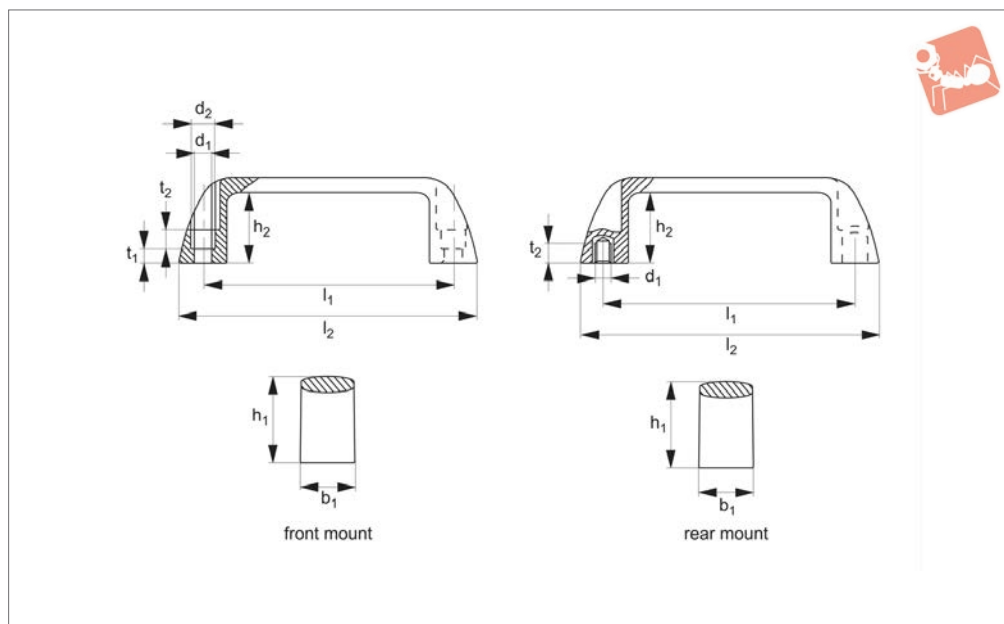

Material

Thermoplastic, black, matt, glass fibre reinforced.


Threaded bush: brass.

Technical Notes

Other colours on request: red, orange,


white & grey - subject to minimum quantity.

Order No.	Type	l_1	l_2	b_1	d_2	h_1	h_2	t_1	t_2	$\varnothing d_1$	Weight g
79150.W0010	Front Mount	93.5	112	21	$\varnothing 10,5$	36	30	6	7	6.5	26
79150.W0011	Front Mount	117.0	139	26	$\varnothing 10,5$	41	34	6	9	6.5	41
79150.W0012	Front Mount	117.0	139	26	$\varnothing 13,0$	41	34	6	9	8.5	40
79150.W0013	Front Mount	132.0	156	27	$\varnothing 10,5$	45	37	9	7	6.5	56
79150.W0014	Front Mount	132.0	156	27	$\varnothing 13,0$	45	37	7	9	8.5	54
79150.W0018	Front Mount	179.0	204	28	$\varnothing 13,0$	50	42	8	9	8.5	72
79150.W0509	Rear Mount	93.5	112	21	-	36	30	-	9	M 5	33
79150.W0510	Rear Mount	93.5	112	21	-	36	30	-	9	M 6	33
79150.W0511	Rear Mount	117.0	139	26	-	41	34	-	9	M 6	47
79150.W0512	Rear Mount	117.0	139	26	-	41	34	-	9	M 8	49
79150.W0513	Rear Mount	132.0	156	27	-	45	37	-	9	M 6	62
79150.W0514	Rear Mount	132.0	156	27	-	45	37	-	9	M 8	64
79150.W0518	Rear Mount	179.0	204	28	-	50	42	-	9	M 8	82

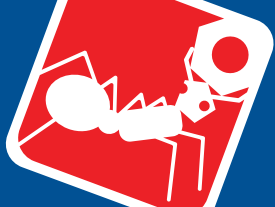

Plastic Pull Handles

rear mounting

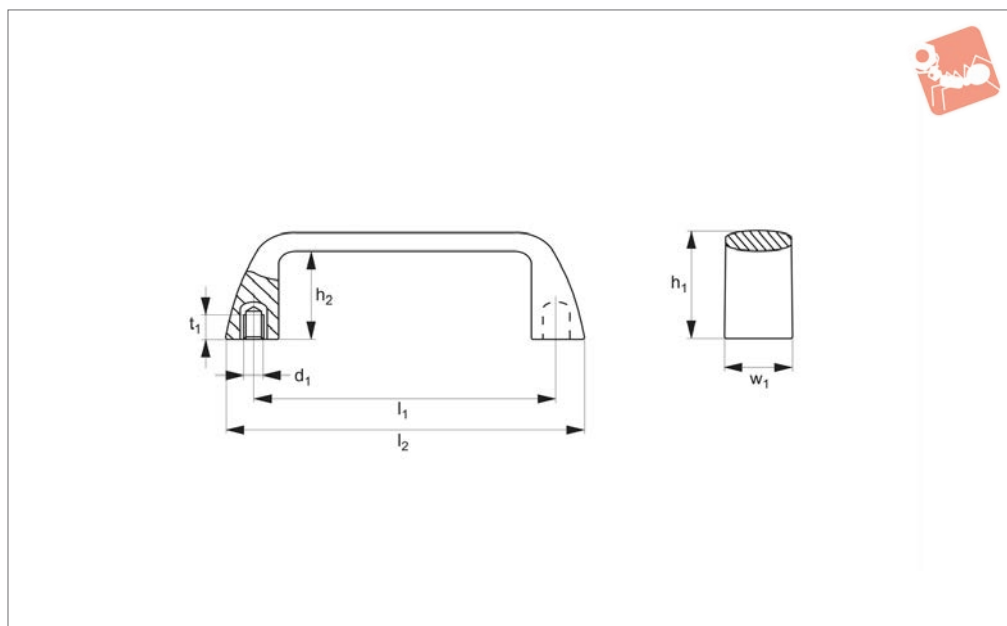

79180

PULL HANDLES

Material

Thermoplastic, black, matt. Glass fibre reinforced.

Brass insert with tapped blind hole.

Technical Notes

Other colours on request:- red, orange,

white & grey - subject to minimum quantity.

Order No.	l_1	l_2	d_1	h_1	h_2	t_1	w_1	Weight g
79180.W0009	105	121	M 5	37	29	9	26	46
79180.W0010	105	121	M 6	37	29	9	26	48
79180.W0011	110	133	M 5	40	32	9	26	58
79180.W0012	110	133	M 6	40	32	9	26	60
79180.W0016	117	133	M 5	40	32	9	26	57
79180.W0017	117	133	M 6	40	32	9	26	59
79180.W0018	117	133	M 8	40	32	9	26	61