




Cap Head Hexagon Socket Medical

PEEK Fasteners

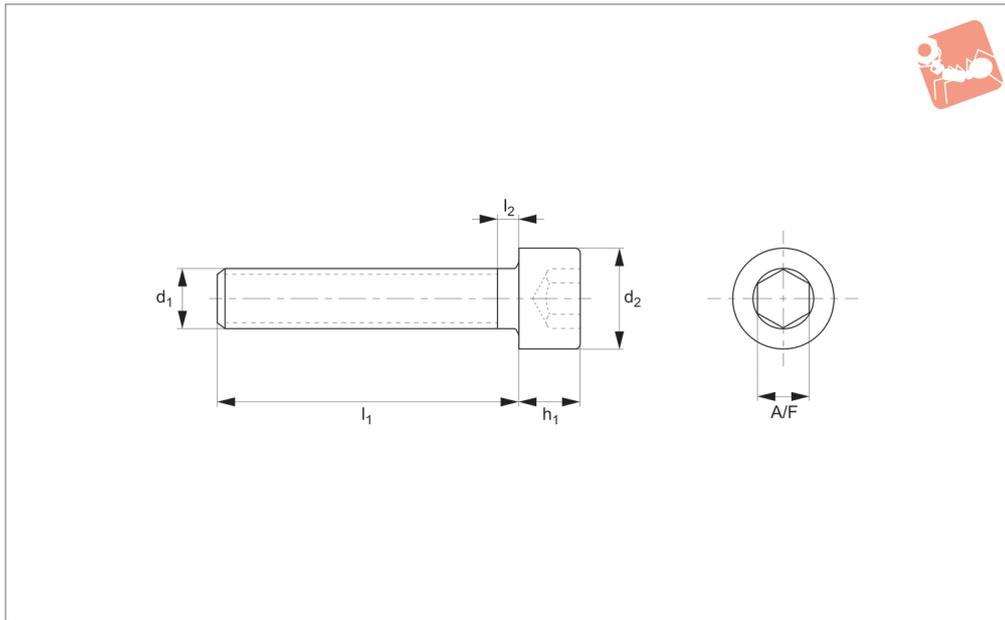

WN0500.MP

PEEK FASTENERS

Material

Polyether ether ketone (PEEK). Green

A high performance plastic with very good durability and wear resistance. PEEK has excellent chemical resistance and performs well at temperatures up to 260°C. Tensile

strength ~116N/mm².

Technical Notes

Manufactured for medical industry applications, these products are in a variant of PEEK which is refined for biocompatibility.

For industries with a hygienic requirement, these products are available with an X-Ray opaque or metal detectable filler, blue in colour, for optical detection.

Natural PEEK is used in the aerospace and chemical industries.

Order No.	d ₁	l ₁ +/- 0.2	l ₂ max.	d ₂	h ₁	A/F
WN0500.030-008-MP	M 3	8	1.0	5.5	3	2.5
WN0500.030-010-MP	M 3	10	1.0	5.5	3	2.5
WN0500.030-012-MP	M 3	12	1.0	5.5	3	2.5
WN0500.030-015-MP	M 3	15	1.0	5.5	3	2.5
WN0500.030-020-MP	M 3	20	1.0	5.5	3	2.5
WN0500.030-025-MP	M 3	25	1.0	5.5	3	2.5
WN0500.040-008-MP	M 4	8	1.4	7.0	4	3.0
WN0500.040-010-MP	M 4	10	1.4	7.0	4	3.0
WN0500.040-012-MP	M 4	12	1.4	7.0	4	3.0
WN0500.040-015-MP	M 4	15	1.4	7.0	4	3.0
WN0500.040-020-MP	M 4	20	1.4	7.0	4	3.0
WN0500.040-025-MP	M 4	25	1.4	7.0	4	3.0
WN0500.050-008-MP	M 5	8	1.6	8.5	5	4.0
WN0500.050-010-MP	M 5	10	1.6	8.5	5	4.0
WN0500.050-012-MP	M 5	12	1.6	8.5	5	4.0
WN0500.050-015-MP	M 5	15	1.6	8.5	5	4.0
WN0500.050-020-MP	M 5	20	1.6	8.5	5	4.0
WN0500.050-025-MP	M 5	25	1.6	8.5	5	4.0
WN0500.050-030-MP	M 5	30	1.6	8.5	5	4.0
WN0500.060-010-MP	M 6	10	2.0	10.0	6	5.0
WN0500.060-012-MP	M 6	12	2.0	10.0	6	5.0
WN0500.060-015-MP	M 6	15	2.0	10.0	6	5.0
WN0500.060-020-MP	M 6	20	2.0	10.0	6	5.0
WN0500.060-025-MP	M 6	25	2.0	10.0	6	5.0
WN0500.060-030-MP	M 6	30	2.0	10.0	6	5.0
WN0500.080-020-MP	M 8	20	2.5	13.0	8	6.0
WN0500.080-025-MP	M 8	25	2.5	13.0	8	6.0
WN0500.080-030-MP	M 8	30	2.5	13.0	8	6.0
WN0500.080-035-MP	M 8	35	2.5	13.0	8	6.0