



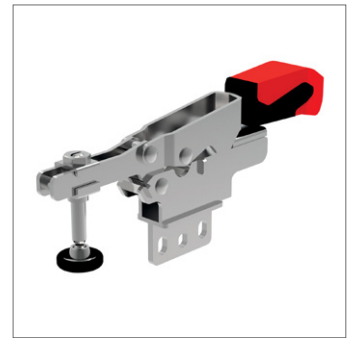

Auto-Adjust Toggle Clamp

open clamping arm - vertical base

Auto-Adjust Toggle Clamps

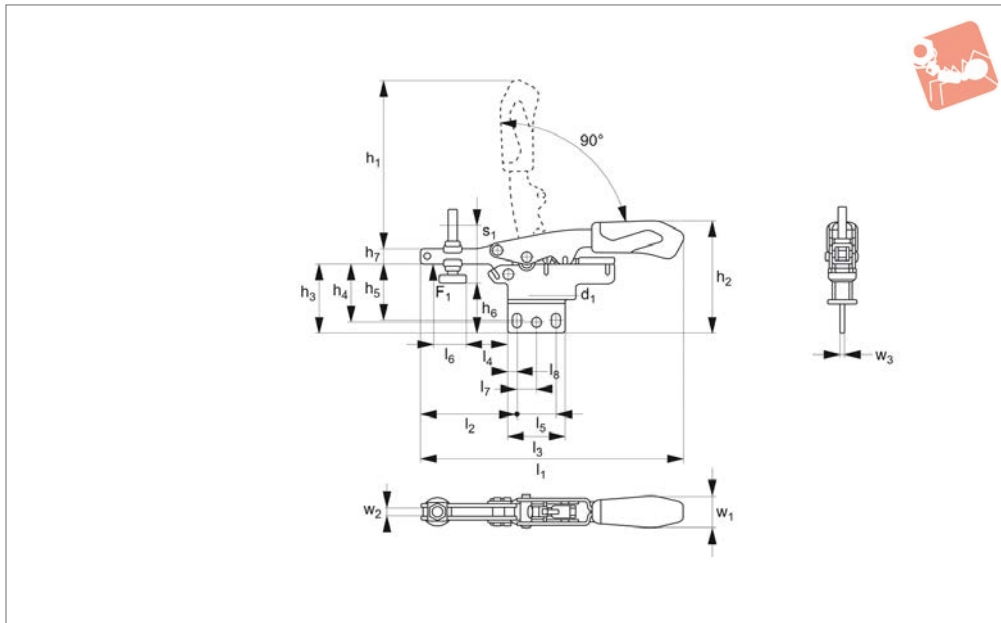

42609

AUTO-ADJUST TOGGLE CLAMPS

Material

Body: steel, zinc plated.
Ergonomic, soft feel and oil-resistant
handle with large grip area.

Supplied complete with zinc plated clamping screw (with rubber pad).

Technical Notes

Automatically adjusts to suit work-piece height.
Temperature range -10°C to +80°C.

Order No.	Size	F_1 kN	Automatic height compensation s_1	Height compensation max.	Clamping screw	h_1	h_2	h_3	h_4	h_5	h_6 min.	Weight g
42609.W0020	20	2	20	35	M 6x49	113	73.0	47	39.8	37-40	13.5	272
42609.W0050	50	3	35	40	M 8x50	158	94.5	59	49.0	45-49	27.5	544

Order No.	h_6 max.	h_7	l_1	l_2	l_3	l_4	l_5	l_6	l_7	l_8	w_1	w_2	w_3	d_1	d_2
42609.W0020	31	10	173	64.0	38	25.9	26	22	13	6.0	21	6.0	3	5.6	5.6
42609.W0050	38	13	243	106.5	55	38.0	50	35	19	8.5	27	8.2	4	6.5	5.6




Benefits


- Automatically adapts to workpiece height / width.
- Ideal for small batch sizes.
- Adjustable clamping forces.



Example Toggle Clamps

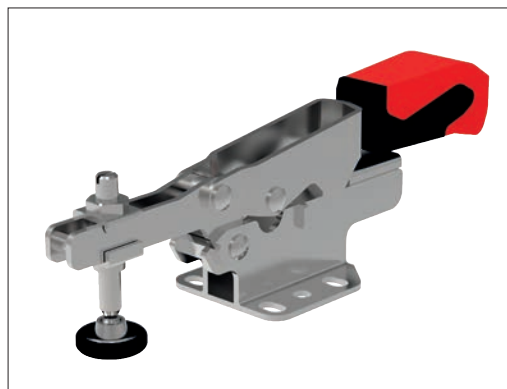

42605 - Horizontal base - vertical acting

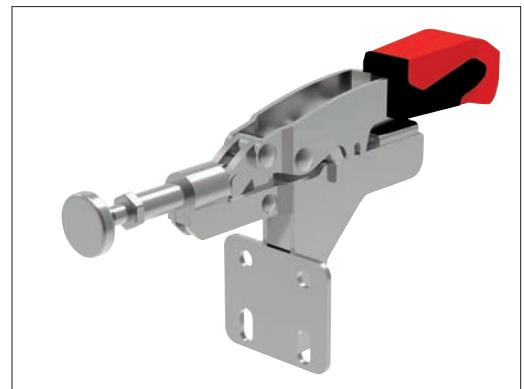

42611 - Push pull type - horizontal acting