


Latch Type Toggle Clamps

horizontal acting



41801.1

STEEL TOGGLE CLAMPS

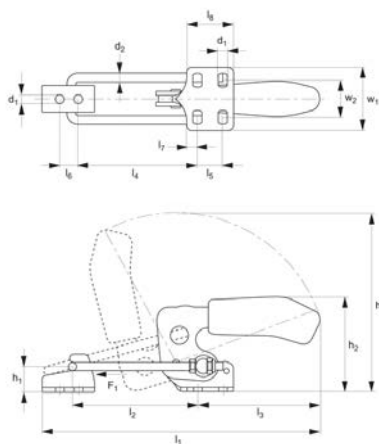

Material

Body: steel, zinc-plated. Stainless steel rivets running in hardened bushes. Pre-lubricated bearings (grease suitable for food industry use).
Ergonomic, soft feel, oil-resistant handle

with large grip area.

Hook: steel, tempered.

Complete with counter strike.

Technical Notes

Temperature range -10°C to +80°C.

Tips


For stainless steel version see part no. 41811.

Order No.	Size	F ₁ kN	h ₁	h ₂	l ₁ min.	l ₁ max.	l ₂ min.	l ₂ max.	h ₃	Weight g
41801.W0002	2	1.6	12	47.0	125	159	42.0	76	99	120
41801.W0003	3	3.2	19	70.0	169	216	53.5	101	136	330
41801.W0004	4	7.0	26	94.5	209	273	66.0	130	168	810

Order No.	l ₃	l ₄ min.	l ₄ max.	l ₅	l ₆	l ₇	l ₈	w ₁	w ₂	d ₁	d ₂
41801.W0002	69	38.0	72	13	11	6.4	26.0	38.0	19,5-23,5	5.2	4
41801.W0003	93	48.6	96	19	14	8.0	35.0	48.0	24,5-32,0	6.5	6
41801.W0004	111	59.0	123	32	19	9.5	53.5	64.5	35,0-46,0	8.5	8



41811.1

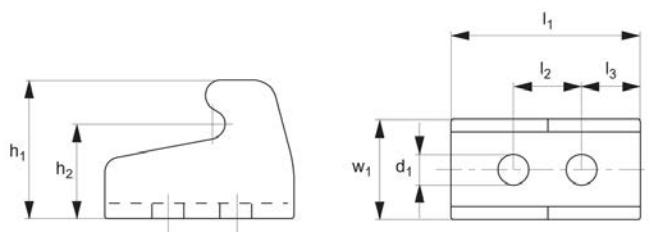

Material

Steel, zinc plated.

For stainless steel version see part no. 41781.W0303.


Technical Notes

See part no. 41781.W0013 for strike catch.

Order No.	Size	h_1	h_2	l_1	l_2	l_3	w_1	d_1	Weight g
41811.W0012	2	16	18	26	11	8	18	5.2	12
41811.W0013	3	44	28	39	14	12	23	6.5	19
41811.W0014	4	108	38	56	19	17	30	8.5	26



41831.1

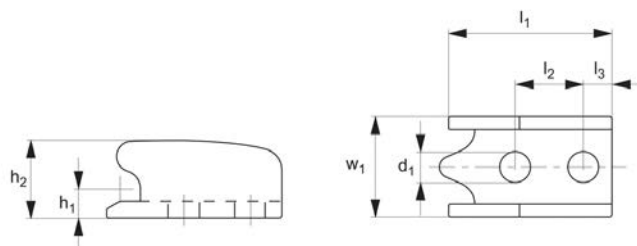

Material

Steel, zinc plated.

Technical Notes

For use with toggle clamp no. 41821.W0002 - .W0004.

Order No.	Size	h_1	h_2	l_1	l_2	l_3	w_1	d_1	Weight g
41831.W0012	2	5	12	26	11	5	18	5.2	14
41831.W0013	3	6	16	36	14	7	23	6.5	30
41831.W0014	4	8	22	48	19	9	30	8.5	66